
 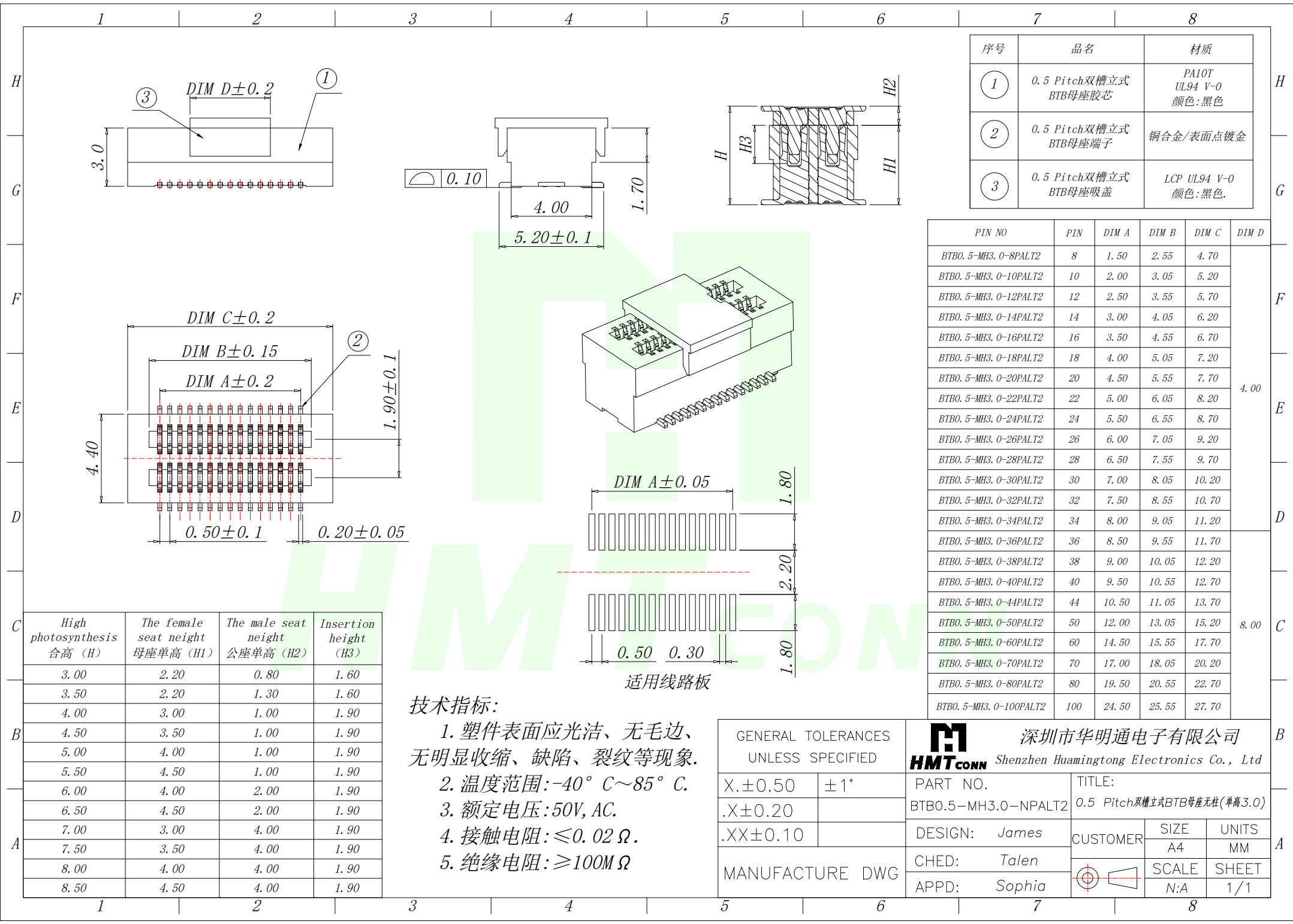




- 技术指标:
1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象.
 2. 温度范围: $-40^{\circ}\text{C} \sim 85^{\circ}\text{C}$.
 3. 额定电压: 50V, AC .
 4. 接触电阻: $\leq 0.02\ \Omega$.
 5. 绝缘电阻: $\geq 100\text{M}\ \Omega$

GENERAL TOLERANCES UNLESS SPECIFIED		 深圳市华明通电子有限公司 HMTconn Shenzhen Huamingtong Electronics Co., Ltd	
X. ± 0.50	$\pm 1^{\circ}$	PART NO.	TITLE:
.X ± 0.20		BTB0.5-MH3.0-NPALT2	0.5 Pitch双槽立式BTB母座无柱(单高3.0)
.XX ± 0.10		DESIGN: James	CUSTOMER
MANUFACTURE DWG		CHED: Talen	SIZE
		APPD: Sophia	UNITS
			SCALE
			SHEET
			N:A
			1/1