


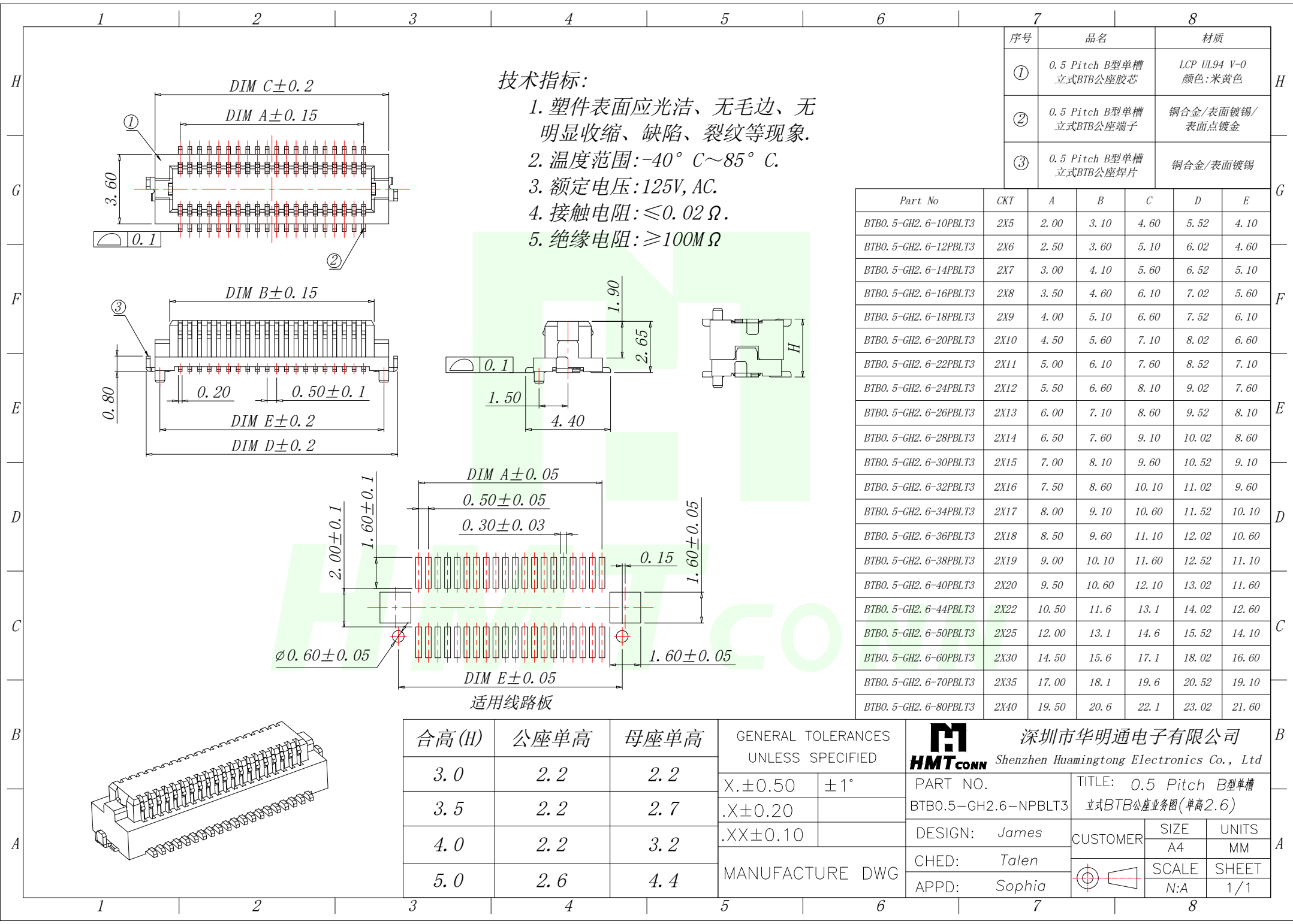

技术指标:

- 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
- 温度范围: -40° C ~ 85° C.
- 额定电压: 125V, AC.
- 接触电阻: ≤ 0.02 Ω.
- 绝缘电阻: ≥ 100M Ω.

序号	品名	材质
①	0.5 Pitch B型单槽 立式BTB公座胶芯	LCP UL94 V-0 颜色:米黄色
②	0.5 Pitch B型单槽 立式BTB公座端子	铜合金/表面镀锡/ 表面点镀金
③	0.5 Pitch B型单槽 立式BTB公座焊片	铜合金/表面镀锡

Part No	CKT	A	B	C	D	E
BTB0. 5-GH2. 6-10PBLT3	2X5	2.00	3.10	4.60	5.52	4.10
BTB0. 5-GH2. 6-12PBLT3	2X6	2.50	3.60	5.10	6.02	4.60
BTB0. 5-GH2. 6-14PBLT3	2X7	3.00	4.10	5.60	6.52	5.10
BTB0. 5-GH2. 6-16PBLT3	2X8	3.50	4.60	6.10	7.02	5.60
BTB0. 5-GH2. 6-18PBLT3	2X9	4.00	5.10	6.60	7.52	6.10
BTB0. 5-GH2. 6-20PBLT3	2X10	4.50	5.60	7.10	8.02	6.60
BTB0. 5-GH2. 6-22PBLT3	2X11	5.00	6.10	7.60	8.52	7.10
BTB0. 5-GH2. 6-24PBLT3	2X12	5.50	6.60	8.10	9.02	7.60
BTB0. 5-GH2. 6-26PBLT3	2X13	6.00	7.10	8.60	9.52	8.10
BTB0. 5-GH2. 6-28PBLT3	2X14	6.50	7.60	9.10	10.02	8.60
BTB0. 5-GH2. 6-30PBLT3	2X15	7.00	8.10	9.60	10.52	9.10
BTB0. 5-GH2. 6-32PBLT3	2X16	7.50	8.60	10.10	11.02	9.60
BTB0. 5-GH2. 6-34PBLT3	2X17	8.00	9.10	10.60	11.52	10.10
BTB0. 5-GH2. 6-36PBLT3	2X18	8.50	9.60	11.10	12.02	10.60
BTB0. 5-GH2. 6-38PBLT3	2X19	9.00	10.10	11.60	12.52	11.10
BTB0. 5-GH2. 6-40PBLT3	2X20	9.50	10.60	12.10	13.02	11.60
BTB0. 5-GH2. 6-44PBLT3	2X22	10.50	11.6	13.1	14.02	12.60
BTB0. 5-GH2. 6-50PBLT3	2X25	12.00	13.1	14.6	15.52	14.10
BTB0. 5-GH2. 6-60PBLT3	2X30	14.50	15.6	17.1	18.02	16.60
BTB0. 5-GH2. 6-70PBLT3	2X35	17.00	18.1	19.6	20.52	19.10
BTB0. 5-GH2. 6-80PBLT3	2X40	19.50	20.6	22.1	23.02	21.60

合高(H)	公座单高	母座单高	GENERAL TOLERANCES UNLESS SPECIFIED		深圳市华明通电子有限公司 Shenzhen Huamingtong Electronics Co., Ltd			
3.0	2.2	2.2	X. ± 0.50	± 1°	PART NO. BTB0.5-GH2.6-NPBLT3	TITLE: 0.5 Pitch B型单槽 立式BTB公座业务图(单高2.6)		
3.5	2.2	2.7	.X ± 0.20					
4.0	2.2	3.2	.XX ± 0.10					
5.0	2.6	4.4	MANUFACTURE DWG		DESIGN: James	CUSTOMER	SIZE	UNITS
					CHED: Talen		A4	MM
					APPD: Sophia		SCALE	SHEET
							N:A	1/1