


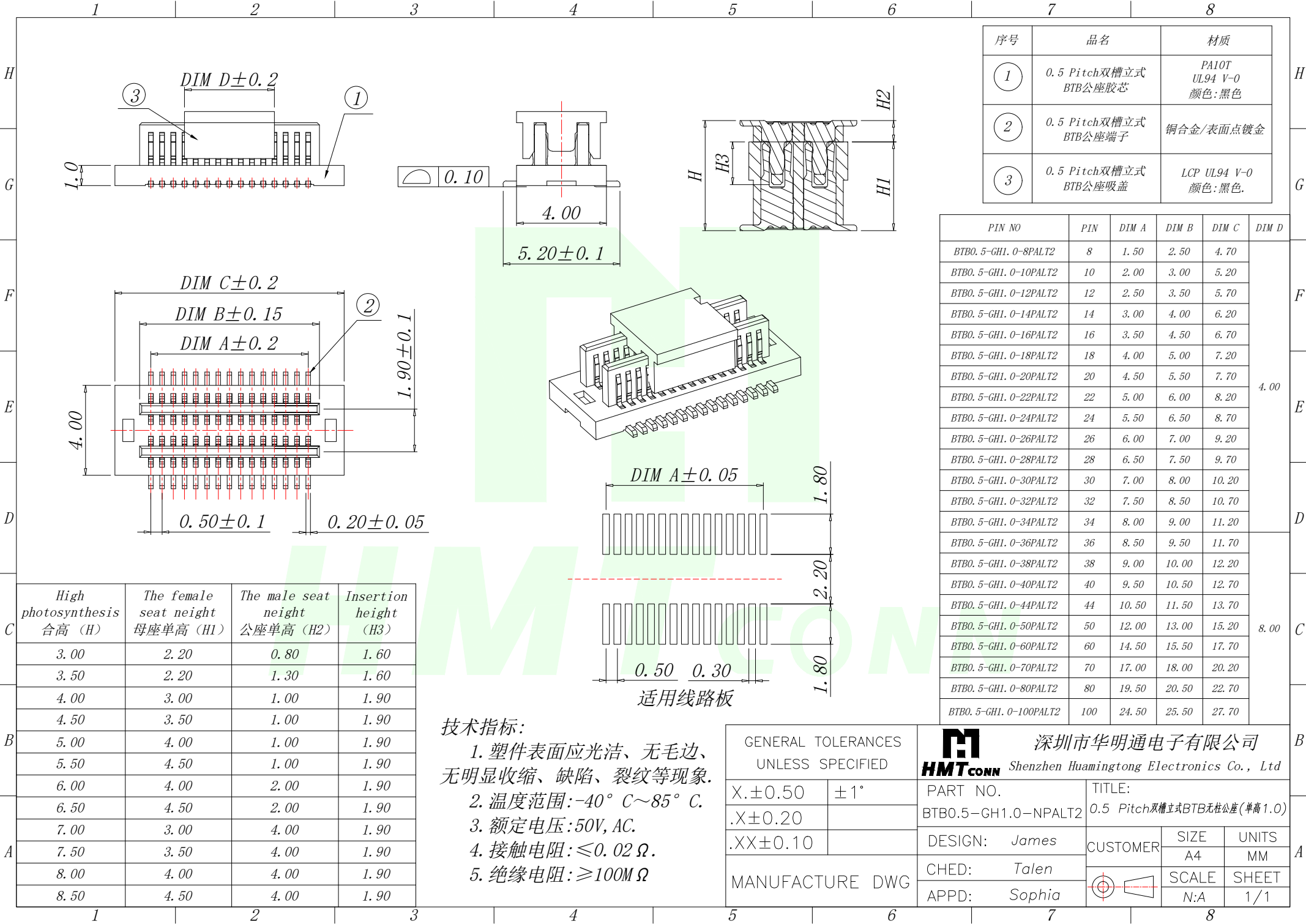

序号	品名	材质
1	0.5 Pitch双槽立式BTB公座胶芯	PA10T UL94 V-0 颜色:黑色
2	0.5 Pitch双槽立式BTB公座端子	铜合金/表面点镀金
3	0.5 Pitch双槽立式BTB公座吸盖	LCP UL94 V-0 颜色:黑色.

PIN NO	PIN	DIM A	DIM B	DIM C	DIM D
BTB0. 5-GH1. 0-8PALT2	8	1.50	2.50	4.70	4.00
BTB0. 5-GH1. 0-10PALT2	10	2.00	3.00	5.20	
BTB0. 5-GH1. 0-12PALT2	12	2.50	3.50	5.70	
BTB0. 5-GH1. 0-14PALT2	14	3.00	4.00	6.20	
BTB0. 5-GH1. 0-16PALT2	16	3.50	4.50	6.70	
BTB0. 5-GH1. 0-18PALT2	18	4.00	5.00	7.20	
BTB0. 5-GH1. 0-20PALT2	20	4.50	5.50	7.70	
BTB0. 5-GH1. 0-22PALT2	22	5.00	6.00	8.20	
BTB0. 5-GH1. 0-24PALT2	24	5.50	6.50	8.70	
BTB0. 5-GH1. 0-26PALT2	26	6.00	7.00	9.20	
BTB0. 5-GH1. 0-28PALT2	28	6.50	7.50	9.70	8.00
BTB0. 5-GH1. 0-30PALT2	30	7.00	8.00	10.20	
BTB0. 5-GH1. 0-32PALT2	32	7.50	8.50	10.70	
BTB0. 5-GH1. 0-34PALT2	34	8.00	9.00	11.20	
BTB0. 5-GH1. 0-36PALT2	36	8.50	9.50	11.70	
BTB0. 5-GH1. 0-38PALT2	38	9.00	10.00	12.20	
BTB0. 5-GH1. 0-40PALT2	40	9.50	10.50	12.70	
BTB0. 5-GH1. 0-44PALT2	44	10.50	11.50	13.70	
BTB0. 5-GH1. 0-50PALT2	50	12.00	13.00	15.20	
BTB0. 5-GH1. 0-60PALT2	60	14.50	15.50	17.70	
BTB0. 5-GH1. 0-70PALT2	70	17.00	18.00	20.20	
BTB0. 5-GH1. 0-80PALT2	80	19.50	20.50	22.70	
BTB0. 5-GH1. 0-100PALT2	100	24.50	25.50	27.70	

High photosynthesis 合高 (H)	The female seat neight 母座单高 (H1)	The male seat neight 公座单高 (H2)	Insertion height (H3)
3.00	2.20	0.80	1.60
3.50	2.20	1.30	1.60
4.00	3.00	1.00	1.90
4.50	3.50	1.00	1.90
5.00	4.00	1.00	1.90
5.50	4.50	1.00	1.90
6.00	4.00	2.00	1.90
6.50	4.50	2.00	1.90
7.00	3.00	4.00	1.90
7.50	3.50	4.00	1.90
8.00	4.00	4.00	1.90
8.50	4.50	4.00	1.90

- 技术指标:
- 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象.
 - 温度范围: -40° C~85° C.
 - 额定电压: 50V, AC.
 - 接触电阻: $\leq 0.02 \Omega$.
 - 绝缘电阻: $\geq 100M \Omega$

GENERAL TOLERANCES UNLESS SPECIFIED		HMTCONN 深圳市华明通电子有限公司 Shenzhen Huamingtong Electronics Co., Ltd			
X.±0.50	±1°	PART NO.	TITLE:		
.X±0.20		BTB0.5—GH1.0—NPALT2	0.5 Pitch双槽立式BTB无柱公座(单高1.0)		
.XX±0.10		DESIGN: James	CUSTOMER	SIZE	UNITS
MANUFACTURE DWG		CHED: Talen		A4	MM
		APPD: Sophia		SCALE	SHEET
				N:A	1/1