

Specification

Insulator Material: Polysetr,UL94V-0

Standard:PA6T

Contact Material: Brass

Contact plated: Gold Over Nickel

Poles:2~40P



Current Rating : 3Amp

Contact Resistance:20 Milliohms Max

Insulation Resistace : 1000MΩ Min.

Dielectric withstanding Voltage:AC 500V

Operation Temperature : -40℃ -- +105℃

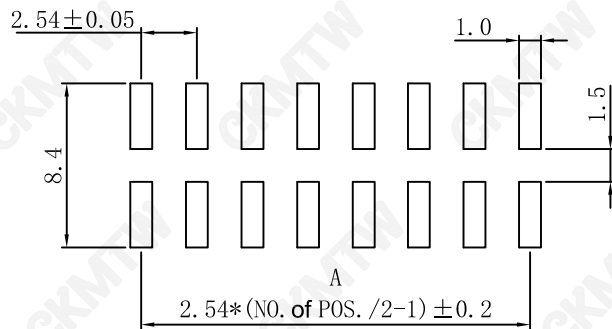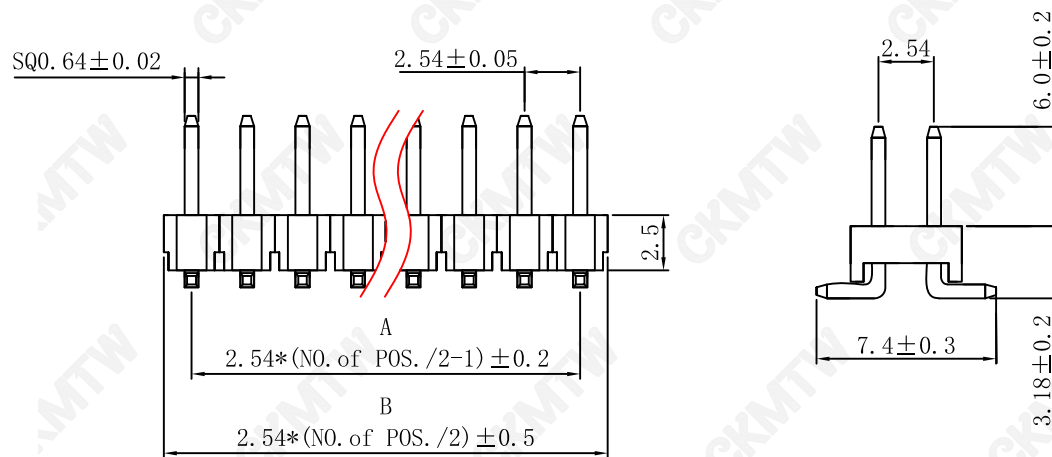

P. C. B. LAYOUT

Poles	PART NO.	Dimension mm	
		A	B
2*2	B-2100N04P-B211	2.54	5.08
2*3	B-2100N06P-B211	5.08	7.62
2*4	B-2100N08P-B211	7.62	10.16
2*5	B-2100N10P-B211	10.16	12.70
2*6	B-2100N12P-B211	12.70	15.24
2*7	B-2100N14P-B211	15.24	17.78
2*8	B-2100N16P-B211	17.78	20.32
2*9	B-2100N18P-B211	20.32	22.86
2*10	B-2100N20P-B211	22.86	25.40
...	...	...	...
2*40	B-2100N80P-B211	99.06	101.60

未注公差表	
X. X	±0.2
X. XX	±0.15
X. XXX	±0.05

核准:	日期:	深圳市灿科盟实业有限公司 Ckmtw CHANKLEMENT INDUSTRYCO., LTD			
业务:	日期:	品名规格: 210SMT-2*XP W=7.4mm 塑高2.5 PA:6.0, PB:3.18			
制图: LYF	日期: 2024-08-07	客户料号		B-2100NXXP-B211	
		单位	mm	比例	/
		图纸编号:		Ckmtw-210-0010	版本 A