

邀您使用(微信)小程序

硕方电子开关&连接器选型手册

手机扫码即可进入...

LTEM NO.:MC-306FD (Series)

(L7.85×W10.00×H4.65 2.0-USB-CONNECTORS)

表面贴装 SMT

側向操作 LATERAL

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS


Technical parameter

LEVEL		A[better product]		B[average product]	
PROJECT					
Electrical Properties	Contact Rating	3.0A, 100V AC			
	Initial Contact Resistance	100mΩ max.			
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC		
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut		
	There No Load	6,000 Cycles	5,000 Cycles		
Durable Performance	Rated Load	5,000 Cycles	4,000 Cycles		
	Storage temp.	-35℃～+75℃(Operating Temp:)			
Operating Force		IF:10. ON MAX. (EF:10. ON MIN.)			
Heat Rrsistance		IR Reflow:255℃,5sec. Manual:350℃,3sec.			

Unit:mm

No.	NAME	Description
①	Molding 包胶	LCP 30%(Gray) 耐热塑胶 UL94V-0
②	Glue(防水)涂层	液态 (HF)环氧橡胶[Black]
③	插件端子	不锈钢 SUS304R-3/4H t=0. 20mm
④	接触端子	磷铜 C5191(镀金 1u" /焊尾雾锡)
⑤	Shell 外壳	不锈钢 SUS304R-3/4H t= 0. 30mm
⑥	Body 胶芯	LCP 30%(Gray) 耐热塑胶 UL94V-0
⑦	METAL COVER	STAINLESS STEEL (t=0. 20mm)
⑧	Oval ring 圆环	软橡胶 Rubber

圆形防水环推荐尺寸

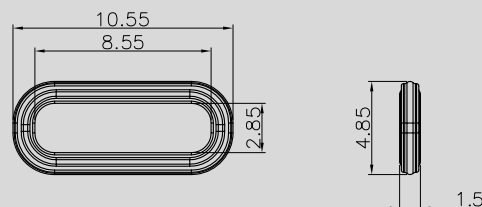

PIN	Signal NAME	PIN	Signal NAME
A 5	CC1	B 5	CC2
A 9	V BUS	B 9	V BUS
A12	GND	B12	GND

