


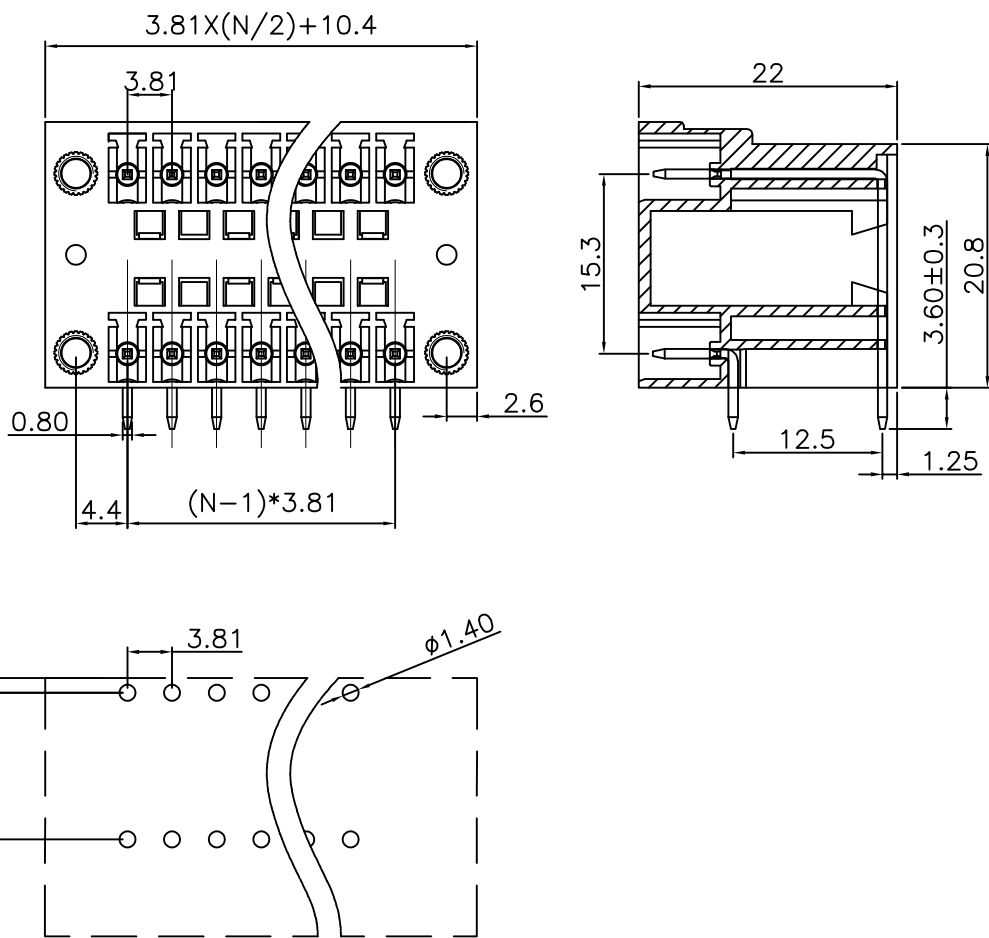

- 材质及电镀(Material)
焊针(Pin header):铜合金, 镀锡(Brass, Tin plated)
塑件(Housing): PA66, UL94V-0
- 电气性能(Electrical)
额定电压(Rated Voltage): 300V
额定电流(Rated Corrent): 8A
绝缘电阻(Insulation Resistance): 5000MΩ/1000V
耐电压(Withstanding Voltage): AC1500V/1Min
- 机械性能(Mechanical)
温度范围(Temperature Range): -40℃~ +105℃
瞬时温度(MAX Soldering): +250℃, 5秒(5 Seconds)

订购方式(HOW TO ORDER)
MX15EDGRHM - 3.81-□□P-□ - □ - □□□□

型号	间距	极数	客户型号
Series NO.	Pitch	Poles	Customer Request

颜色(Color)
1. 灰色(Gray) 2. 蓝色(Blue)
3. 黑色(Black) 4. 绿色(Green)
5. 橙色(Orange) 6. 红色(Red)
7. 黄色(Yellow) 8. 白色(White)
9. 透明(Transparent)

公差一览表				安徽亿思特电子科技有限公司				
TOLERANCE UNLESS OTHERWISE				ANHUI EAST ELECTRONIC TECHNOLOGY CO.,LTD				
X.	±0.25	X°.	±5°	单位	mm	制图	产品名称	MX15EDGRHM-3.81-XXP-1X
.X	±0.20	.X°	±2°	角法	VIEW	设计	设计	
.XX	±0.15	.XX°	±1°	比例	SCALE	审核	产品料号	
.XXX	±0.02	.XXX°	±0.5°	日期	DATE	核准	图号	
2	(Contact)触点	(Copper alloy)铜合金	(Sn plated)镀锡	2026.08.05	版本	A0	APPD	MX15EDGRHM38100A
1	(Housing)塑件	PA66	UL94V-0					
ITEM	NAME OF PART	MATERIAL	NOTES					