

Operation: DIP/卧插式导边

3.0USB 连接器 (Type-A)



LTEM NO.:U30-01E (Series)

(L16.5×W13.1×H7.0 3.0-USB-CONNECTORS)

表面插装 DIP

侧向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

Technical parameter

LEVEL		A[better product]	B[average product]
PROJECT			
Electrical Properties	Contact Rating	0.25A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
Durable Performance	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-40℃~+85℃(Operating Temp:)	
Operating Force		IF:20N MAX. (EF:10.0N MIN.)	
Heat Rrsistance		IR Reflow:235℃, 5sec. Manual:350℃, 3sec.	



邀您使用(微信)小程序
硕方电子开关&连接器选型手册
手机扫码即可进入...






Material declaration

No.	NAME	Description
① A	胶芯	PBT 耐热塑胶[Blue]
② B	胶体	PBT 耐热塑胶[Blue]
③ ④	接触端子	磷铜 C5191 (镀金 1u" /焊尾雾锡)
⑤ E	外壳	黄铜 C2680/SPCC[镀镍 50u" min]

PIN SIGNAL

1	V BUS+	Power
2	Data-	USB2.0 differential pair
3	Data+	USB2.0 differential pair
4	GND	Ground for power return
5	SSRXM-	SuperSpeed Receiver differential pair
6	SSRX+	SuperSpeed Receiver differential pair
7	GND	Ground for power return
8	SSTXM-	SuperSpeed Transmitter differential pair
9	SSTXP+	SuperSpeed Transmitter differential pair

Unit:mm

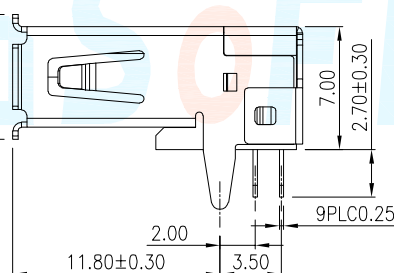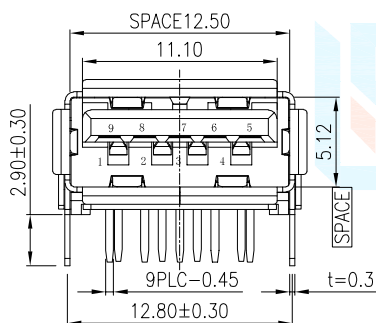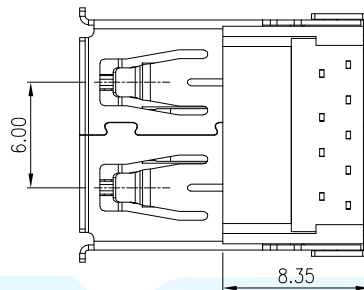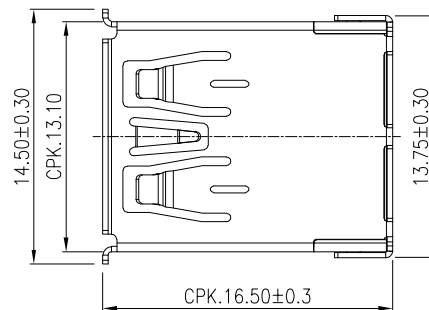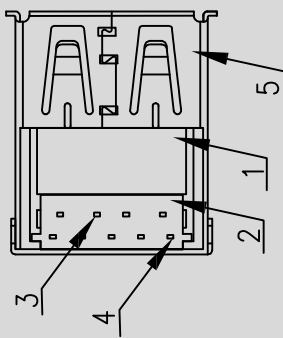

P.C.B LAYOUT

