



邀您使用(微信)小程序

硕方电子开关&连接器选型手册

手机扫码即可进入...

Technical parameter

LEVEL		A[better product]		B[average product]		
PROJECT						
Properties	Contact Rating	3.0A, 100V AC				
	Electrical Initial Contact Resistance	100mΩ max.				
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC			
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut			
	Durable Performance	There No Load	6,000 Cycles	5,000 Cycles		
		Rated Load	5,000 Cycles	4,000 Cycles		
	Storage temp.	-35℃～+75℃(Operating Temp:)				
Operating Force	IF:10.ON MAX.(EF:10.ON MIN.)					
Heat Rrsistance	IR Reflow:255℃,5sec. Manual:350℃,3sec.					

Type-C(PD)快充连接器

LTEM NO.:MC-306C-08 (Series)

(L6.5×W8.95×H3.15 TYPE C-CONNECTORS)

沉板贴装 SMT


側向操作 LATERAL

精密部品 NICETY




可靠 STABILIZE

適合環保 RoHS


CIRCUIT DIAGRAM

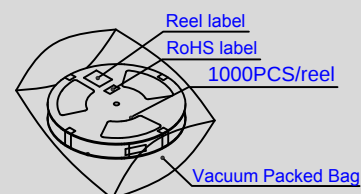

Unit:mm

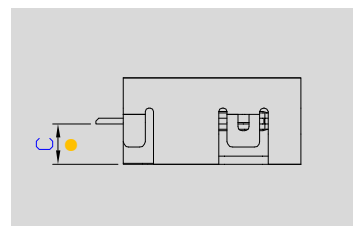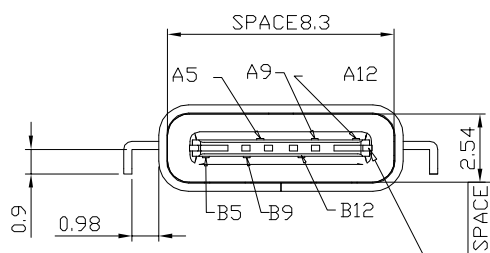 

□(尾编)	沉板高度
C15	1.5mm
C12	1.2mm
● C08	0.8mm

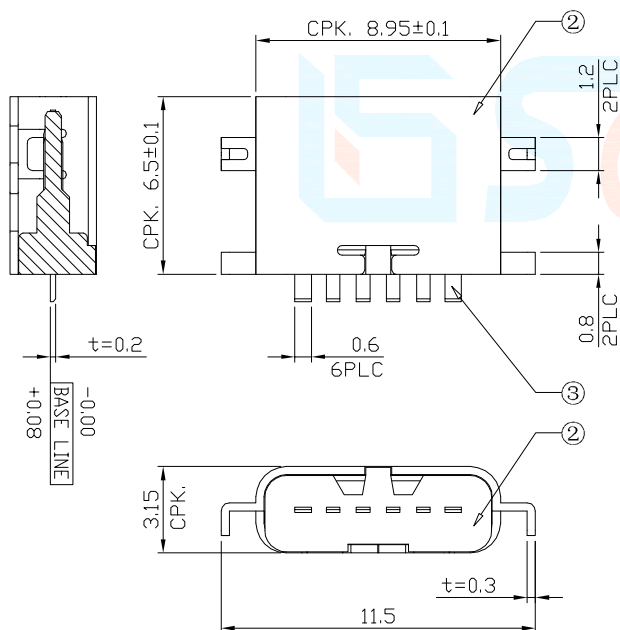

PIN	Signal NAME	PIN	Signal NAME
A 5	CC1	B 5	CC2
A 9	V BUS	B 9	V BUS
A12	GND	B12	GND

