




ITEM NO.:USB-07X 反向沉板式焊板公头

(L18.8×W12.0×H4.0mm 2.0-USB-CONNECTORS)

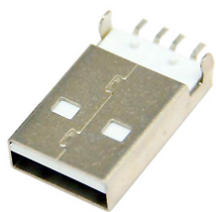

Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	25mA, 24V DC	
	Initial Contact Resistance	30mΩ max.	50mΩ max.
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	6,000 Cycles	5,000 Cycles
Durable Performance	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-25℃~+75℃(Operating Temp:)	

卧式插装 SMT+DIP

 

側向導入 LATERAL

精密部品 NICETY


可靠 STABILIZE

適合環保 RoHS

Unit:mm

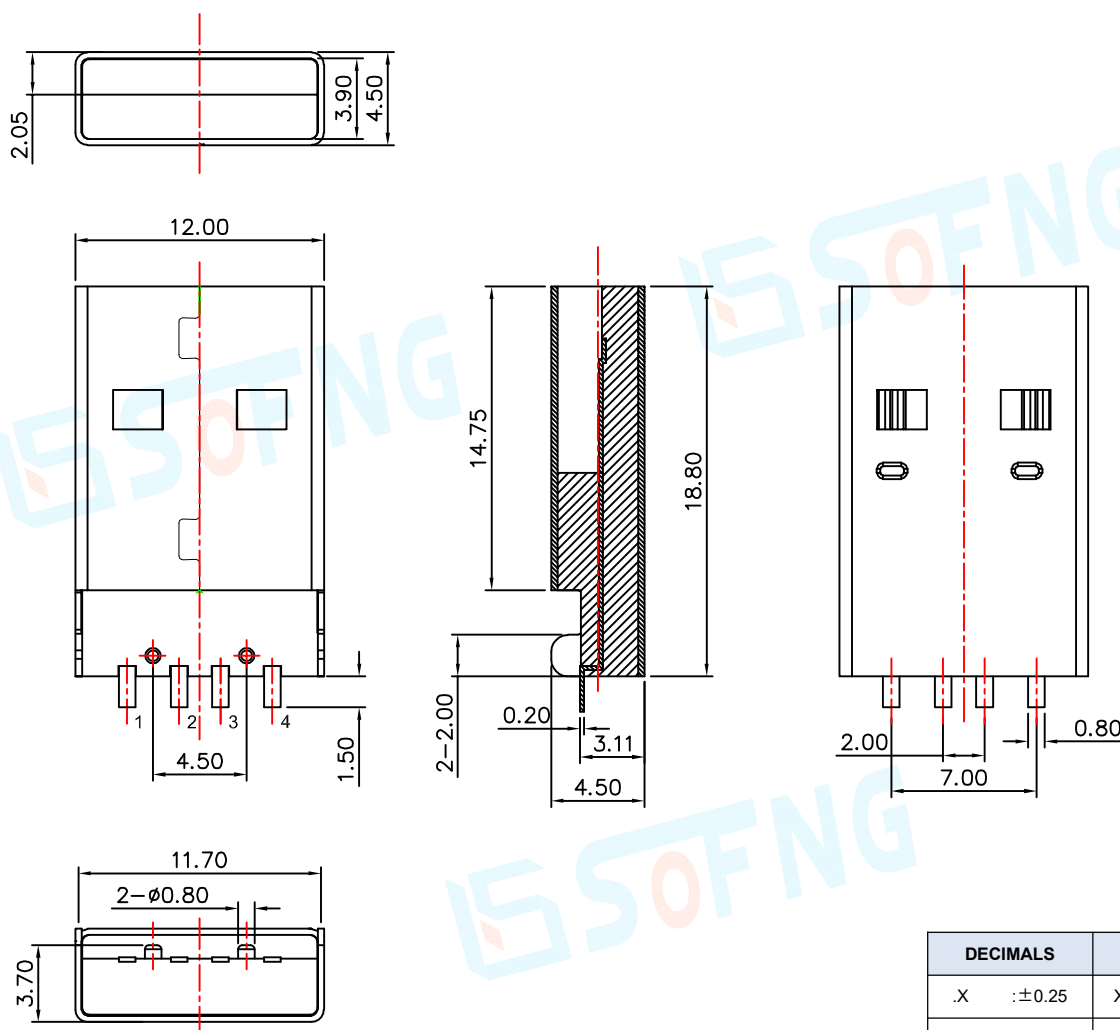

DECIMALS	ANGLES
.X :±0.25	X.° :±1.5°
.XX :±0.15	X.X° :±1.0°
.XXX :±0.10	.XXX° :±0.5°

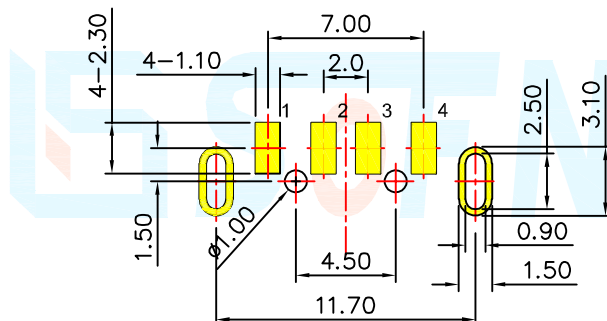

Pin Definition



Material declaration

No.	NAME	Type	Description
① A	胶芯	1	PBT 耐热塑胶[白色] / PA6T 尼龙
② B	接触端子	4	磷铜 C5191 (镀金 1u" / 焊区雾锡)
③ C	外壳	1	SPCC[电镀 50u" min]

PIN SIGNAL

1	VCC	+5V
2	-DATA 0	Neagative Data Channel 0
3	+DATA 0	Positive Data Channel 0
4	GND	Ground



邀您使用(微信)小程序
硕方电子开关&连接器选型手册
手机扫码即可进入...



本品不屬於危害性廢棄物，須丟棄時可以委託
回收商予以回收再生處理。

Products do not belong to •

注記 NOTICE

1. 碩方公司擁有最終解釋權；The company reserves the right of final interpretation;
2. 文件禁止外洩、轉載；Leaked and reproduced prohibited;
3. 未經授權修改無效。Modify is invalid.

運送時本產品不要直接與水、酸鹼性化學物質接觸,或放置於含有以上氣體環境中,並且需要注意會有滑落、側翻的危險發生;運輸過程中不能有碰撞或者擠壓,須保證溫度與濕度適中[常溫 25℃,濕度在 50℃ 以內],不可導致材料變形或氧化。