

Operation: 2.0 Universal Serial Bus Connectors



LTEM NO.:USB-324D 側立式

(L19.5×W5.7×H13.6mm -USB-CONNECTORS)



Technical parameter

LEVEL		A[better product]		B[average product]	
PROJECT					
Electrical Properties	Contact Rating	25mA, 24V DC			
	Initial Contact Resistance	30mΩ max.		50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC		Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage	500V AC for 1 minute		350 V AC for 1 minut	
	There No Load	6,000 Cycles		5,000 Cycles	
	Rated Load	5,000 Cycles		4,000 Cycles	
	Storage temp.	-25℃～+75℃(Operating Temp:)			

側立插装 DIP


側向導入 LATERAL


精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

Unit:mm

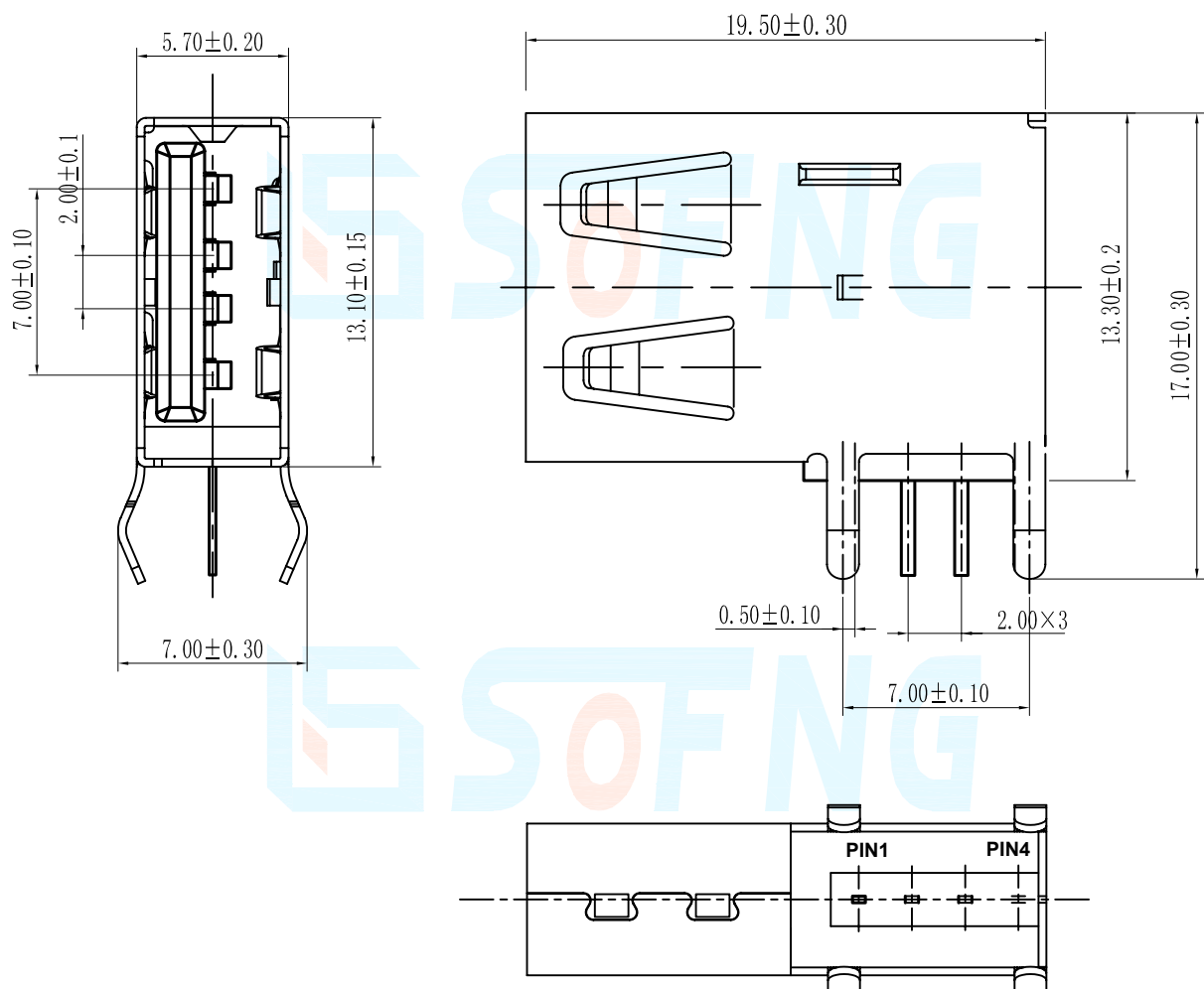

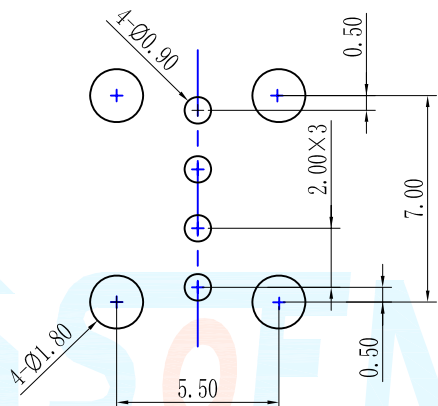

Pin Definition



Material declaration

No.	NAME	Type	Description
① A	胶芯	1	LCP 热塑性[Black]
② B	接触端子	4	磷铜 C5191 (镀金 1u" /焊区雾锡)
③ C	外壳	1	黄铜 C2680/SPCC [镀镍 50u" min]



邀您使用(微信)小程序

硕方电子开关&连接器选型手册

手机扫码即可进入...



本品不屬於危害性廢棄物,須丟棄時可以委託
回收商予以回收再生處理。
Products do not belong to •

注記 NOTICE

- 碩方公司擁有最終解釋權; The company reserves the right of final interpretation;
- 文件禁止外洩、轉載; Leaked and reproduced prohibited;
- 未經授權修改無效。Modify is invalid.

運送時本產品不要直接與水、酸鹼性化學物質
接觸,或放置於含有以上氣體環境中,並且需要
注意會有滑落、側翻的危險發生; 運輸過程中
不能有碰撞或者擠壓,須保證溫度與濕度適中
[常溫 25℃,濕度在 50℃以內],不可導致材料變
形或氧化。