

Operation: SMT/卧贴式 全铜(耐高温)无导边-2.0USB 连接器



ITEM NO.: USB-302SD-Y1 (Series)

(L14.0×W13.1×H6.9 2.0-USB-CONNECTORS)

表面贴装 SMT

侧向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

Technical parameter

		LEVEL			
PROJECT		A[better product]		B[average product]	
Electrical Properties	Contact Rating	0.25A, 24V DC			
	Initial Contact Resistance	50mΩ max.			
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC		
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut		
	There No Load	6,000 Cycles	5,000 Cycles		
	Rated Load	5,000 Cycles	4,000 Cycles		
	Storage temp.	-35℃~+75℃(Operating Temp:)			
	Operating Force	IF:20N MAX. (EF:10.0N MIN.)			
	Heat Rrsistance	IR Reflow:255℃, 5sec. Manual:350℃, 3sec.			




Material declaration

No.	NAME	Description
① A	外壳	黄铜 C2680/SPCC[镀镍 50u" min]
② B	胶芯	LCP 30% UL94V-0 耐热塑胶
③ C	接触端子	磷铜 C5191(镀金 1u" /焊尾雾锡)

PIN SIGNAL

1	VCC	+5V
2	-DATA 0	Neagative Data Channel 0
3	+DATA 0	Positive Data Channel 0
4	GND	Ground





Unit:mm

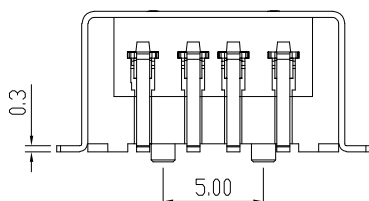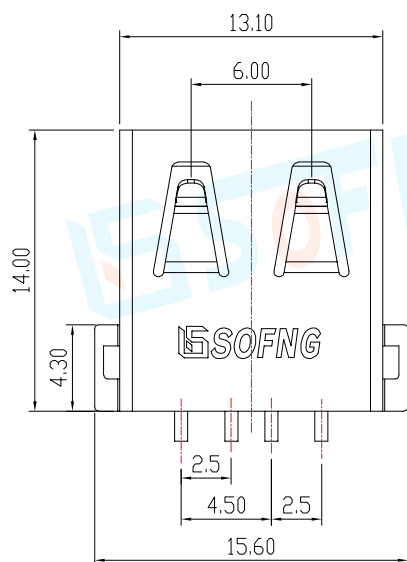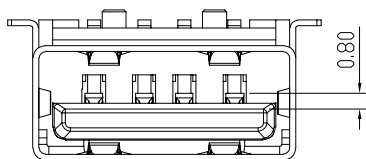

邀您使用(微信)小程序

碩方电子开关&连接器选型手册

 手机扫码即可进入...

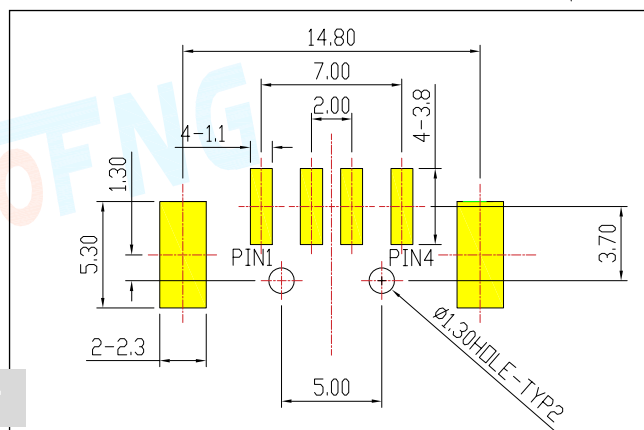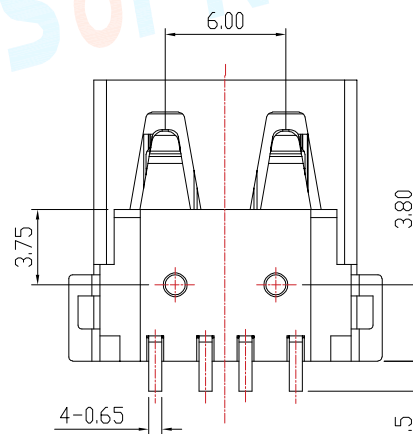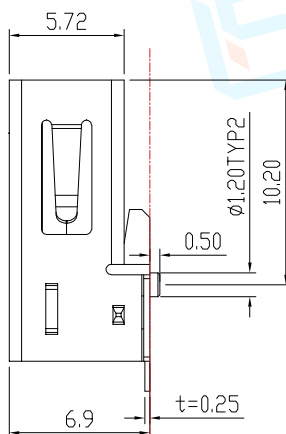

P.C.B LAYOUT