


NO.	ECN NO.	DESCRIPTION	DATE

客户图

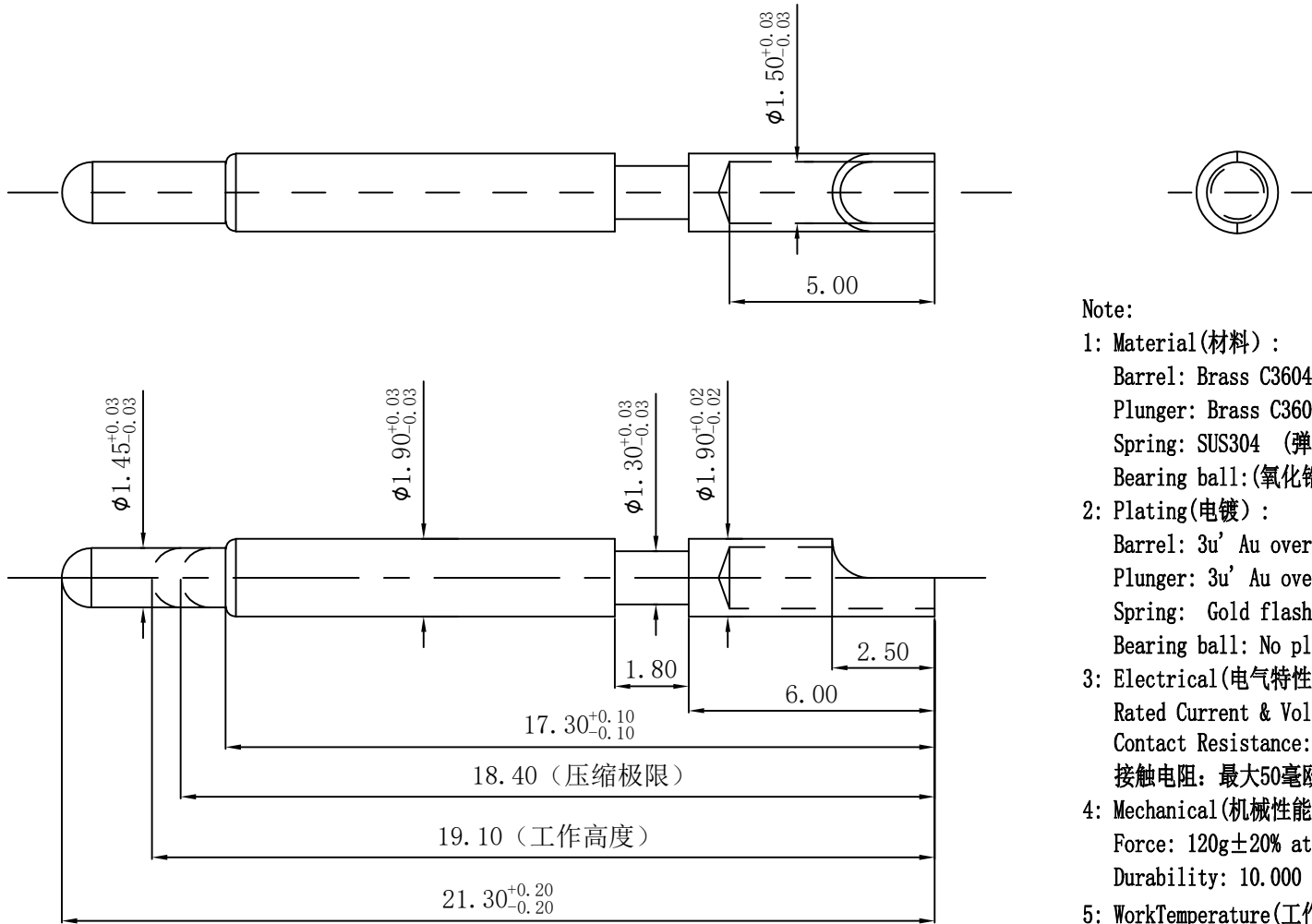

- Note:
- Material(材料) :
 Barrel: Brass C3604 (针管: 黄铜 C3604)
 Plunger: Brass C3604 (针头: 黄铜 C3604)
 Spring: SUS304 (弹簧: SUS304)
 Bearing ball: (氧化锆陶瓷珠 ϕ 1.5)
 - Plating(电镀) :
 Barrel: 3u' Au over 50~80u' Ni (针管: 镀金3u', 镍底50~80u'.)
 Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u'.)
 Spring: Gold flash (弹簧: 电镀1u')
 Bearing ball: No plated. (氧化锆陶瓷珠: 不电镀)
 - Electrical(电气特性) :
 Rated Current & Voltage: DC 12V;8A (额定电压&电流: 直流12V, 8A)
 Contact Resistance: 50 mohm Max. at working height.
 接触电阻: 最大50毫欧 (在工作高度状态下)
 - Mechanical(机械性能) :
 Force: 120g $\pm$ 20% at working height. (120g $\pm$ 20% 在工作高度).
 Durability: 10.000 cycles(min) (寿命: 10000次)
 - WorkTemperature(工作环境):
 Withstanding Higt Temperature: 280 $^{\circ}$ C
 Operational Temperature: - 40 $^{\circ}$ C~ + 85 $^{\circ}$ C

深圳市鑫扬泽电子有限公司

[HTTP://WWW.XYZPOGOPIN.COM](http://www.xyzpogopin.com)
 TEL:0755-28773277 FAX:0755-28891353



SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	
DATE:	2023.8.25	VER.	A.0

THE UNMARKED TOLERANCE ARE AS BELOW :				DESIGNED BY:		DWG. NO.	YZG0030-19213-01
LENGTH		ANGLE		CHECKED BY:		TITLE:	pogo pin
X.XX	$\pm$ 0.05mm	X.XX	$\pm$ 0.50'	APPROVED BY:			
X.X	$\pm$ 0.10mm	X.X	$\pm$ 1.00'				
X.	$\pm$ 0.20mm	X.	$\pm$ 2.00'				