


客户图纸

NO.	ECN NO.	DESCRIPTION	DATE
1			

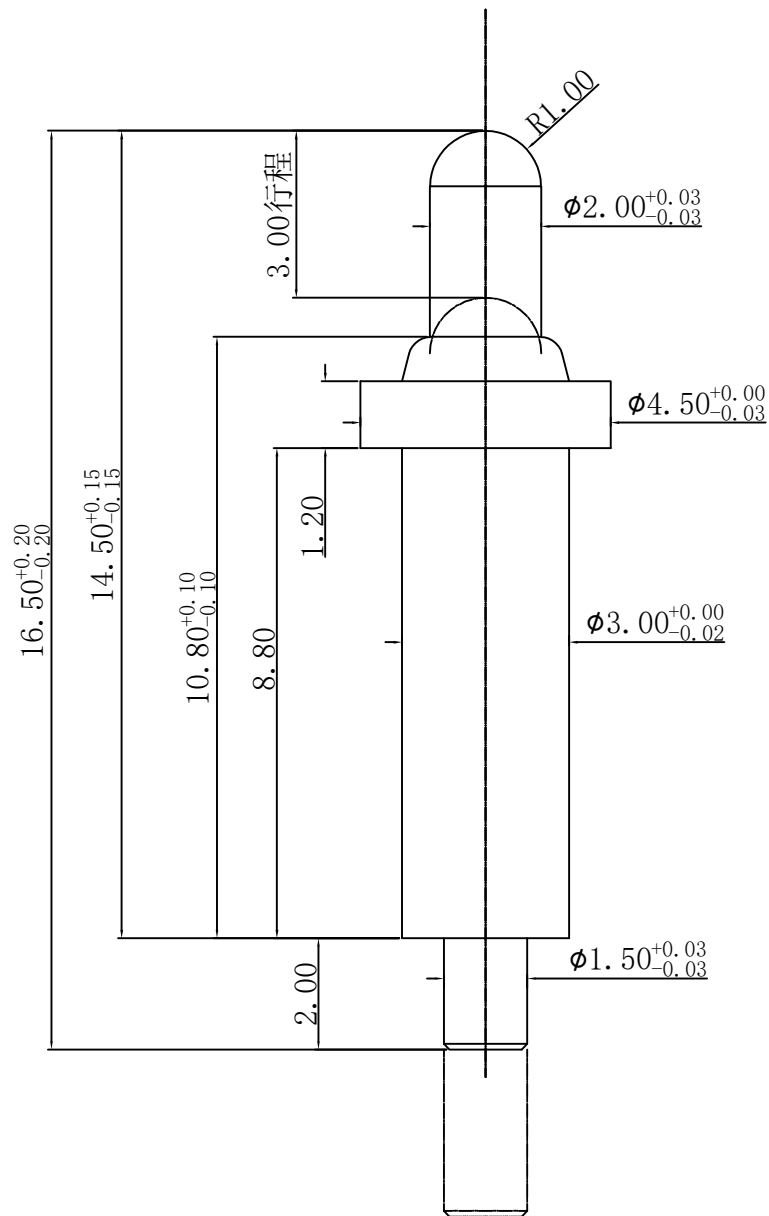

Note:

1: Material(材料):

Barrel: Brass C3604 (针管: 黄铜 C3604)

Plunger: Brass C3604 (针头: 黄铜 C3604)

Spring: SUS304 (弹簧: SUS304)

2: Plating(电镀):

Barrel: 5u' Au over 100~150u' Ni (针管: 镀金5u', 镍底100~150u'.)

Plunger: 5u' Au over 100~150u' Ni (针头: 镀金5u', 镍底100~150u'.)

Spring: Gold plated (弹簧: 镀金)

3: Electrical(电气特性):

Rated Current & Voltage: DC 12V;8A (额定电压&电流: 直流12V, 8A)

Contact Resistance: 50 mohm Max. at working height.

接触电阻: 最大50毫欧 (在工作高度状态下)

4: Mechanical(机械性能):

Force: 160g±20% at working height. (160g±20% 在工作高度)。

Durability: 10.000 cycles(min) (寿命: 10000次)

5: WorkTemperture(工作环境):

Withstanding Higt Temperature: 280℃

Operational Temperature: - 20℃~ + 70℃

深圳市鑫扬泽电子有限公司

HTTP://WWW.XYZPOGOPIN.COM

TEL:0755-28773277 FAX:0755-28891353



SCALE:	N/A	UNIT	mm	THE UNMARKED TOLERANCE ARE AS BELOW :		DESIGNED BY:		DWG. NO.	YZP0764-45165-02
SHEET:	1 of 1	PROJECTION				CHECKED BY:		TITLE:	Pogo pin 连接器
DATE:	2023.2.25	VER.	A.1	LENGTH	ANGLE	APPROVED BY:			
				X.XX ±0.05mm X.X ±0.10mm X. ±0.20mm	X.XX ±0.50° X.X ±1.00° X. ±2.00°				