


客户图

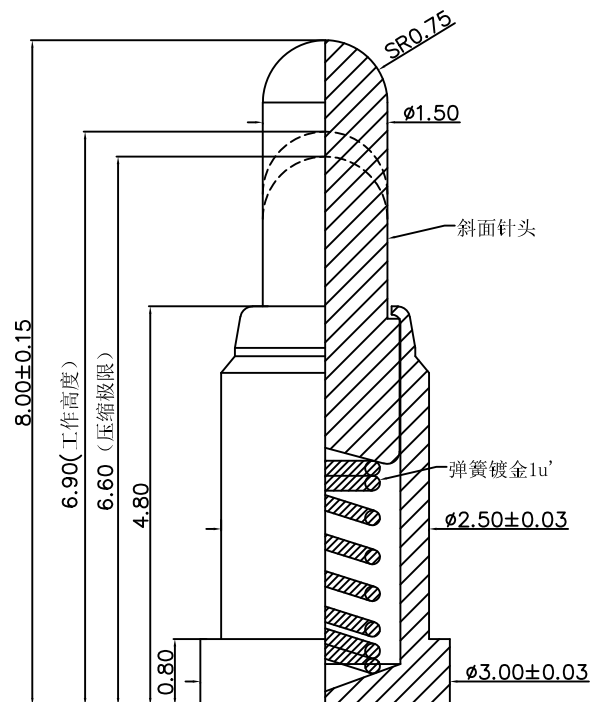

NO.	ECN NO.	DESCRIPTION	DATE

Note:

- Material (材料):
 Barrel: Brass C3604 (针管: C3604)
 Plunger: Brass C3604 (针管: C3604)
 Spring: SUS304 (弹簧: SUS304)
- Plating (电镀):
 Barrel: 3u' Au over 50~80u' Ni (针管: 镀金3u', 镍底50~80u'.)
 Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u'.)
 Spring: Gold flash (弹簧: 电镀1u')
- Electrical (电气特性):
 Rated Current & Voltage: DC 12V;2A (额定电压&电流: 直流12V, 2A)
 Contact Resistance: 50 mohm Max. at working height.
 接触电阻: 最大50毫欧 (在工作高度状态下)
- Mechanical (机械性能):
 Force: 250g ± 20% at working height. (250g ± 20% 在工作高度)。
 Durability: 10,000 cycles (min) (寿命: 10,000次)
- Work Temperature (工作环境):
 Withstanding High Temperature: 280°C
 Operational Temperature: - 20°C ~ + 70°C

深圳市鑫扬泽电子有限公司

HTTP://WWW.XYZPOGOPIN.COM

TEL: 0755-28773277 FAX: 0755-28891353



SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	
DATE:	2021.11.25	VER.	D.0

THE UNMARKED TOLERANCE ARE AS BELOW :

LENGTH	ANGLE
X.XX ± 0.05mm	X.XX ± 0.50°
X.X ± 0.10mm	X.X ± 1.00°
X. ± 0.20mm	X. ± 2.00°

DESIGNED BY:		DWG. NO.	YZR0171-30080-01
CHECKED BY:		TITLE:	Pogo pin连接器
APPROVED BY:			