


客户图纸

NO.	ECN NO.	DESCRIPTION	DATE

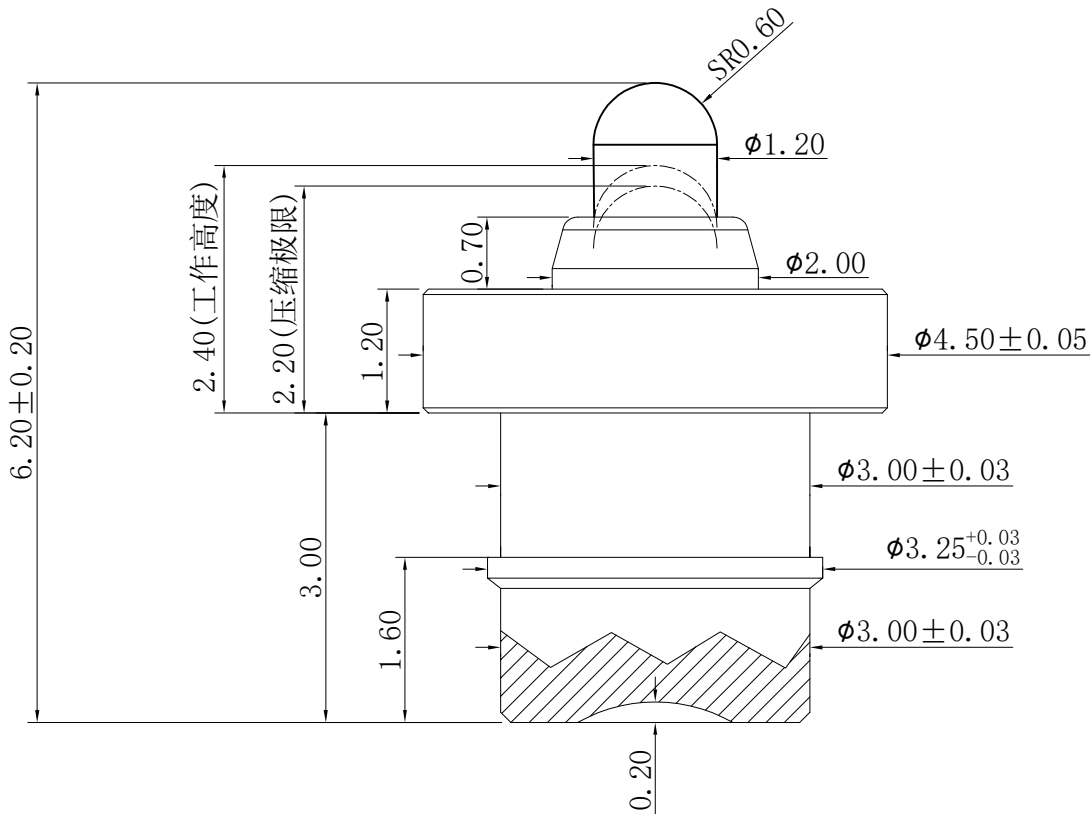

- Note:
- 1: Material(材料) :
Barrel: lead-free Brass (C6801) (针管: 无铅铜 C6801)
Plunger: lead-free Brass (C6801) (针头: 无铅铜 C6801)
Spring: SUS304 (弹簧: SUS304)
- 2: Plating(电镀) :
Barrel: 3u' Au over 50~80u' Ni (针管: 镀金3u', 镍底50~80u'.)
Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u'.)
Spring: Gold flash (弹簧: 电镀1u')
- 3: Electrical(电气特性) :
Rated Current & Voltage: DC 15V;3A (额定电压&电流: 直流15V, 3A)
Contact Resistance: 50 mohm Max. at working height.
接触电阻: 最大50毫欧 (在工作高度状态下)
- 4: Mechanical(机械性能) :
Force: 100g ± 20% at working height. (100g ± 20% 在工作高度)。
Durability: 10.000 cycles(min) (寿命: 10000次)
- 5: WorkTemperature(工作环境):
Withstanding Higt Temperature: 280℃
Operational Temperature: - 20℃ ~ + 70℃

深圳市鑫扬泽电子有限公司



HTTP://WWW.XYZPOGOPIN.COM
TEL:0755-28773277 FAX:0755-28891353

SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	
DATE:	2023.3.11	VER.	A.1

THE UNMARKED TOLERANCE ARE AS BELOW :			
LENGTH		ANGLE	
X.XX	±0.05mm	X.XX	±0.50°
X.X	±0.10mm	X.X	±1.00°
X.	±0.20mm	X.	±2.00°

DESIGNED BY:		DWG. NO.	YZP0624-45062-02
CHECKED BY:		TITLE:	Pogo pin 连接器
APPROVED BY:			