


客户图

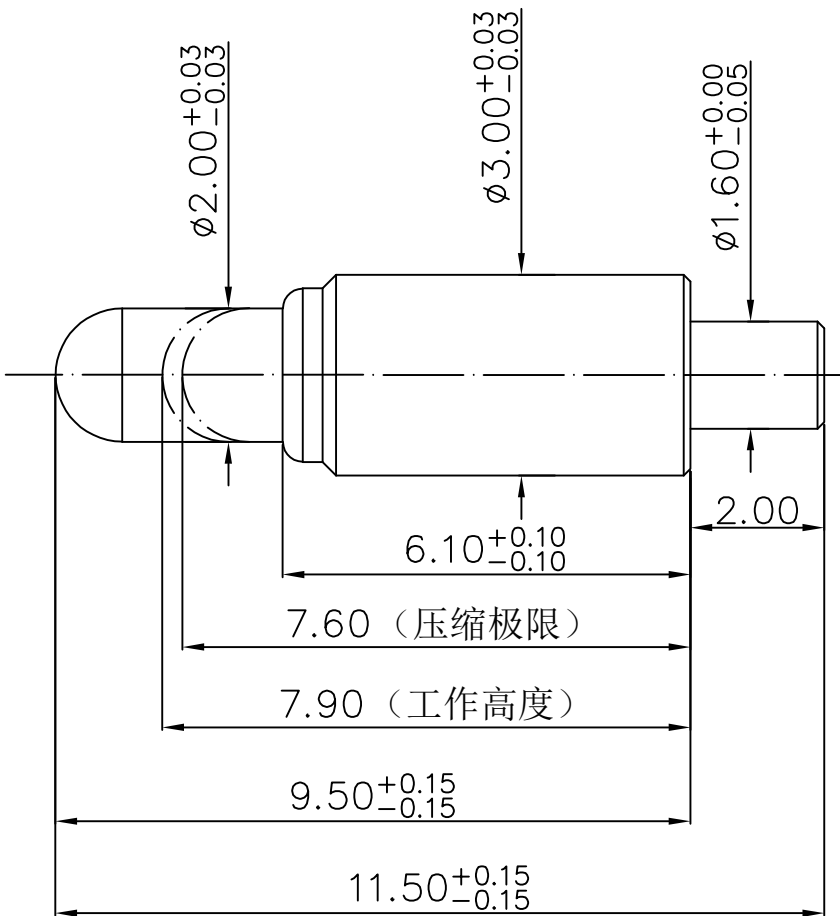

Note:

- Material (材料):
 - Barrel: Brass C6801 (针管: 无铅铜 C6801)
 - Plunger: Brass C6801 (针头: 无铅铜 C6801)
 - Spring: SUS304 (弹簧: SUS304)
- Plating (电镀):
 - Barrel: 5u' Au over 200u' Cu over 200u' Ni (针管: 镀金5u', 铜底200u', 镍底200u'.)
 - Plunger: 5u' Au over 200u' Cu over 200u' Ni (针头: 镀金5u', 铜底200u', 镍底200u'.)
 - Spring: Gold plated (弹簧: 镀金)
- Electrical (电气特性):
 - Rated Current & Voltage: DC 12V; 3A (额定电压&电流: 直流12V, 3A)
 - Contact Resistance: 50 mohm Max. at working height. (接触电阻: 最大50毫欧 (在工作高度状态下))
 - Insulation Resistance: 1,000M Ω minimum. (绝缘电阻: 1,000M Ω 以上)
 - Dielectric Withstand Voltage: 500VAC/minute. (抗击电压: 500VAC/minute)
- Mechanical (机械性能):
 - Force: 260g $\pm$ 20% at working height. (260g $\pm$ 20% 在工作高度)。
 - Durability: 10,000 cycles(min) (寿命: 10000次)
- Work Temperature (工作环境):
 - Withstanding High Temperature: 280 $^{\circ}$ C
 - Operational Temperature: -20 $^{\circ}$ C ~ +70 $^{\circ}$ C

深圳市鑫探技术有限公司

HTTP://WWW.XYZPOGOPIN.COM

TEL: 0755-28773277 FAX: 0755-28891353



SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	
DATE:	2024.9.12	VER.	A.0

THE UNMARKED TOLERANCE ARE AS BELOW :

LENGTH		ANGLE	
X.XX	± 0.05 mm	X.XX	$\pm 0.50^{\circ}$
X.X	± 0.10 mm	X.X	$\pm 1.00^{\circ}$
X.	± 0.20 mm	X.	$\pm 2.00^{\circ}$

DESIGNED BY:		DWG. NO.	YZP0797-30115-01
CHECKED BY:		TITLE:	Pogo pin 连接器
APPROVED BY:			