



CHIP COMMON MODE CHOKE


High Common Mode Impedance at High Frequency. Excellent Noise Suppression Performance.
Small Size and Low Profile, Surface Mount Type. Operating Temperature Range: -40 °C to +105 °C, 70%RH max
RoHS Compliant.



Electrical Specifications @25°C


Part Number	Common mode Impedance (ohm $\pm 25\%$ @100M)	DCR		Rated Current (A Max)	Rated Volt (Vdc)Max	IR (MΩ Min)
		(mΩ typ.)	(mΩ Max)			
ACP3225-102-2P-T000 T-CND	1000	50	100	1.5	50	10
ACP3225-501-2P-T000 T-CND	500	40	100	2	50	10
ACP3225-101-2P-T000 T-CND	100	15	100	1	50	10

MECHANICAL

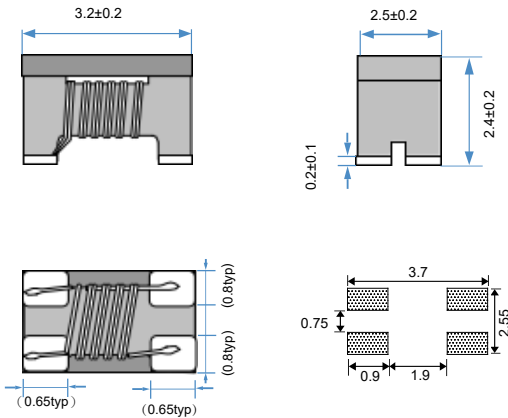


Unless otherwise specified all tolerances are: ±0.25mm

TAPING AND PACKING

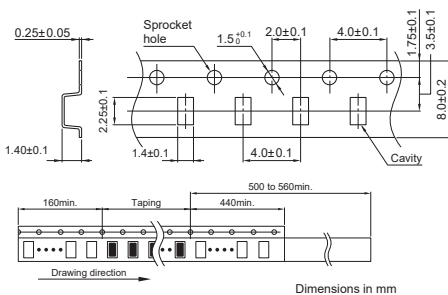


Quantity (pcs):
2000 PCS PER REEL
10 REELS PER CARTON
20000 PCS PER CARTON

SCHEMATICS

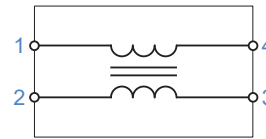

• No polarity

IMPEDEANCE FREQUENCY

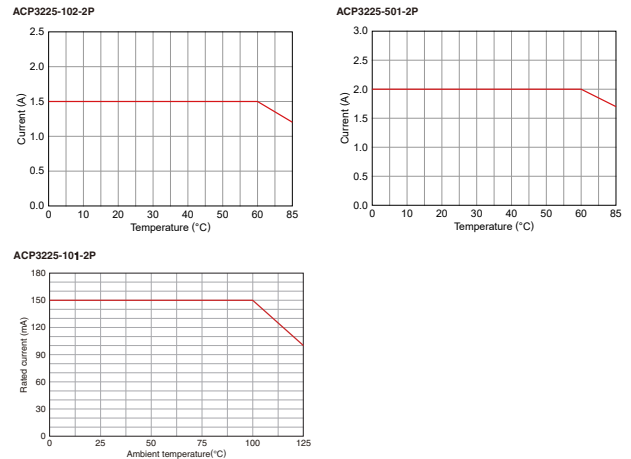

Reel

