
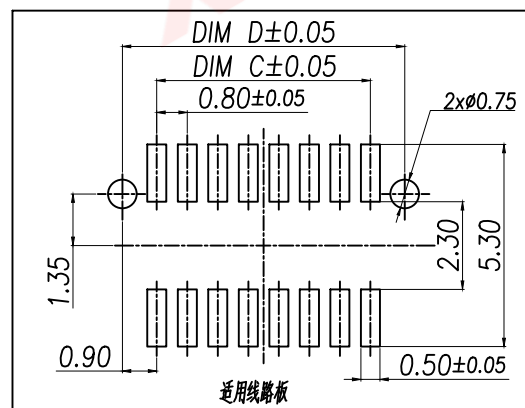
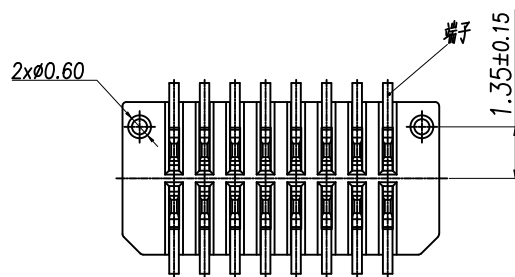
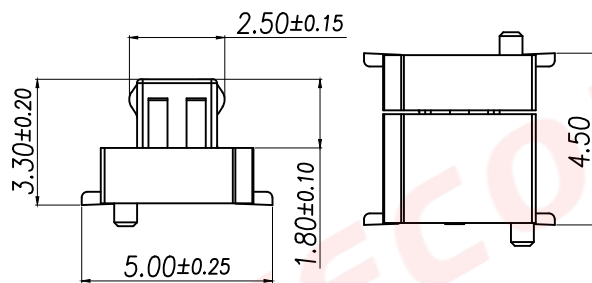
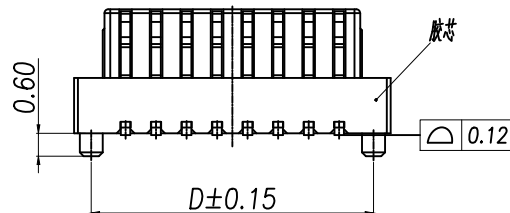
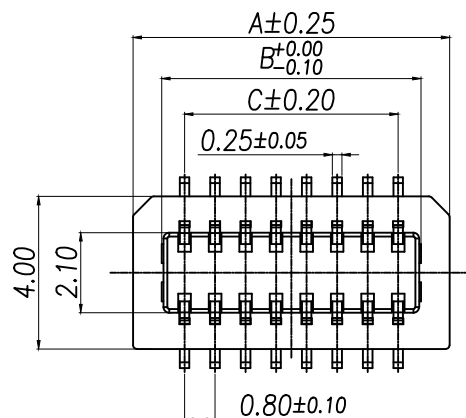


技术指标:

1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
2. 温度范围: $-40^{\circ}\text{C} \sim 105^{\circ}\text{C}$ 。
3. 额定电压: 50V, AC。
4. 接触电阻: $\leq 0.02\Omega$ 。
5. 绝缘电阻: $\geq 500\text{M}\Omega$

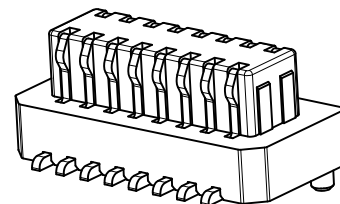

DIMENSION IN mm		厦门市辛译精密电子有限公司 Xiamen XinYi Xyeconn Electronics Co.,Ltd			
TOLERANCE UNLESS OTHERWISE SPECIFIED		TITLE: 0.8 Pitch F型单排立式BTB公座 (间距3.3)			
.X±0.5	X.*±1°	APR.	Alex	DWG NO. XY-DF833F-NLBDW	
.XX±0.2	.X.*±	CHK.	Jack	PROJ.  CUSTOMER DRAWING	
.XXX±0.1	.XX.*±	DRA.	Can	SIZE A4	SCALE 1:1
		SHEET 1/1		REV. A	

序号	品名	材质
①	0.8 Pitch F型单排立式BTB公座触芯	PA9T UL94 V-0,颜色:黑色
②	0.8 Pitch F型单排立式公座端子	铜合金/表面镀金

总高(H)	公座引脚(H)		单座引脚(H)
	H	H1	
4.00	2.80	1.80	2.90
4.50	3.30		
5.00	3.80		
5.50	4.30	2.30	3.40
6.00	4.80		
6.50	5.30		
7.00			3.90

Part No	CKT	A	B	C	D
XY-DF833F-6LBGDW	2*3	4.30	2.80	1.60	3.40
XY-DF833F-8LBGDW	2*4	5.10	3.60	2.40	4.20
XY-DF833F-10LBGDW	2*5	5.90	4.40	3.20	5.00
XY-DF833F-12LBGDW	2*6	6.70	5.20	4.00	5.80
XY-DF833F-14LBGDW	2*7	7.50	6.00	4.80	6.60
XY-DF833F-16LBGDW	2*8	8.30	6.80	5.60	7.40
XY-DF833F-18LBGDW	2*9	9.10	7.60	6.40	8.20
XY-DF833F-20LBGDW	2*10	9.90	8.40	7.20	9.00
XY-DF833F-30LBGDW	2*15	13.90	12.40	11.20	13.00
XY-DF833F-40LBGDW	2*20	17.90	16.40	15.20	17.00
XY-DF833F-50LBGDW	2*25	21.90	20.40	19.20	21.00
XY-DF833F-60LBGDW	2*30	25.90	24.40	23.20	25.00
XY-DF833F-70LBGDW	2*35	29.90	28.40	27.20	29.00
XY-DF833F-80LBGDW	2*40	33.90	32.40	31.20	33.00
XY-DF833F-90LBGDW	2*45	37.90	36.40	35.20	37.00
XY-DF833F-100LBGDW	2*50	41.90	40.40	39.20	41.00