


合高(H)	公座单高	母座单高
3.0	2.2	2.2
3.5	2.2	2.7
4.0	2.2	3.2
5.0	2.6	4.4

技术指标:

1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
2. 温度范围: $-40^{\circ}\text{C}\sim 85^{\circ}\text{C}$ 。
3. 额定电压: 125V, AC。
4. 接触电阻: $\leq 0.02\Omega$ 。
5. 绝缘电阻: $\geq 100\text{M}\Omega$

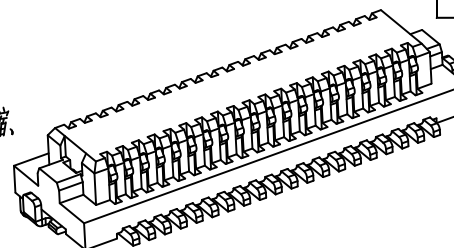

Part No	CKT	A	B	C	D	E
BTB0.522-10PLBDC2-GB42	2X5	2.00	3.10	4.60	5.52	4.10
BTB0.522-12PLBDC2-GB42	2X6	2.50	3.60	5.10	6.02	4.60
BTB0.522-14PLBDC2-GB42	2X7	3.00	4.10	5.60	6.52	5.10
BTB0.522-16PLBDC2-GB42	2X8	3.50	4.60	6.10	7.02	5.60
BTB0.522-18PLBDC2-GB42	2X9	4.00	5.10	6.60	7.52	6.10
BTB0.522-20PLBDC2-GB42	2X10	4.50	5.60	7.10	8.02	6.60
BTB0.522-22PLBDC2-GB42	2X11	5.00	6.10	7.60	8.52	7.10
BTB0.522-24PLBDC2-GB42	2X12	5.50	6.60	8.10	9.02	7.60
BTB0.522-26PLBDC2-GB42	2X13	6.00	7.10	8.60	9.52	8.10
BTB0.522-28PLBDC2-GB42	2X14	6.50	7.60	9.10	10.02	8.60
BTB0.522-30PLBDC2-GB42	2X15	7.00	8.10	9.60	10.52	9.10
BTB0.522-32PLBDC2-GB42	2X16	7.50	8.60	10.10	11.02	9.60
BTB0.522-34PLBDC2-GB42	2X17	8.00	9.10	10.60	11.52	10.10
BTB0.522-36PLBDC2-GB42	2X18	8.50	9.60	11.10	12.02	10.60
BTB0.522-38PLBDC2-GB42	2X19	9.00	10.10	11.60	12.52	11.10
BTB0.522-40PLBDC2-GB42	2X20	9.50	10.60	12.10	13.02	11.60
BTB0.522-44PLBDC2-GB42	2X22	10.50	11.6	13.1	14.02	12.60
BTB0.522-50PLBDC2-GB42	2X25	12.00	13.1	14.6	15.52	14.10
BTB0.522-60PLBDC2-GB42	2X30	14.50	15.6	17.1	18.02	16.60
BTB0.522-70PLBDC2-GB42	2X35	17.00	18.1	19.6	20.52	19.10
BTB0.522-80PLBDC2-GB42	2X40	19.50	20.6	22.1	23.02	21.60

序号	品名	材质
①	0.5 Pitch B型单槽立式 BTB公座嵌芯	LCP UL94 V-0 颜色:米黄色
②	0.5 Pitch B型单槽立式 BTB公座端子	铜合金/表面镀锡/表面点镀金
③	0.5 Pitch B型单槽立式 BTB公座弹片	铜合金/表面镀锡

DIMENSION IN mm

TOLERANCE UNLESS
OTHERWISE SPECIFIED

.X $\pm$ 0.5	X.* $\pm$ 1°
.XX $\pm$ 0.2	.X.* $\pm$
.XXX $\pm$ 0.1	.XX.* $\pm$

厦门市辛译精密电子有限公司
Xiamen XinYi Xyeconn Electronics Co.,Ltd

APR. Alex	TITLE: 0.5 Pitch B型单槽立式BTB公座嵌芯(料2.2)
CHK. Jack	DWG NO. XY-DF522B-NLBGDH
DRA. Can	PROJ.  CUSTOMER DRAWING
SIZE A4	SCALE 1:1
SHEET 1/1	REV. A