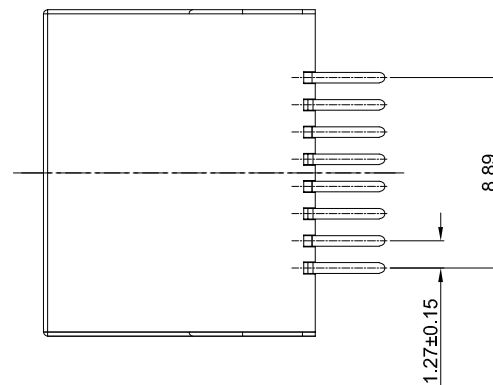
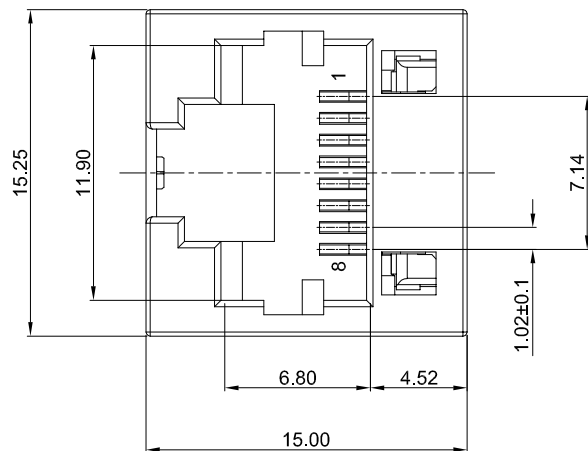


GT - RJ45 U N 0X - 009 A

G-Switch

Series
RJ45



Shield
U=UTP

Light
N=without led

Detail

Serial code

Contact Plated
00=Au G/F
01=Au 1u"
03=Au 3u"
...

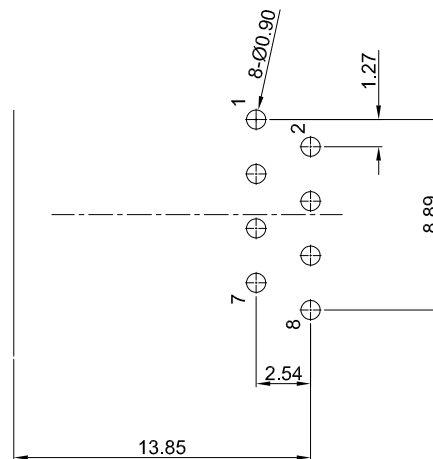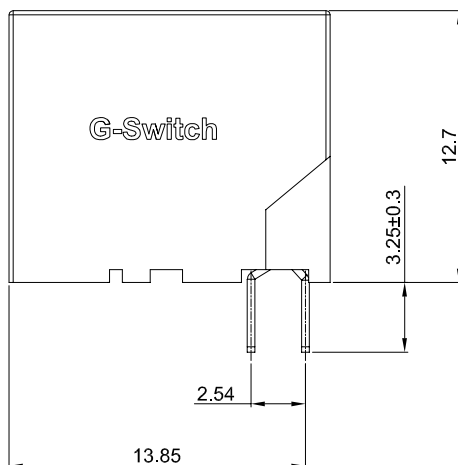

PCB REFERENCE DIAGRAM
TOLERANCE:±0.05

G-Switch Specification:

- 1.Current rating: 1.5A
- 2.Voltage rating: 125V AC RMS.
- 3.Insulation resistance: 500MQ min
- 4.Contact resistance: 40mΩ max
- 5.Dielectric strength: 500 megohms min @ 100V DC
- 6.Durability: 750 cycles
- 7.Withstand voltage: AC1000V RMS 50Hz or 60Hz min
- 8.Operating temperature range: -40°C ~ +85°C

1	INSERT	PA9T	BLACK
2	HOUSING	PA9T	BLACK
3	TERMINALS	PHOSPHOR BRONZE T=0.35	Au PLATED ON CONTACT AREA TIn PLATED ON SOLDER AREA
NO.	PARTS	MATERIAL	REMARKS

RoHS
Compliant
EU RoHS Standards

SCALE: 1:1	UNIT: mm	Title: Vertical RJ45 Conn 8P8C DIP 15.26×15.0×H12.7mm				 品赞科技 b-Switch www.dg-switch.com	
SIZE: A4	 						
Unless otherwise General tolerance:		Molde Code: GT-RJ45UNXX-009A					
		DRAWN	CHECKED	APPROVED	DATE		
X. ±0.50 X.x ±0.30 X.xx ±0.20 Angles ±3°		Xia	Chen	Chen	2025.07.03	REV: A0	SHEET: 1/1