



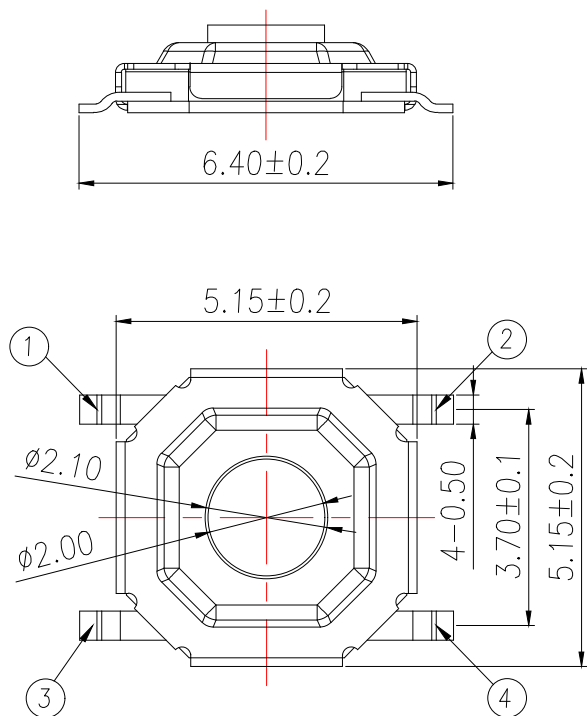

主要技术参数、性能

The Main Thchnology Performance

额定电流、电压 Rate voltage,current	50mA DC12V
接触电阻 Contact resistance	≤100mΩ
按力 Operating force	±50gf
行程 travel	0.2±0.1mm
绝缘电阻 Insulated resistance	>100MΩ
介电强度 Dielectric strength	≥250VAC/1min
工作温度 Operating temperature	-30°C~+80°C

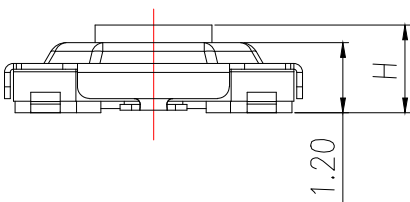


H
1.5
1.6
1.7
1.8
2.0
2.5
...
5.5

B X - T S - - 4 4 N T T


力度:
10:100g
16:160g
26:260g

高度:
15:1.5H
16:1.6H
17:1.7H
18:1.8H
19:1.9H
20:2.0H
25:2.5H
....

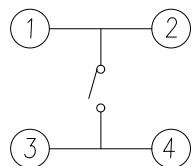


电路图

CIRCUIT DIAGRAM

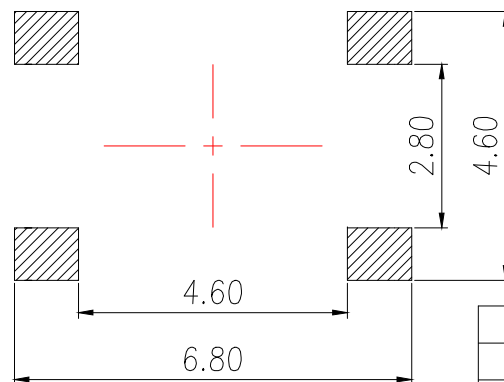

PCB.焊接图

PCB.WELDING DRAWING

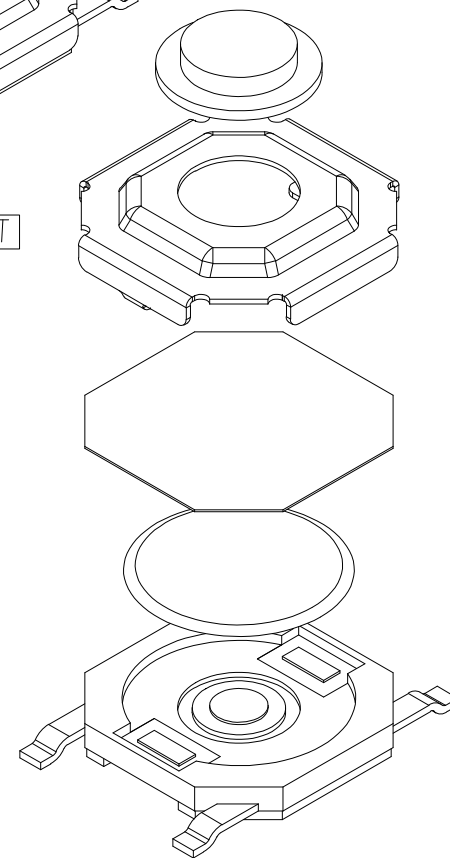

E	按钮	黄铜	1	酸洗
D	盖板	不锈钢	1	清洗
C	防尘膜	聚酰亚胺	1	橙黄色
B	弹片	不锈钢	1	镀银
A	卡件	黄铜	1	镀银
项目 ITEM	名称 DESCRIPTION	材质 MATERIAL	数量 QTY	表面处理/颜色 FINSH/COLOR
料号 PART NO.	BX-TS-N-44NTT		版本 REV.	A
品名 TITLE	TACT SWITCH		页次 SHEET	1/1
客户料号 CUTM.NO.				
制图 DRAWING	EMMA		单位 UNITS	MM
审核 CHECK	EVA		比例 SCALE	1:1
核准 APPROVAL	JADE			