


客户图 NL-Q10-SW

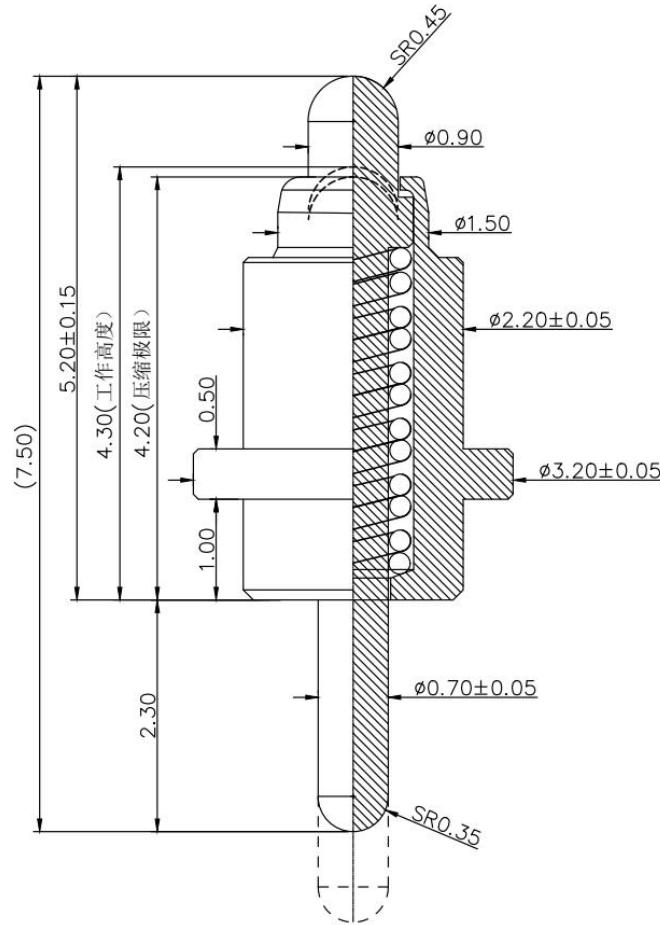

Note:

- 1: Material(材料):
Barrel: Brass C3604 (针管: 黄铜 C3604)
Plunger: Brass C3604 (针头: 黄铜 C3604)
Spring: SUS304 (弹簧: SUS304)
- 2: Plating(电镀):
Barrel: 1u' Au over 80~120u' Ni (针管: 镀金1u', 镍底80~120u'.)
Plunger: 3u' Au over 80~120u' Ni (针头: 镀金3u', 镍底80~120u'.)
Spring: No plated (弹簧: 不电镀)
- 3: Electrical(电气特性):
Rated Current & Voltage: DC 12V;5A (额定电压&电流: 直流12V,5A)
Contact Resistance: 50 mohm Max. at working height.
接触电阻: 最大50毫欧 (在工作高度状态下)
- 4: Mechanical(机械性能):
Force: 80g±20% at working height. (80g±20% 在工作高度)。
Durability: 10.000 cycles(min) (寿命: 10000次)
- 5: WorkTemperture(工作环境):
Withstanding Higt Temperature: 280℃
Operational Temperature: -40℃~ +85℃
6. Salt spray test: 48 hours salt spray measurement.

深圳市鑫扬泽电子有限公司



HTTP://WWW.XYZPOGOPIN.COM
TEL:0755-28773277 FAX:0755-28891353

SCALE:	N/A	UNIT	mm	THE UNMARKED TOLERANCE ARE AS BELOW :		DESIGNED BY:	lyg	DWG. NO.	YZP0516-32075-01
SHEET:	1 of 1	PROJECTION				CHECKED BY:		TITLE:	Pogo Pin
DATE:	2021.1.26	VER.	D.0	LENGTH		APPROVED BY:			
				X.XX	±0.05mm	X.XX	±0.50°		
				X.X	±0.10mm	X.X	±1.00°		
				X.	±0.20mm	X.	±2.00°		