

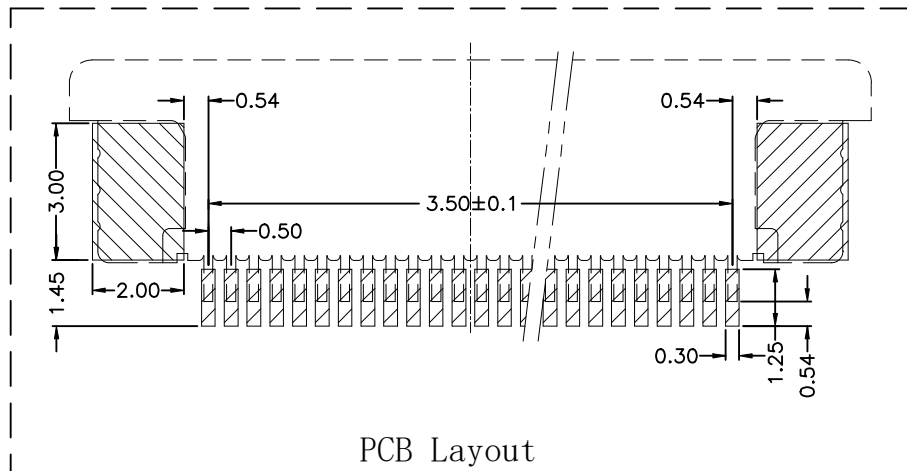
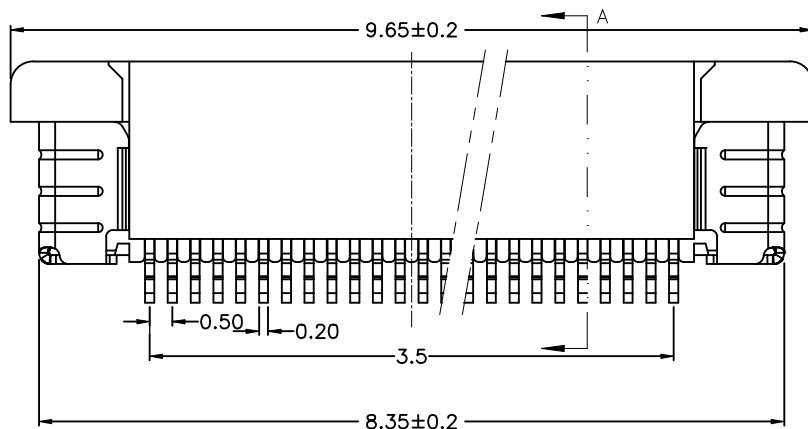
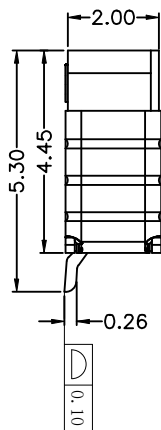


ROHS

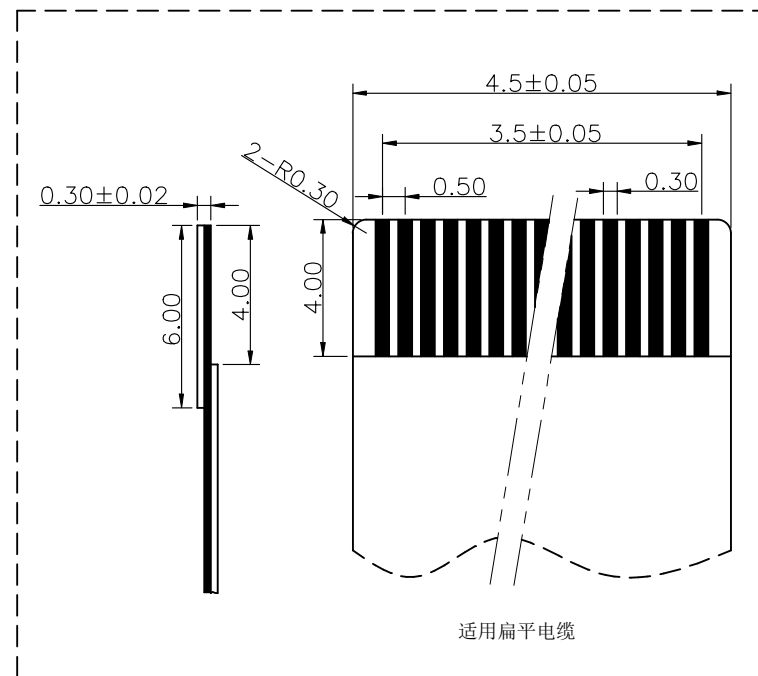

8PIN

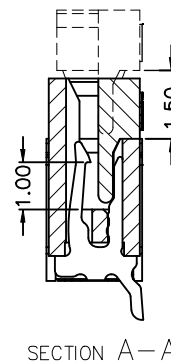

适用扁平电缆

技术要求(Technical Index):

1. 材质与表面处理(Material And Finish):
基座 (Housing) and 盖子 (Cover): LCP UL94V-0 Nature Or Black;
端子 (Terminal) :Phosphor Copper Au/Sn Plated;
焊片 (Solder) : Copper Alloy Au/Sn Plated;
2. 工作温度(Temperature range): -25° C~+85° C.
3. 额定电压(Rated voltage): 50V, AC/DC.
4. 额定电流: 0.4A, AC/DC.
5. 接触电阻(Contact resistance): ≤20mΩ.
6. 绝缘电阻(Insulation resistance): ≥500MΩ.
7. 耐电压(Withstanding Voltage): 200V AC/minute.

CUSTOMER DRAWING		LAILIAN 深圳市莱联电子有限公司 SHENZHEN LAILIAN ELECTRONICS CO., LTD				
DRAWING		TITLE FPC连接器0.5间距8PIN抽屉式上接（焊贴）			REV.	A
CHECKED						
APPROVED						
TOLERANCES ARE		PART NO. DWG. NO.	LAIL-FPC-BS01-8P0.5-W	UNITS	mm	Projection 
30-150	±0.35					
10-30	±0.2					
5-10	±0.15					
0-5	±0.1					
ANGLE						
±3°						