








PART NUMBER
10170159-1XXXXLF

A

B

C

D

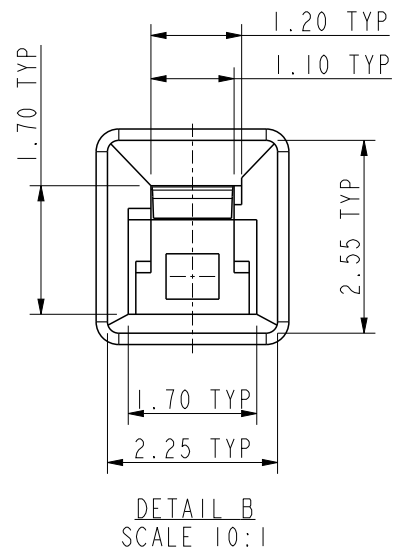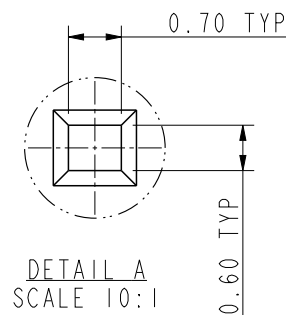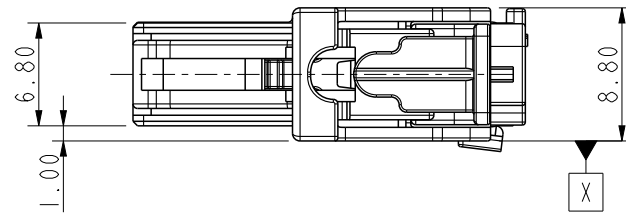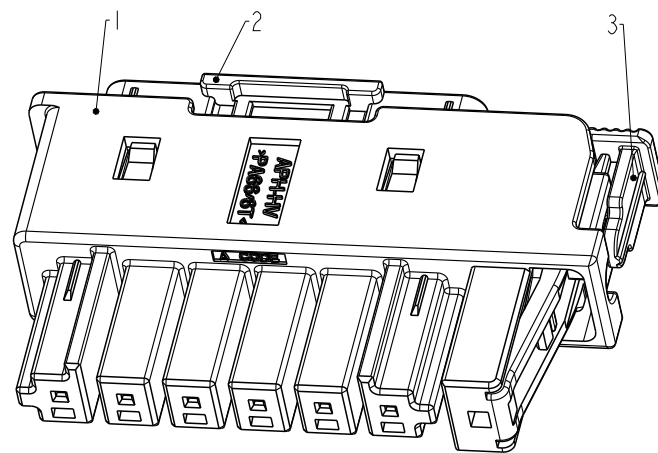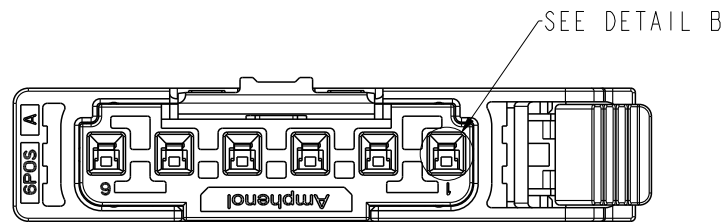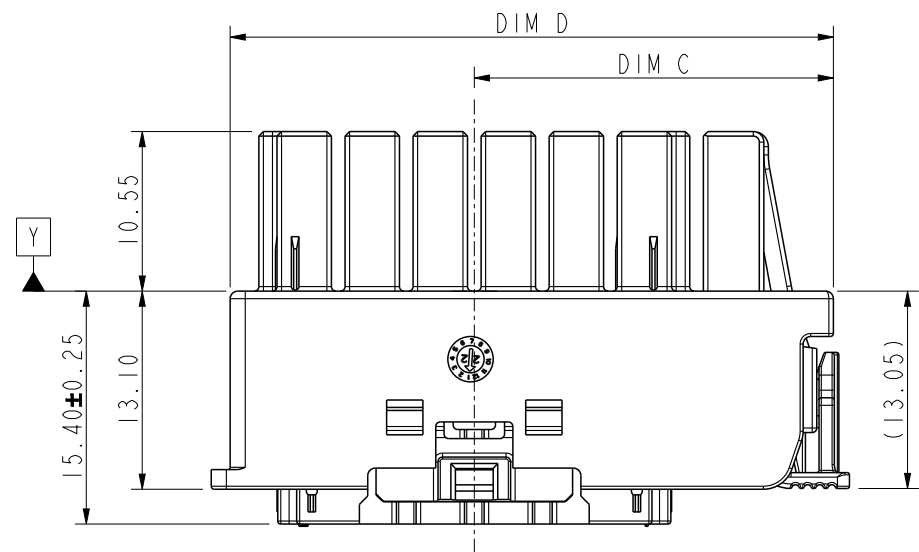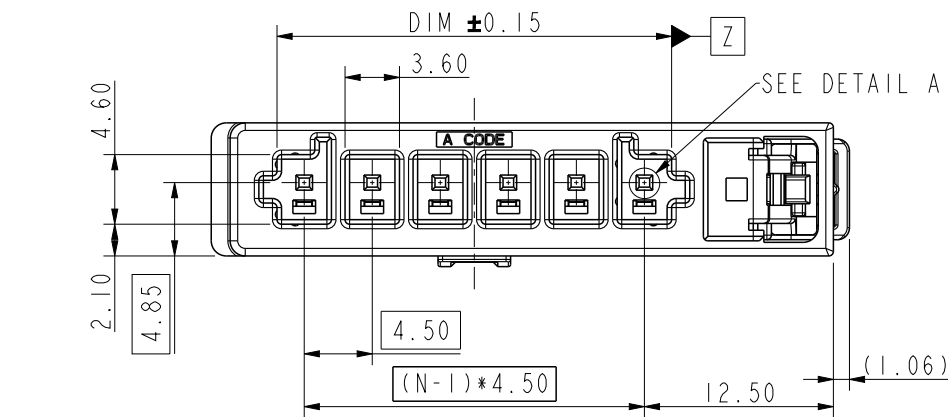


- NOTES:
1. MATERIAL: PA66 OR PA6T, THERMOPLASTIC UL94 V-0
COLOR: ORANGE WITH RED CPA
 2. PACKAGE SPECIFICATION: GS-14-3001.
 3. PART NUMBER CODE: 10170159-1 XX X X


NUMBER OF POSITIONS
06 $\rightarrow$ 6 PINS
07 $\rightarrow$ 7 PINS
10 $\rightarrow$ 10 PINS

LE
RoHS COMPATIBLE
FOR CUSTOMER CODE
CODE TYPE
A $\rightarrow$ A CODE
B $\rightarrow$ B CODE
PACKAGING
K $\rightarrow$ PE BAG
T $\rightarrow$ TRAY PACKAGE

A CODE / COLOR: ORANGE; COLOR CODE: RAL2008

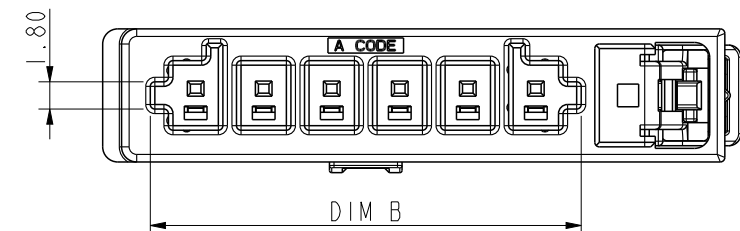

B CODE / COLOR: ORANGE; COLOR CODE: RAL2008

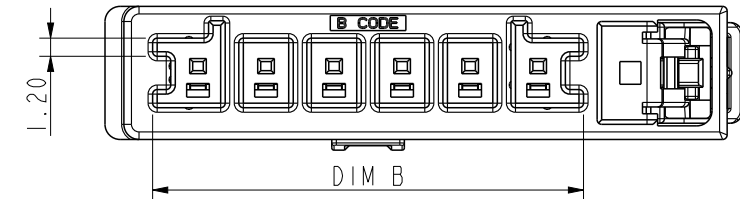

POS.	PART NO.	DIM.A	DIM.B	DIM.C	DIM.D
06	10170159-106XXLF	26.10	28.50	23.75	39.90
07	10170159-107XXLF	30.60	33.00	26.00	44.40
08	10170159-108XXLF	35.10	37.50	28.25	48.90
09	10170159-109XXLF	39.60	42.00	30.50	53.40
10	10170159-110XXLF	44.10	46.50	32.75	57.90

3	SIDE LATCH CPA	THERMOPLASTIC UL94 V-0; RED	I	
2	INNER RECEPTACLE HOUSING	THERMOPLASTIC UL94 V-0; ORANGE	I	
1	SIDE LATCH PLR	THERMOPLASTIC UL94 V-0; ORANGE	I	
No.	Components Description	Material Specifications	Q'ty	Remarks

spec ref	dr	Huang, Jeffrey	2023/07/21	projection	mm	size	A3	scale	2:1
tolerance std	eng	Song Yang	2026/08/26	chr	-	ecn no	ELX-N-295499-1	rel level	Released
ISO 406 ISO 1101	appr	Tim Yao	2026/08/28	product family	RECEPTACLE KITS, WITH CPA HVL Lock Series Cable Kits	dwg no	10170159	rev	C
surface	linear	0.X ± 0.3 0.XX ± 0.15 0.XXX ± 0.05	Amphenol FCi	cat. no.	Product - Customer Drw	sheet 1 of 1			
ISO 1302	angular	0° $\pm 2^\circ$							