

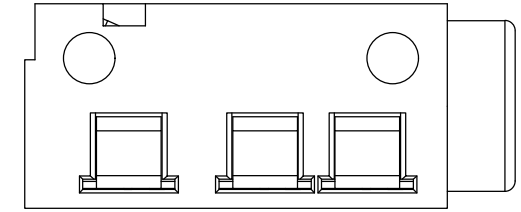
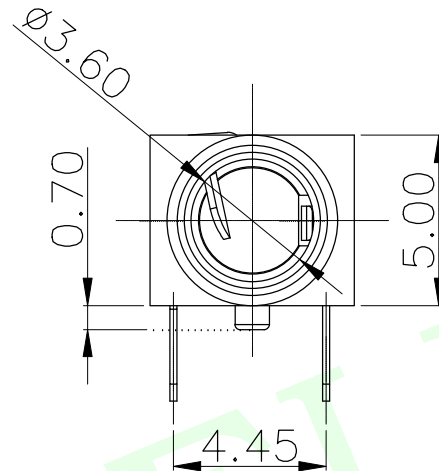
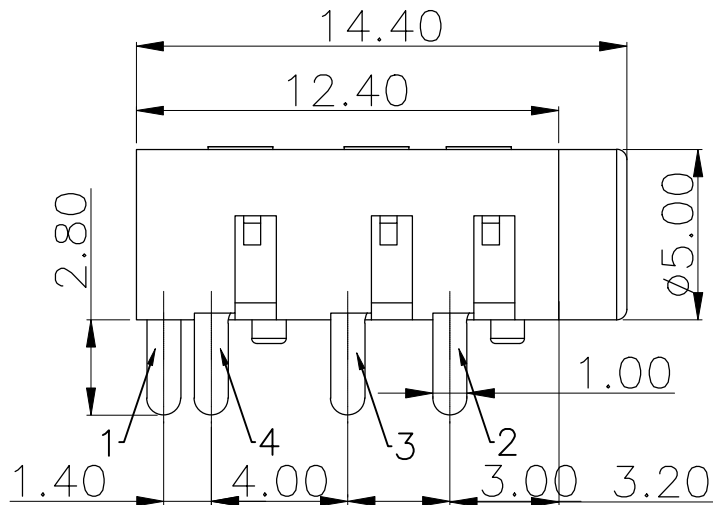
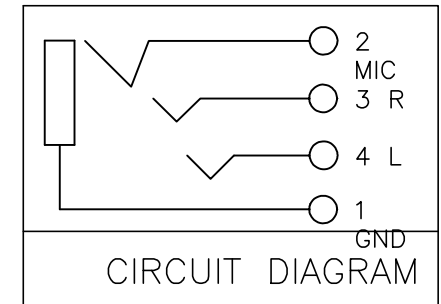


RoHS Compliant

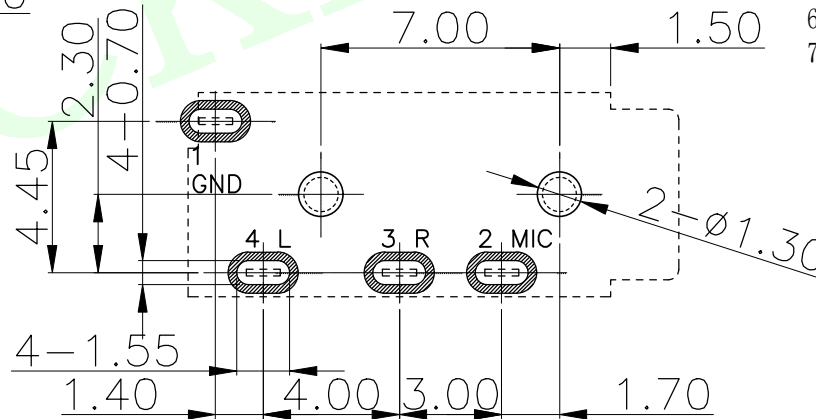

- 一、Materials and electroplating specifications:
- 1.terminal: Brass; After nickel plating 30u", tin plating 80u";
 2. Insulator: Polyamide; Color:Black.
- 二、SPECIALITY:
1. RATED:30V Max/0.5A Max
 2. CONTACT RESISTANCE: 100mΩ Max;
 3. DIELECTRIC STRENGTH: 500V/AC 1min No Breakdown
 4. INSULATION RESISTANCE:100MΩ Min. 500V DC
 5. INSERTION FORCE:3.0Kgf Max
WITHDRAWAL FORCE:0.3Kgf Min
 6. temperature:-20℃ to +70℃
 7. Parts must comply with RoHS standards

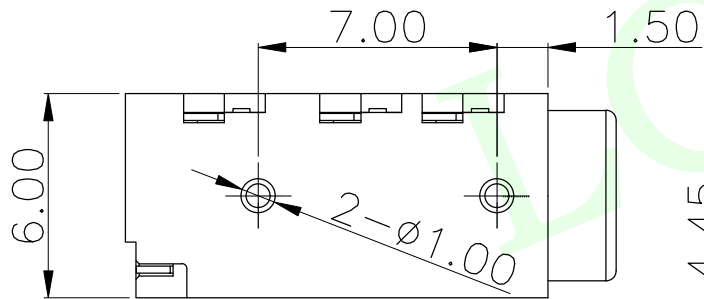

P.C.B LAYOUT
(for reference only)

MEASURE POINT:
QUADRANT POINT (QP)
TANGENCY POINT (TP)
INTERSECTION POINT (IP)

UNLESS OTHERWISE
SPECIFIED, TOLERANCE:
X. ±0.25
X.x ±0.20
X.xx ±0.15
ANGULAR ±3°



联晟欣连接器 (深圳) 有限公司
Lianshengxin Connector (Shenzhen) Co., Ltd

DESIGN	Andy	DATE	2014.12.24	TITLE:	PJ 插件式 4PIN 黑色主体 1.00mm
CHECKED		DATE			定位柱 插口 5.00mm 尾部封装
APPROVED		DATE			
PART NO:	LCK-PJ-002	REV:	04	SCALE:	1:1
DRAWING NO:		SHEET:	1/1	UNIT:	mm