
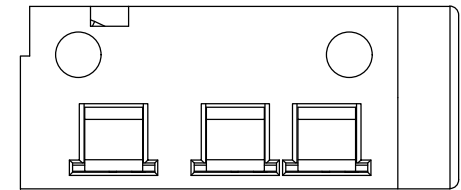
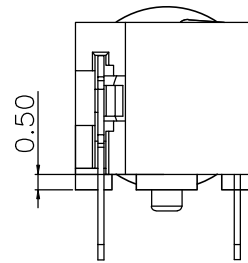






RoHS Compliant

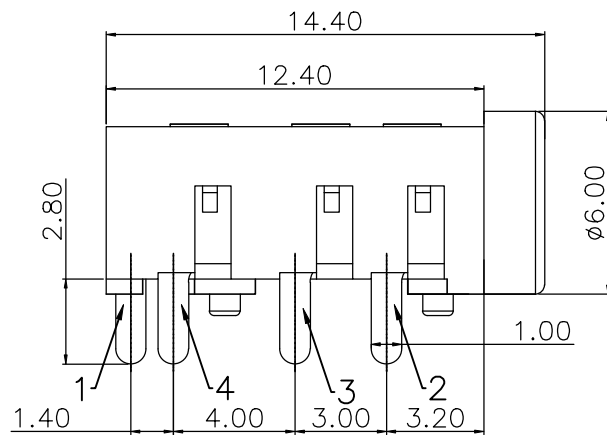

- 一、Materials and electroplating specifications:
- 1.terminal: Brass; After nickel plating 30u", tin plating 80u";
 2. Insulator: Polyamide; Color:Black.

二、SPECIALITY:

1. RATED: 30V Max/0.5A Max
2. CONTACT RESISTANCE: 100mΩ Max;
3. DIELECTRIC STRENGTH: 500V/AC 1min No Breakdown
4. INSULATION RESISTANCE: 100MΩ Min. 500V DC
5. INSERTION FORCE: 3.0Kgf Max
WITHDRAWAL FORCE: 0.3Kgf Min
6. temperature: -20℃ to +70℃
7. Parts must comply with RoHS standards

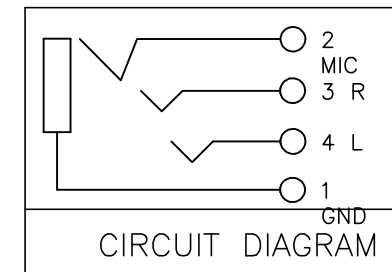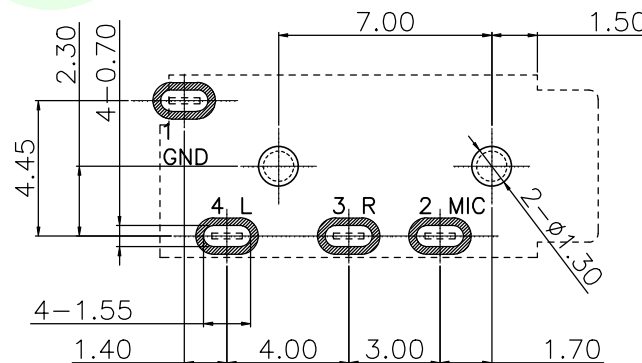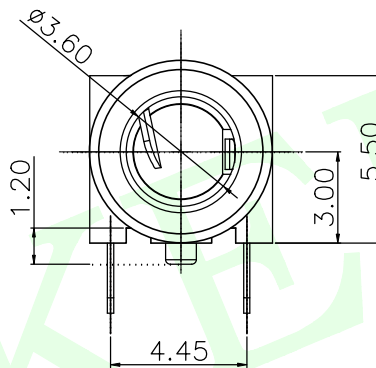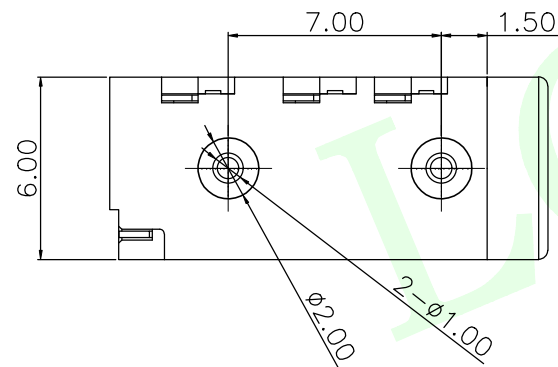

MEASURE POINT: QUADRANT POINT TANGENCY POINT INTERSECTION POINT		QP TP IP		UNLESS OTHERWISE SPECIFIED, TOLERANCE: X. ±0.25 X.x ±0.20 X.xx ±0.15 ANGULAR ±3°		DESIGN CHECKED APPROVED		Andy DATE DATE		2014.12.24 DATE		TITLE: PJ 插件式 4PIN 黑色主体 1.00mm 定位柱 插口 6.00mm 尾部封装		PART NO: LCK-PJ-003 DRAWING NO:		REV: 04 SIZE: A4		SCALE: 1:1 SHEET: 1/1		UNIT: mm	
--	--	----------------	--	---	--	-------------------------------	--	----------------------	--	--------------------	--	---	--	------------------------------------	--	---------------------	--	--------------------------	--	----------	--

联晟欣连接器（深圳）有限公司
Lianshengxin Connector (Shenzhen) Co., Ltd