


客户图

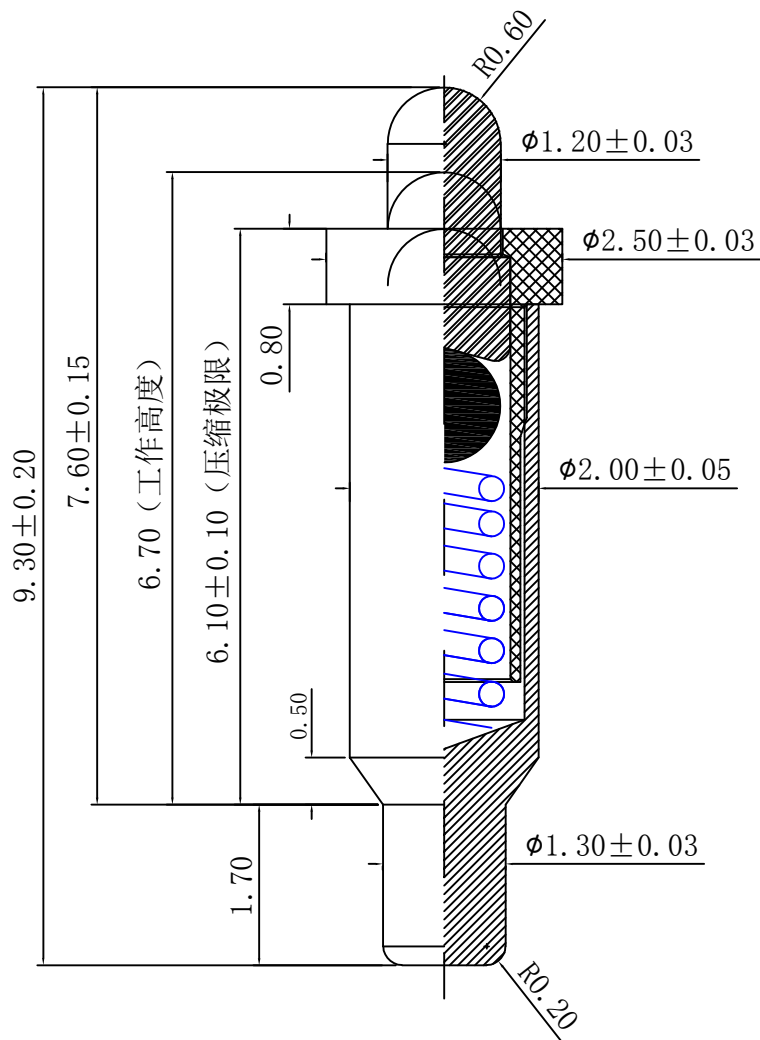

Note:

1: Material(材料) :

Barrel: Brass C3604(针管: 黄铜 C3604)

Plunger: Brass C3604(针头: 黄铜 C3604)

bead: Zirconium oxide (珠子: 氧化锆)

Spring: SUS304 (弹簧: SUS304)

2: Plating(电镀) :

Barrel: 5u' Au over 50~80u' Ni(针管: 镀金5u', 镍底50~80u'.)

Plunger: 5u' Au over 50~80u' Ni(针头: 镀金5u', 镍底50~80u'.)

Bearing ball: No plated.(氧化锆陶瓷珠: 不电镀)

Spring: Gold flash(弹簧: 镀金)

3: Electrical(电气特性) :

Rated Current & Voltage: DC 4V;10A (额定电压&电流: 直流4V, 10A)

Contact Resistance: 50 mohm Max. at working height.

接触电阻: 最大50毫欧 (在工作高度状态下)

4: Mechanical(机械性能) :

Force: 150g ± 20% at working height. (150g ± 20% 在工作高度)。

Durability: 10,000 cycles(min) (寿命: 10000次)

5: WorkTemperture(工作环境):

Withstanding Higt Temperature: 280°C

Operational Temperature: - 20°C ~ + 70°C

深圳市鑫探技术有限公司



TEL: 0755-28773277 FAX: 0755-28891353

SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	
DATE:	2026.9.3	VER.	A.0

THE UNMARKED TOLERANCE ARE AS BELOW :

LENGTH		ANGLE	
X.XX	±0.05mm	X.XX	±0.50°
X.X	±0.10mm	X.X	±1.00°
X.	±0.20mm	X.	±2.00°

DESIGNED BY:		DWG. NO.	YZP0897-25093-03
CHECKED BY:		TITLE:	Pogo pin
APPROVED BY:			