


客户图

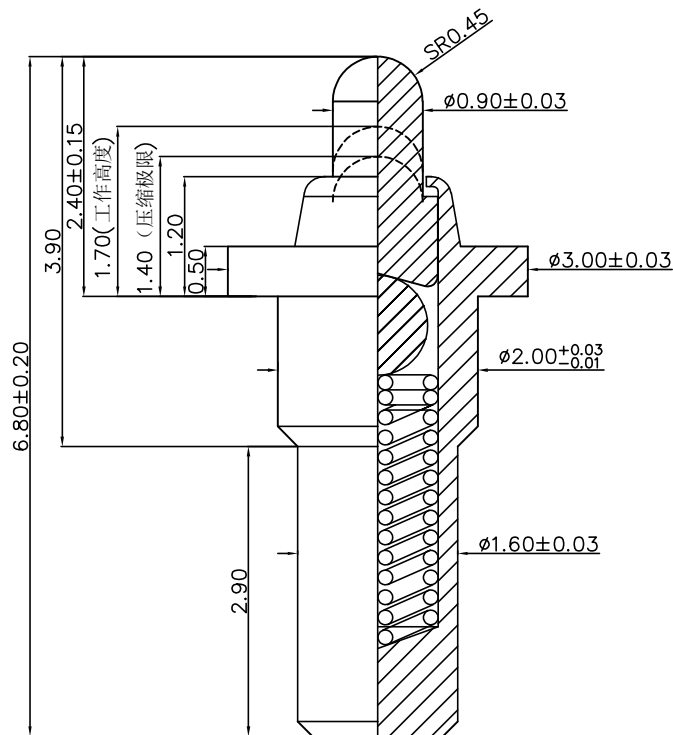

Note:

- 1: Material(材料) :
Barrel: Brass C3604 (针管: 黄铜 C3604)
Plunger: Brass C3604 (针头: 黄铜 C3604)
Spring: SUS304 (弹簧: SUS304)
Ball bearing: Sus304 (钢珠: SUS304)
- 2: Plating(电镀) :
Barrel: 5u' Au over 50~80u' Ni (针管: 镀金5u', 镍底50~80u'.)
Plunger: 5u' Au over 50~80'u Ni (针头: 镀金5u', 镍底50~80u'.)
Spring: Gold flash (弹簧: 电镀1u')
Ball bearing : Gold flash(钢珠: 电镀2u')
- 3: Electrical(电气特性) :
Rated Current & Voltage: DC 12V;5A (额定电压&电流: 直流12V,5A)
Contact Resistance: 50 mohm Max. at working height.
接触电阻: 最大50毫欧 (在工作高度状态下)
- 4: Mechanical(机械性能) :
Force: 120g±20% at working height. (120g±20% 在工作高度)。
Durability: 10.000 cycles(min) (寿命: 10000次)
- 5: WorkTemperture(工作环境):
Withstanding Height Temperature: 280℃
Operational Temperature: - 40℃~ +85℃

深圳市鑫探技术有限公司



TEL:0755-28773277 FAX:0755-28891353

SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	
DATE:	2026.9.3	VER.	D.0

THE UNMARKED TOLERANCE ARE AS BELOW :

LENGTH		ANGLE	
X.XX	±0.05mm	X.XX	±0.50°
X.X	±0.10mm	X.X	±1.00°
X.	±0.20mm	X.	±2.00°

DESIGNED BY:		DWG. NO.	YZP0655-30068-01
CHECKED BY:		TITLE:	Pogo pin
APPROVED BY:			