
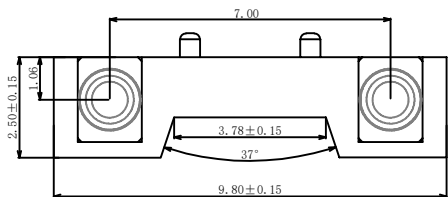


客户图纸

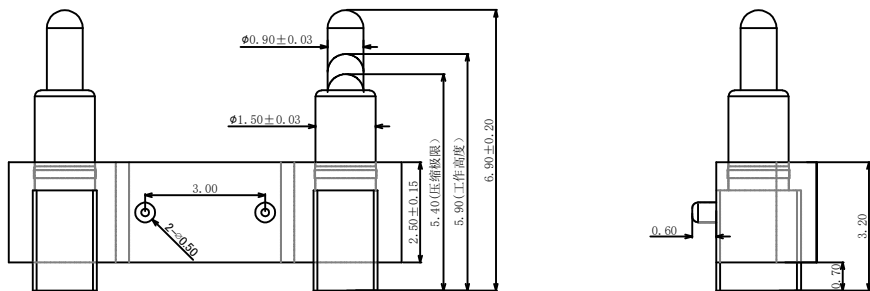

Note:

1: Material(材料):

Barrel: Brass C3604 (针管: 黄铜 C3604)

Plunger: Brass C3604 (针头: 黄铜 C3604)

Spring: SUS301 (弹簧: SUS301)

House: PA9T Black (塑胶: PA9T 黑色)

2: Plating(电镀):

Barrel: 3u' Au over 50~100u' Ni (针管: 镀金3u', 镍底50~100u'。)

Plunger: 3u' Au over 50~100u' Ni (针头: 镀金3u', 镍底50~100u'。)

Spring: Gold flash. (电镀)

3: Electrical(电气特性):

Rated Current & Voltage: DC 12V;2A (额定电压&电流: 直流12V, 2A)

Contact Resistance: 50 mohm Max. at working height.

接触电阻: 最大50毫欧 (在工作高度状态下)

4: Mechanical(机械性能):

Force: 50g $\pm$ 20% at working height. (50g $\pm$ 20% 在工作高度)。

Durability: 10.000 cycles(min) (寿命: 10000次)

5: WorkTemperture(工作环境):

Withstanding Higt Temperature: 280℃

Operational Temperature: - 20℃ ~ + 70℃

深圳市鑫探技术有限公司



TEL:0755-28773277 FAX:0755-28891353

SCALE:

N/A

UNIT

mm

SHEET:

1 of 1

PROJECTION



DATE:

2021.3.22

VER.

THE UNMARKED TOLERANCE ARE AS BELOW :

LENGTH

ANGLE

X.XX ± 0.05 mm
X.X ± 0.10 mm
X. ± 0.20 mm

X.XX $\pm 0.50^\circ$
X.X $\pm 1.00^\circ$
X. $\pm 2.00^\circ$

DESIGNED BY:

DWG. NO.

YZF0046-21069-02070-02

CHECKED BY:

TITLE:

Pogo pin 连接器

APPROVED BY: