
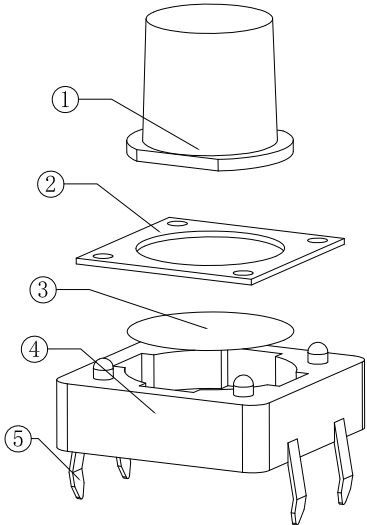
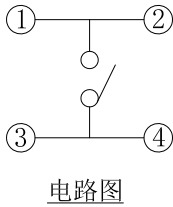
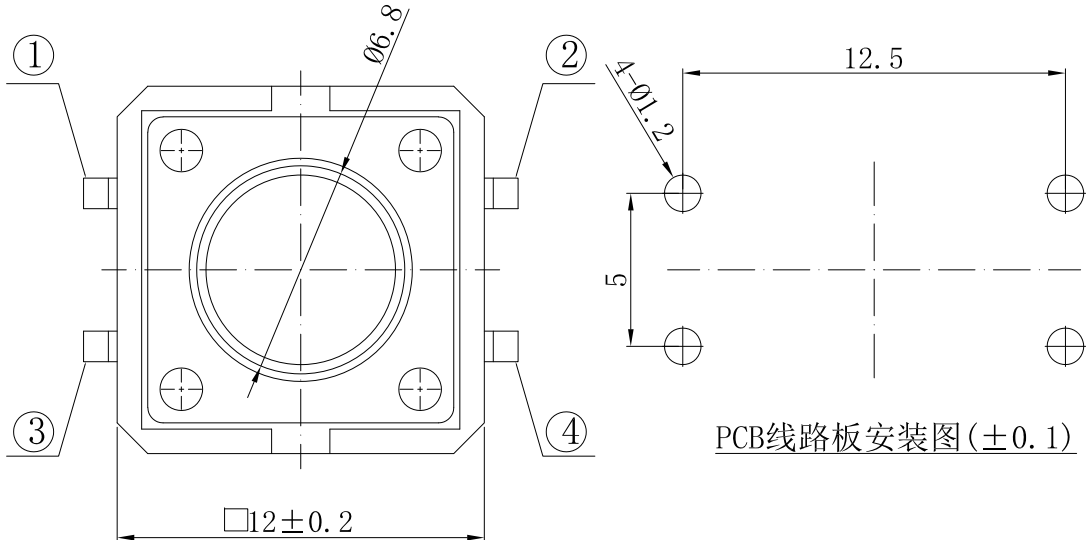


A	RoHS	1
	REACH	
B	H(高度)	A±0.1
	4.3H	6.80
	4.5H	6.85
	5.0H	6.85
C	5.5H	6.70
	6.0H	6.60
	6.5H	6.70
	7.0H	6.60
D	7.5H	6.60
	8.0H	6.65
	8.5H	6.65
	9.0H	6.85
E	9.5H	6.70
	10.0H	6.30
	10.5H	6.55
	11.0H	6.30
F	12.0H	6.70
	13.0H	6.45
	14.0H	6.30
	15.0H	6.30
G	16.0H	6.30
	17.0H	6.00
	18.0H	6.25
	19.0H	6.20
H	20.0H	6.20
	21.0H	6.10
	>21.0H	6.00

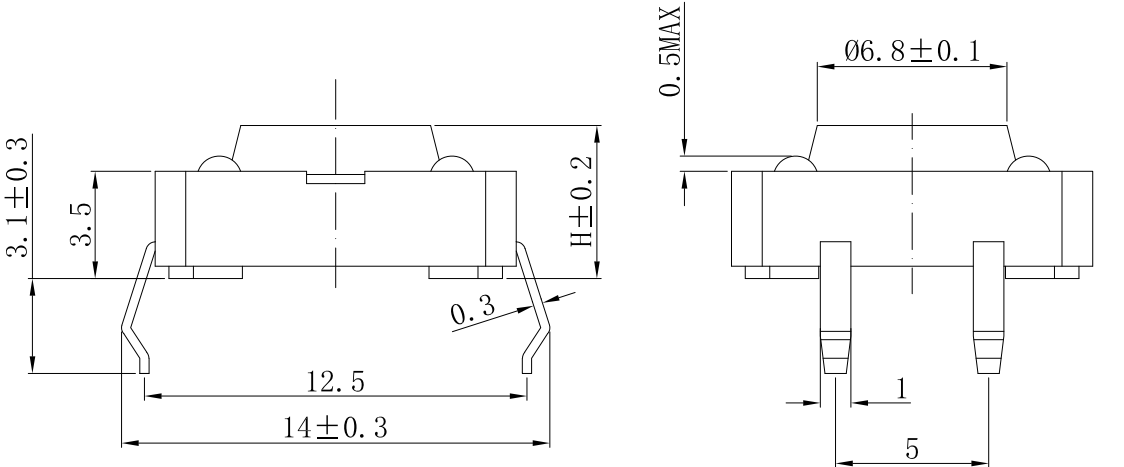

- 技术参数:
- 1. 做用温度: -25~+85℃;
 - 2. 额定负荷: DC 12V 50mA;
 - 3. 接触电阻: ≤50mΩ;
 - 4. 绝缘电阻: ≥100MΩ;
 - 5. 耐 压: AC250V(50Hz)/min;
 - 6. 动 作 力: 160g±50g
 - 7. 使用寿命: 100000次;
 - 8. 未注尺寸公差参照下面表格。

5	接触脚	黄铜	镀银	1	
4	基座	PPA	——	1	黑色
3	簧片	覆银磷铜/不锈钢	镀银	1	
2	盖板	不锈钢	——	1	
1	按钮	PPA	——	1	黑色
序号	零件名称	材料规格	表面处理	数量	备注

未注尺寸公差(mm)				设 计	S H		
0~3	±0.05	±0.10	±0.20			图面	A4
>3~6	±0.05	±0.10	±0.30	审 核	Z F C	单位	MM
>6~30	±0.10	±0.20	±0.50	标准化		比例	
>30~120	±0.15	±0.30	±0.80			重量	
角 度		±1°		批 准	L P J	页码	1/1
						版次	A/0