
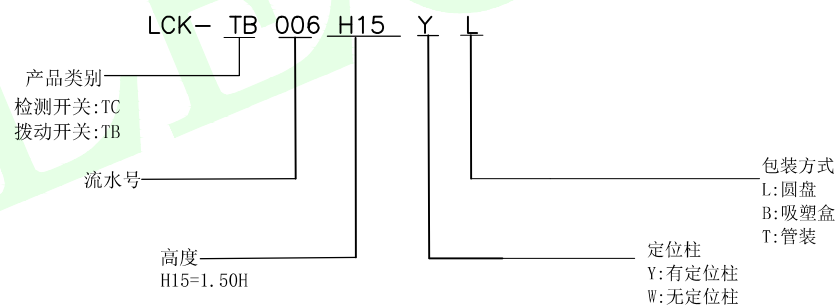


RoHS Compliant

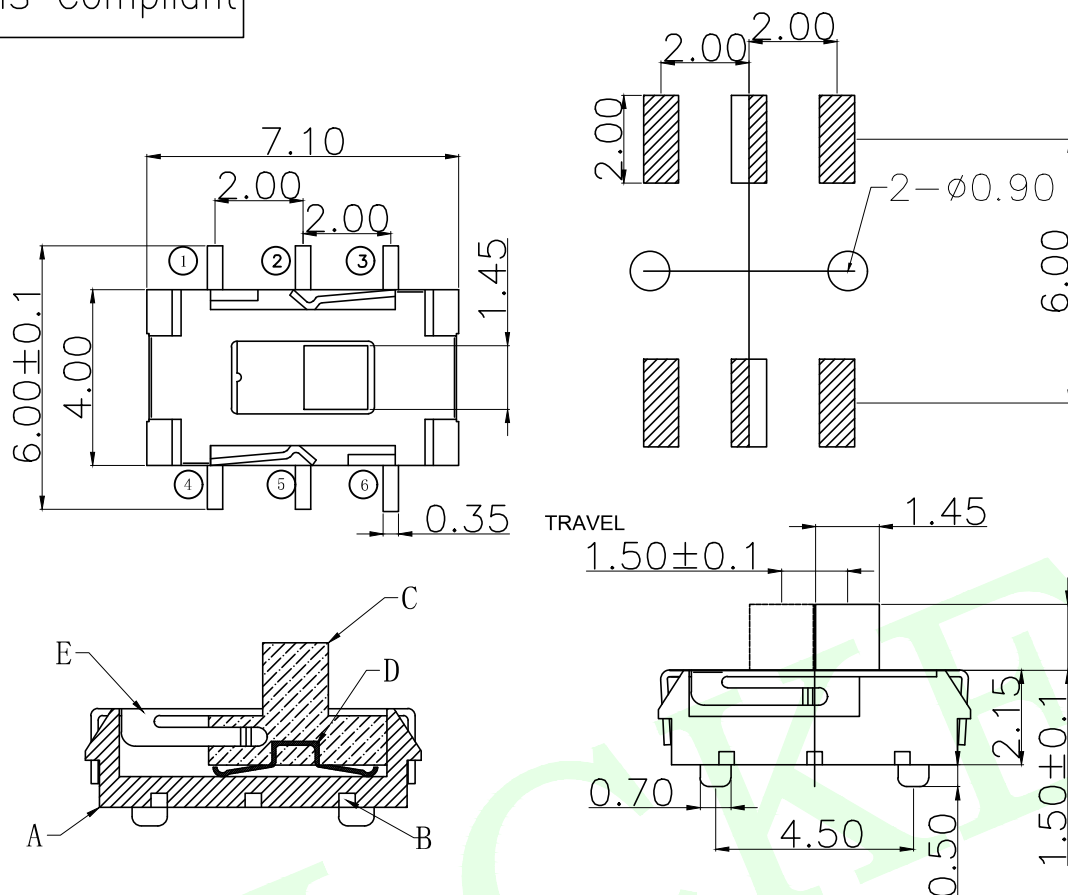

项 目		标 准
电气性能	额定电流 Rated Current:	50mA MAX
	额定电压 Rated voltage:	DC 12V
	接触电阻 Contact resistance:	$\leq 70\text{m}\Omega$
	绝缘电阻 Insulation Resistance:	$\geq 100\text{M}\Omega$
	耐压强度 Compressive strength:	AC250V 50Hz/1 min
机械性能	操作力度 Operating force:	150 $\pm$ 100gf
	机械寿命 Mechanical life:	10,000 cycles Min
	操作行程 Operation Stroke:	1.5 $\pm$ 0.1mm
环境性能	温度范围 Temperature Range:	-30 $^{\circ}\text{C}$ ~ +85 $^{\circ}\text{C}$

F	弹条	1	SUS301	整体清洗	银白色	
E	盖板	1	C5191R	整体镀银		
D	簧片	1	QBe2	接触面镀银	接触面银白色	
C	桃心	1	进口高温增强尼龙	/	黑色	
B	嵌件	1	C5191R	整体镀银	银白色	
A	底座/基座	1	LCP	/	黑色	
NO.	零件名称 Part Name	QTY	材 料 Material	镀涂 Plating coating	颜色 colour	备注 Remarks
MEASURE POINT: QUADRANT POINT TANGENCY POINT INTERSECTION POINT			 联晟欣连接器（深圳）有限公司 Lianshengxin Connector (Shenzhen) Co., Ltd			
QP TP IP						
UNLESS OTHERWISE SPECIFIED, TOLERANCE:			TITLE:			
X. ±0.25			DESIGN	Andy	DATE	2014.12.24
X.x ±0.20			CHECKED		DATE	
X.xx ±0.15			APPROVED		DATE	
ANGULAR ±3°			PART NO: LCK-TB006-H15YL			REV: 04
			DRAWING NO: 102022802			SCALE: 1:1
			SIZE: A4			UNIT: mm
			SHEET: 1/1			 