


Kinghelm®

REV.	ECN NO.	DESCRIPTION	DATE	DESIGN
AO.	/	新版发行	24.12.20	

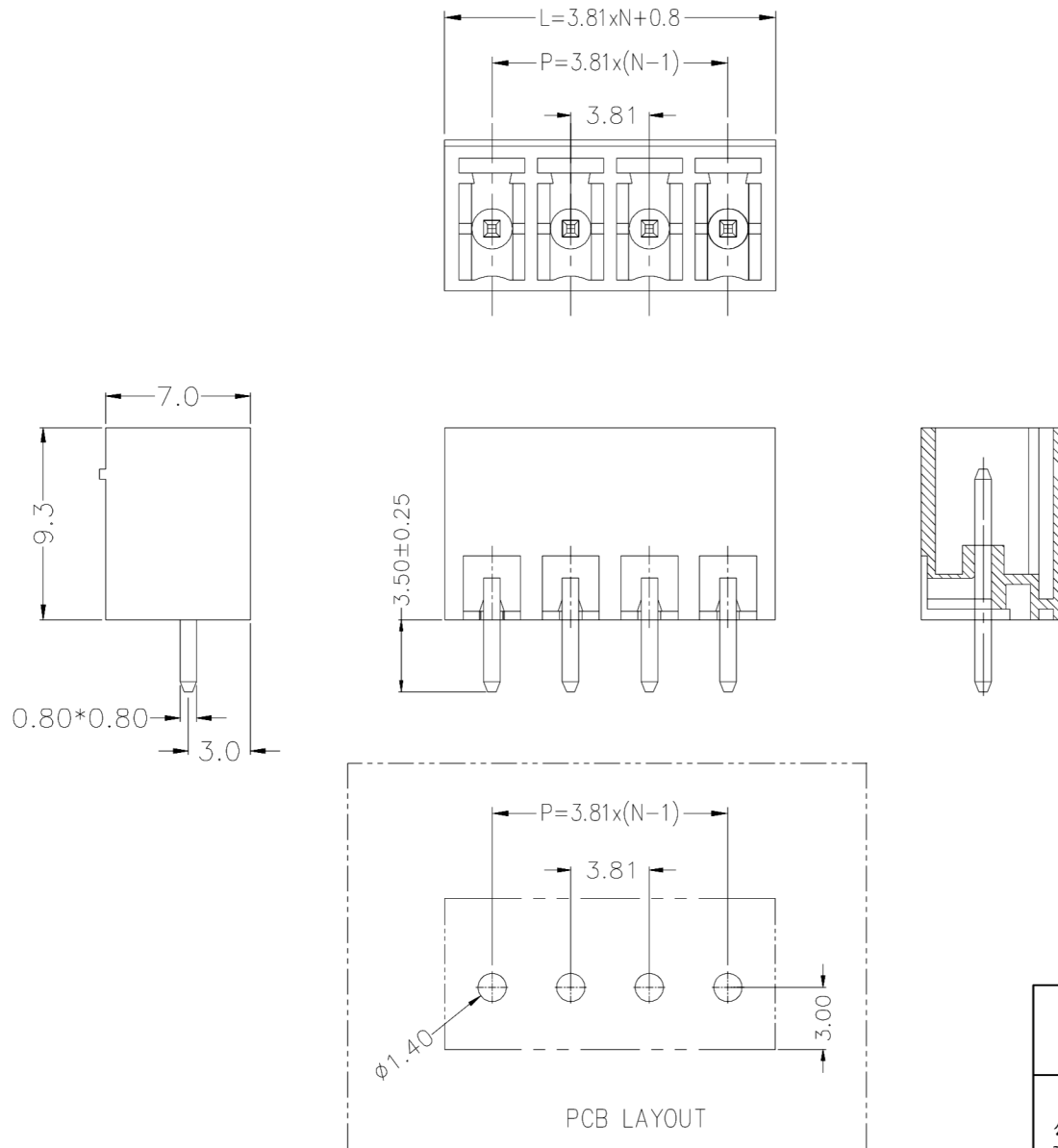

材料及电镀

- ①. 塑件主体: PA66, UL94V-0
- ②. 焊 针: 黄铜, 镀镍

电气性能

额定电压: 300V
额定电流: 8A
接触电阻: $20m\Omega$ (Max)
绝缘电阻: $500M\Omega$ \DC1000V
耐 电 压: AC1500V\1min

机械性能

温度范围: $-40^{\circ}\text{C} \sim +105^{\circ}\text{C}$
瞬时温度: $+250^{\circ}\text{C}$, 5秒

深圳市金航标电子有限公司

www.kinghelm.com.cn

0755-28190160

公差参数


Poles	Dim	Dim P	Dim L
2-6P		± 0.10	± 0.20
7-12P		± 0.20	± 0.30
13-18P		± 0.25	± 0.40
19-24P		± 0.30	± 0.50

NAME:

接线端子3.81封闭式直针

P/N:
KH-2BF200V-3.81-P-G-1 (**代表P数)
DWG NO:

 THIRD ANGLE PROJECTION



UNIT:	SCALE	SIZE:	SHEET:	REV.
MM	1:1	A4	1/1	A1

DRAWN:

CHECKED:

APPROVED: