

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

<b>Series</b>	2B
<b>Termination type</b>	No contacts / Accessory
<b>IP rating</b>	61 mated (mating interface)
<b>AWG wire size</b>	0.00 - 0.00
<b>Cable Ø</b>	0.00 - 0.00 mm
<b>Status</b>	Active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

<b>Shell Style/Model</b>	BRA*: Cap for receptacle
<b>Keying</b>	No keying
<b>Housing Material</b>	POM (Polyoxymethylene) shell without treatment, silicone gasket
<b>Weight</b>	1.24 g

### Performance

<b>Configuration</b>
<b>Insulator</b>
<b>Rated Current</b>

### Others

Endurance (Shell): 5000
Temp (min / max): -55 °C / +100 °C
Humidity (max): <=95% [at 60 deg C /140 F]
Vibration: 15 g [10 Hz - 2000 Hz]
Shock Resistance: 100 g [ 6 ms]


*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

Climatical Category: 50/175/21

Shielding (min): 75 dB (10 MHz)

Shielding (min): 40 dB (1 GHz)

## DRAWINGS

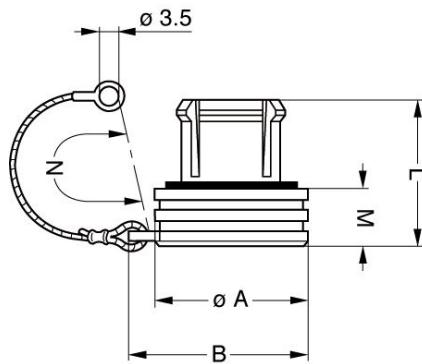

No keying

### Dimensions

	A	B	L	M	N
mm.	18	21	14.5	6	60
in.	0,71	0,83	0,57	0,24	2,36

## RECOMMENDED BY LEMO

### Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.