


Coaxial Cable Connector 16_4310-50-3-X1/003_-

Description

Right angle cable plug

Interface standards
IEC 61169-54

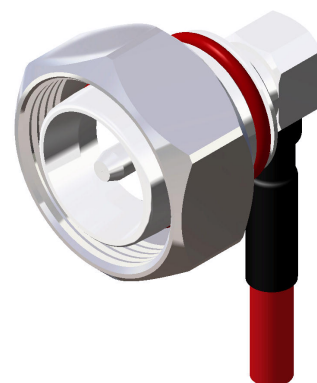

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	12 GHz

Mechanical Data

Centre contact	soldered
Outer contact	soldered
Weight	0.0287 kg

Environmental Data

Operating temperature	-55 °C to 90 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	Silver Plating
Outer contact	Brass	Silver Plating
Body	Brass	Silver Plating
Insulator	PTFE (Polytetrafluoroethylene)	
Coupling nut	Brass	SUCOPLATE (R) Plating
Gasket	VMQ (Silicone rubber)	

Related Documents

Outline drawing	DOU-00283695
Catalogue drawing	DCA-00292603
Assembly instruction	DOC-0000683297

Ordering Information

Bulk 100 pcs package	16_4310-50-3-X1/003_-H
----------------------	------------------------

Additional Information

Suitable cables	SUCOFORM_141_CU
-----------------	-----------------