




Connectors > Connector Accessories > Connector Seals & Cavity Plugs

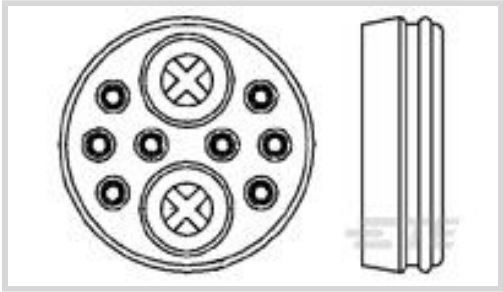

Connector Seal & Plug Type: **Wire Entry Seal Kit**

Operating Temperature (Max): **105 °C [221 °F]**

Number of Positions: **10**

Operating Temperature Range: **-55 – 105 °C [-67 – 221 °F]**

Features

Product Type Features

Connector Seal & Plug Type	Wire Entry Seal Kit
----------------------------	---------------------

Configuration Features

Number of Positions	10
---------------------	----

Mechanical Attachment

Thread Size	15/16-20
-------------	----------

Usage Conditions

Operating Temperature (Max)	105 °C[221 °F]
Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]

Packaging Features

Packaging Quantity	1
Packaging Method	Loose Piece

Other

Connector Accessory Comment	Kit includes (1) Silicon Wire Entry Seal and (1) Pressure Plate., Requires Cable Clamp Kit p/n 213902-1.
-----------------------------	--

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant



China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 213900-1
CPC SEAL ASSY KIT, SRS 6, 17-10

Also in the Series | AMP CPC

Circular Connector Adapters(7)	Circular Connector Caps & Covers(16)	Circular Connector Hardware(3)	Circular Connector Keying Plugs(2)



Circular Power Connectors(458)



Connector Backshells(56)




Connector Seals & Cavity Plugs(36)



Connector Strain Relief(6)



Insertion & Extraction Tools(1)

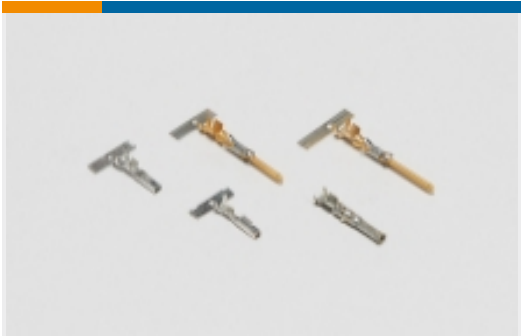

Power Contacts(6)



Sealing Sleeves(2)


Customers Also Bought




TE Part #213893-2
CPC RECPT SEALED SIZE 17-10



TE Part #1-967402-2
Circular DIN Housings

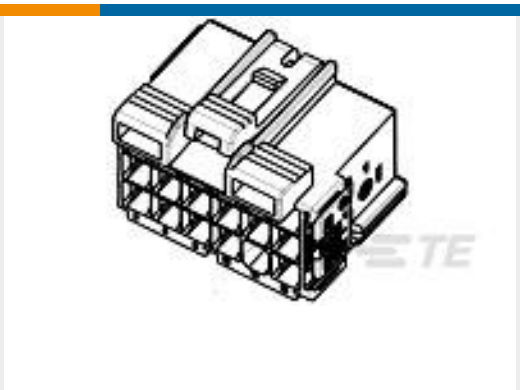

TE Part #1241581-1
JUN-POW-TIM HOUSING 17POS

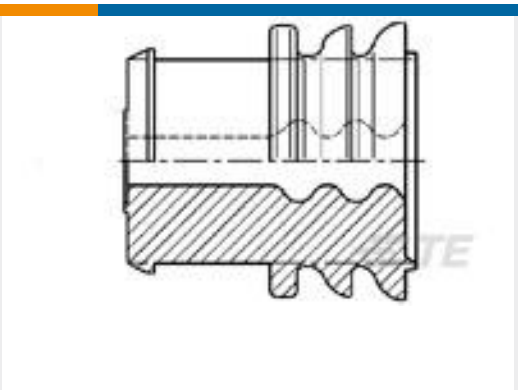


TE Part #963245-1
EINZELLEIT-DICHTUNG



TE Part #1-1564297-6
31POS, MIXED,REC HSG,ASSY



TE Part #1-1564512-1
Heavy Duty Sealed Connector Series Housings

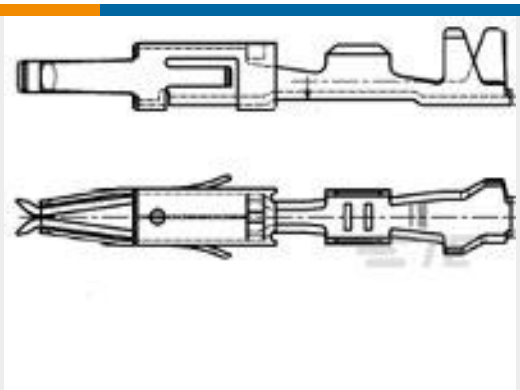

TE Part #962875-1
MT2 REC 1.6 Contact SWS Sn



TE Part #185793-1
90 DEG CAP CORRUGTD TUBE

Documents

Product Drawings

CPC SEAL ASSY KIT,SRS 6,17-10

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_213900-2_C.2d_dxf.zip



English

Customer View Model

[ENG_CVM_213900-2_C.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_213900-2_C.3d_stp.zip](#)

English

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_213900-2_B.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_213900-2_B.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_213900-2_B.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

[Product Specification](#)

English

Agency Approvals

[CSA Certificate](#)

English

[CSA Certificate](#)

English