


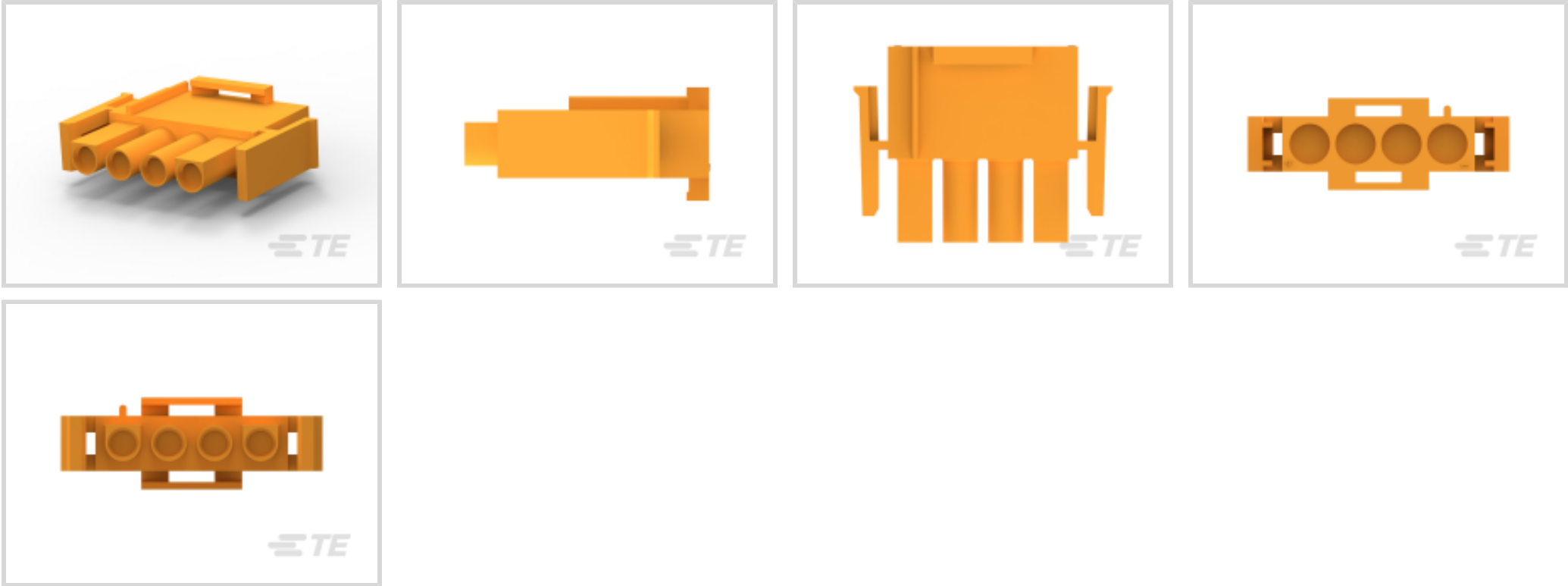

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought



TE Part #1-794610-1
MICRO MNL RPT CNT,LS PC 15AU L

TE Part #53240-1
PG SP SPD 22-16COMM22-18MIL 6

TE Part #1-350779-9
04P UMNL V0 PLUG HSG BLACK

TE Part #282834-2
TERMI-BLOK PCB MOUNT, 90 2P.

TE Part #8-1879130-1
RN 0402 4K99 0.1% 10PPM 5K RL

TE Part #5-2176422-2
TLRP 2512 3.0W R008 1% 50PPM 4K RL

TE Part #5-2176422-7
TLRP 2512 3.0W R018 1% 50PPM 4K RL

TE Part #1-350779-1
04P UMNL V0 PLUG HSG BROWN

TE Part #1-350779-5
04P UMNL V0 PLUG HSG GREEN

Documents

Product Drawings

04P UMNL V0 PLUG HSG ORANGE

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_1-350779-3_AB1.2d_dxf.zip

English

Customer View Model

ENG_CVM_1-350779-3_AB1.3d_igs.zip

English

Customer View Model

ENG_CVM_1-350779-3_AB1.3d_stp.zip

English

3D PDF

3D



Customer View Model

[ENG_CVM_CVM_1-350779-3_BB.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1-350779-3_BB.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1-350779-3_BB.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[SOFT_SHELL_PIN_SOCKET_CONNECTORS_STANDARD_DENSITY](#)

English

Product Specifications

[Application Specification](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English