


## Coaxial Panel Connector 23\_PC35-50-0-53/199\_U

### Description

Straight panel receptacle jack, flange mount

Interface standards  
IEC 60169-23

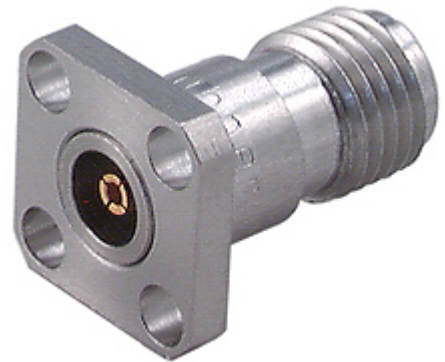

### Technical Data

#### Electrical Data

|                          |             |
|--------------------------|-------------|
| Impedance                | 50 $\Omega$ |
| Interface frequency max. | 26.5 GHz    |

#### Mechanical Data

|                   |           |
|-------------------|-----------|
| Number of matings | 500       |
| Weight            | 0.0035 kg |

#### Environmental Data

|                                                      |                  |
|------------------------------------------------------|------------------|
| Operating temperature                                | -60 °C to 100 °C |
| 2011/65/EU (RoHS - including 2015/863 and 2017/2102) | compliant        |

#### Material Data

| Piece Parts    | Material               | Surface Plating                            |
|----------------|------------------------|--------------------------------------------|
| Centre contact | Copper Beryllium Alloy | Gold Plating (without Nickel underplating) |
| Outer contact  | Stainless Steel        |                                            |
| Body           | Stainless Steel        |                                            |
| Insulator      | PS (Polystyrene)       |                                            |

### Related Documents

|                   |              |
|-------------------|--------------|
| Outline drawing   | DOU-00011352 |
| Catalogue drawing | DCA-00011353 |

### Ordering Information

|                |                        |
|----------------|------------------------|
| Single package | 23_PC35-50-0-53/199_UE |
|----------------|------------------------|