

Multilock Connector System

TE Internal #: 1438759-1

Wire-to-Wire, 22 Position, .098 in [2.5 mm] Centerline, White,
Signal, Cable Mount (Free-Hanging), Multilock Connector System

[View on TE.com >](#)



Connectors > Automotive Connectors > Automotive Housings > MULTILOCK, CONNECTOR HOUSING



Connector System: **Wire-to-Wire**

Number of Positions: **22**

Centerline (Pitch): **2.5 mm [.098 in]**

Sealable: **No**

Mating Tab Width: **1 mm [.039 in]**

[All MULTILOCK, CONNECTOR HOUSING \(567\)](#)

Features

Product Type Features

Mixed & Hybrid Connector	Yes
Connector Shape	Rectangular
Connector System	Wire-to-Wire
Sealable	No

Configuration Features

Number of Positions	22
Number of Rows	2

Body Features

Primary Product Color	White
Connector & Keying Code	B

Contact Features

Contact Size	1mm
Mating Tab Width	1 mm[.039 in]

Mechanical Attachment

Terminal Position Assurance	No
Strain Relief	Without
Mating Alignment Type	Keyed



Mating Alignment	With
Connector Mounting Type	Cable Mount (Free-Hanging)

Housing Features

Housing Material	PBT
Centerline (Pitch)	2.5 mm[.098 in]

Dimensions

Connector Height	25.55 mm[1.006 in]
Product Width	19.75 mm[.778 in]
Product Length	38 mm[1.496 in]

Usage Conditions

Operating Temperature (Max)	70 °C, 75 °C, 80 °C, 85 °C, 90 °C, 100 °C, 105 °C[158 °F][167 °F][176 °F][185 °F][194 °F][212 °F][221 °F]
Operating Temperature Range	-30 – 105 °C[-22 – 221 °F]

Operation/Application

Circuit Application	Signal
---------------------	--------

Packaging Features

Packaging Quantity	45
Packaging Method	Package

Other

Connector Position Assurance Capable	No
--------------------------------------	----

Product Compliance

For compliance documentation, visit the product page on [TE.com](#)>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free



Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-M9194-T273
MULTILOCK, RECEPTACLE AND TAB



TE Part # 9-1438743-6
54way Hyb .040/2.8 Tails Down Cap Assy



TE Part # CAT-A11-T273
1.5/2.8 CONNECTOR SYSTEM, RECPT AND TAB


Also in the Series | Multilock Connector System



Automotive Connector Caps & Covers (17)



Automotive Connector EMC Shielding (1)

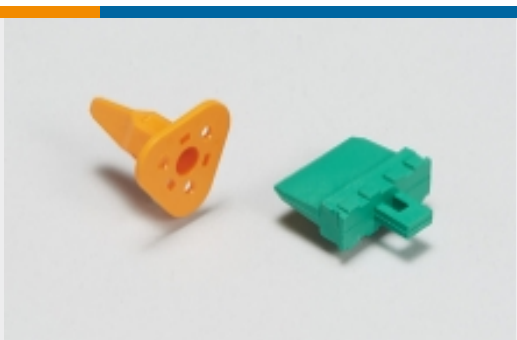

Automotive Connector Locks & Position Assurance(2)



Automotive Housings(603)



Automotive Terminals(141)




Connector Seals & Cavity Plugs(2)



Insertion & Extraction Tools(6)




Other Automotive Connector Accessories(14)

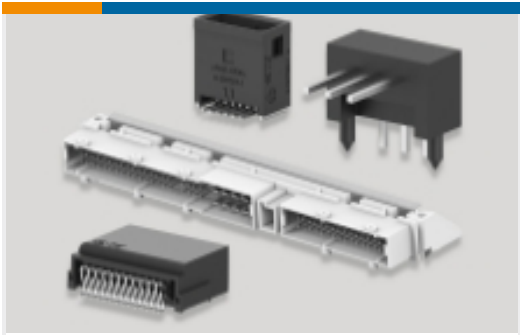


PCB Headers & Receptacles(142)


Customers Also Bought

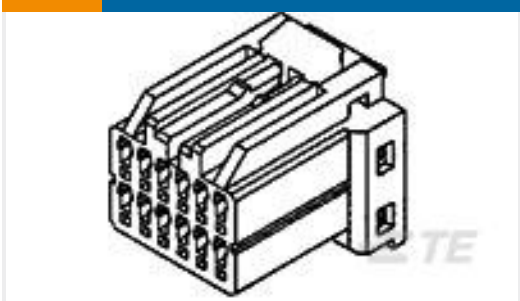


TE Part #175966-2
040 MLC II PLUG HSG ASSY 16P

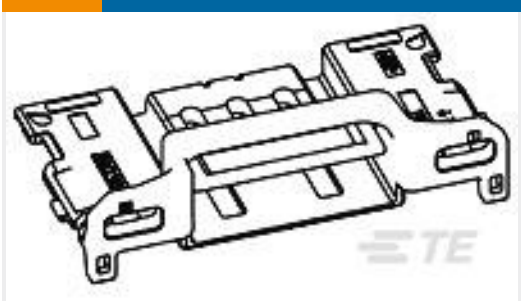


TE Part #1903614-1
0.5 6POS LOCK HOUSING

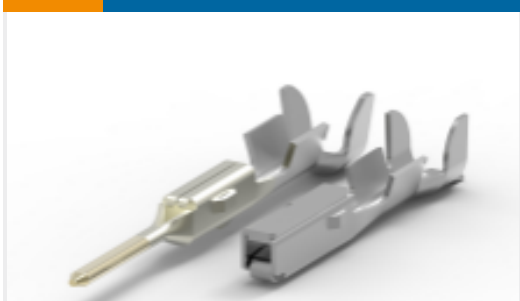

TE Part #284088-1
MULTILOCK, RECEPTACLE AND TAB

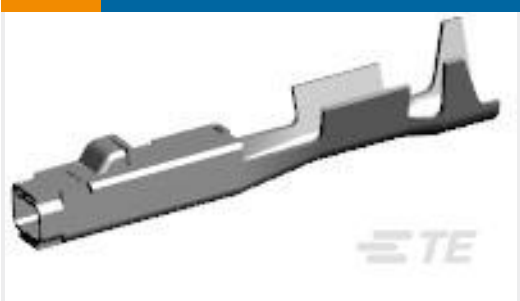

TE Part #1670144-2
MCON 1.2 CB REC SRC AU

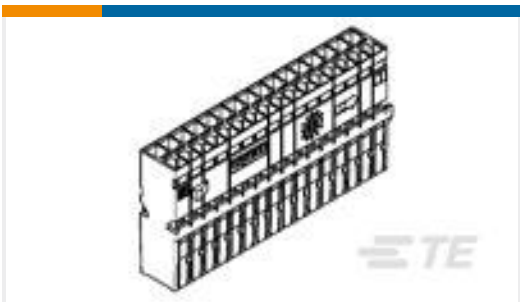

TE Part #1326141-1
32WAY LAC RECEPTACLE CARRIER H



TE Part #1326140-1
32WAY LAC SHIELD ASSEMBLY 70 D



TE Part #1438761-6
22WAY HYBRID .040/2.8 PLUG ASSY KEY'A'



TE Part #2819293-1
PIVOTED ARM ASSEMBLY



TE Part #2819292-1
ARM GUIDE

Documents

Product Drawings

22WAY HYBRID .040/2.8 PLUG ASSY KEY 'B'

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1438759-1_E.2d_dxf.zip



English

Customer View Model

[ENG_CVM_CVM_1438759-1_E.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1438759-1_E.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[MULTILOCK Connector System](#)

English

Product Specifications

[Application Specification](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English