

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

Series	1B
Termination type	No contacts / Accessory
IP rating	0
AWG wire size	0.00 - 0.00
Cable Ø	5.40 - 6.00 mm
Status	Active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	GMA*: Bend relief Grey
Keying	No keying
Housing Material	Thermoplastic polyurethane elastomer (Elastollan 1185 A)
Variant	G : Gray
Weight	.94 g

### Performance

Configuration

Insulator


Rated Current

### Others

Temp (min / max): -40°C / +80°C

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## DRAWINGS

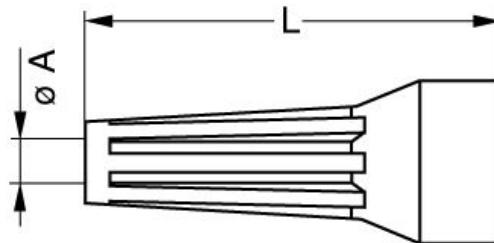

No keying

### Dimensions

	A	L
mm.	5.4	30
in.	0,21	1,18

## RECOMMENDED BY LEMO

### Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.