



Connectors > Circular Connectors > Circular Connector Accessories > Circular Connector Adapters



Compatible With Connector Shell Size: 23

Features

Product Type Features

Protection & Strain Relief Accessory Type	Coupling Ring
---	---------------

Body Features

Primary Product Material	Polyphenylene Oxide
Primary Product Color	Black

Operation/Application

Compatible With Connector Shell Size	23
--------------------------------------	----

Packaging Features

Packaging Quantity	1
--------------------	---

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC



Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts


TE Part # 206305-1
CPC PLUG ASSEMBLY SIZE 23-37

Also in the Series | AMP CPC

Circular Connector Adapters(7)	Circular Connector Caps & Covers(16)	Circular Connector Hardware(3)	Circular Connector Keying Plugs(2)
Circular Power Connectors(458)	Connector Backshells(56)	Connector Seals & Cavity Plugs(36)	Connector Strain Relief(6)



Insertion & Extraction Tools(1)

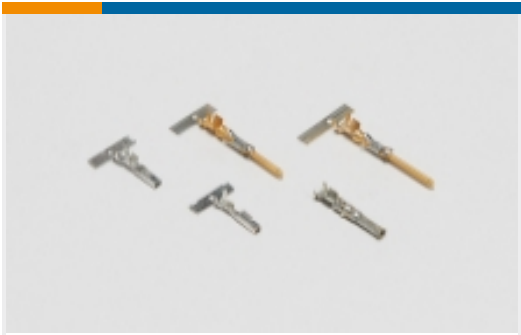

Power Contacts(6)



Sealing Sleeves(2)


Customers Also Bought



TE Part #206207-1
17-3 RECEPT. FREE-HANGING



TE Part #4-640440-6
16P MTA100 CONN ASSY 22AWG RED

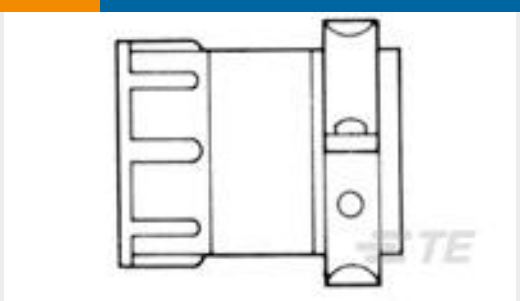

TE Part #1-206322-0
CABLE CLAMP KIT, BULK PKG



TE Part #66107-4
III+ PIN,26-24,30AU/FL,LP




TE Part #1-66332-4
III+ PIN,24-20,TIN ,STRIP




TE Part #YHDP26-24-19SEL024
DEUTSCH HDP20 Housings



TE Part #66255-8
MALE CONTACT ASSY. (STRIP)

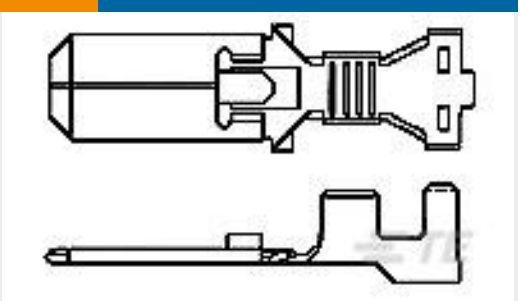

TE Part #344008-1
.250"SPEC.F.TAB (PLATED)

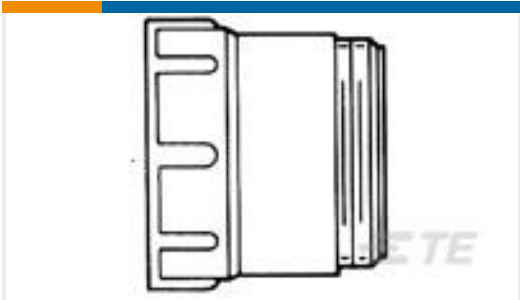

TE Part #207055-1
EXTENDER BACK SHELL

Documents

Product Drawings
COUPLING RING,SZ 23,CPC
English

CAD Files
3D PDF
English
Customer View Model
ENG_CVM_206251-1_D.2d_dxf.zip



English

Customer View Model
[ENG_CVM_206251-1_D.3d_igs.zip](#)

English

Customer View Model
[ENG_CVM_206251-1_D.3d_stp.zip](#)

English

[3D PDF](#)

3D

Customer View Model
[ENG_CVM_CVM_206251-1_Y.2d_dxf.zip](#)

English

Customer View Model
[ENG_CVM_CVM_206251-1_Y.3d_igs.zip](#)

English

Customer View Model
[ENG_CVM_CVM_206251-1_Y.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

[Instruction Sheets](#)
[Instruction Sheet \(U.S.\)](#)

English

[Agency Approvals](#)
[CSA Certificate](#)

English

[CSA Certificate](#)

English