

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Also in the Series | [Micro MATE-N-LOK](#)



Insertion & Extraction Tools(1)

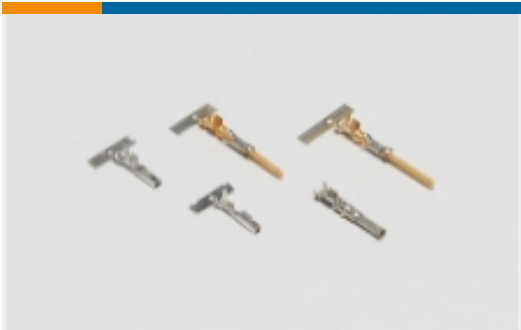

Power Contacts(27)



Rectangular Power Connectors(466)

Customers Also Bought



TE Part #7-2176459-7
SMD Power Resistor: 7 Watt, 0.10-500 Ohm



TE Part #4-794632-6
16P MICRO MNL ASSY,VRT,HDR,LF



TE Part #3-2176371-5
RQ 0603 10K5 0.1% 10PPM 5K RL



TE Part #1977830-1
DIP SWITCH GDH02SA04



TE Part #3-644761-3
03P MTA156 HDR ASSY R/A F/L LF



TE Part #AS107-35PA
RECEPT. IN LINE TYPE 1 AS MICRO 7



TE Part #AS920
CAP PROT. TYPE 9. #20



TE Part #AS922
CAP PROT. TYPE 9. #22

Documents

Product Drawings

MICRO MNL HDR ASSY S/ROW LF

English

CAD Files

Customer View Model

ENG_CVM_CVM_2-1445050-7_C.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2-1445050-7_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2-1445050-7_C.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.



Datasheets & Catalog Pages
SOFT_SHELL_PIN_AND_SOCKET_CONNECTORS_CATALOG

English
MICRO MATE-N-LOK CONNECTOR SYSTEM
English

Product Specifications
Application Specification

English

Product Environmental Compliance
MD_2-1445050-7_0819201759_dmtec

English
MD_2-1445050-7_0819201759_dmtec
English