

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

<b>Series</b>	2B
<b>Termination type</b>	No contacts / Accessory
<b>IP rating</b>	0
<b>AWG wire size</b>	0.00 - 0.00
<b>Cable Ø</b>	6.00 - 6.50 mm
<b>Status</b>	Active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

<b>Shell Style/Model</b>	GMA*: Bend relief Red
<b>Keying</b>	No keying
<b>Housing Material</b>	Thermoplastic polyurethane elastomer (Elastollan 1185 A)
<b>Variant</b>	R : Red
<b>Weight</b>	1.71 g

### Performance

**Configuration**

**Insulator**


**Rated Current**

### Others

Temp (min / max): -40°C / +80°C

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## DRAWINGS

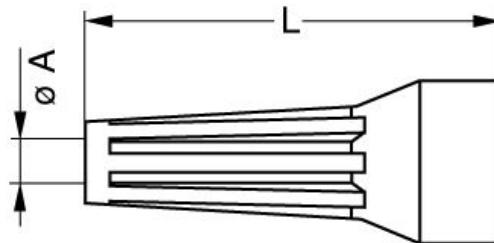

No keying

### Dimensions

	A	L
mm.	6.0	36
in.	0,24	1,42

## RECOMMENDED BY LEMO

### Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.