


Coaxial Cable Connector 25_SMA-50-2-5/111_N

Description

Straight panel cable jack, flange mount

Interface standards

IEC 60169-15_MIL-STD-348A/310_CECC 22110

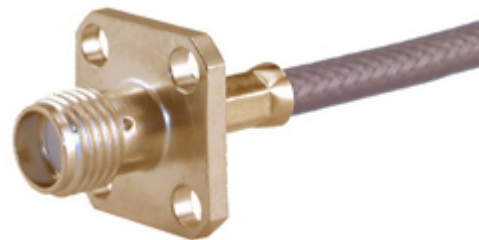

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	18 GHz

Mechanical Data

Centre contact	soldered
Outer contact	crimped
Weight	0.0035 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Body	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	
Crimp ferrule	Copper	Gold Plating (without Nickel underplating)

Related Documents

Catalogue drawing	DCA-00009528
Assembly instruction	DOC-0000184970
Mounting hole	DOU-00008784

Ordering Information

Single package	25_SMA-50-2-5/111_NE
Bulk 100 pcs package	25_SMA-50-2-5/111_NH

Additional Information

Suitable cables	RG_316_/U, RG_188_A/U, RG_174_/U
-----------------	----------------------------------