


Coaxial Cable Connector 25_TNC-50-3-9/133_N

Description

Straight panel cable jack, flange mount

Interface standards

IEC 60169-17_MIL-STD-348A/313_CECC 22200

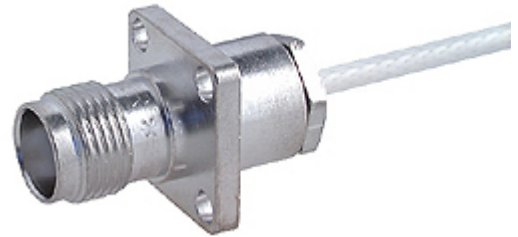

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	11 GHz

Mechanical Data

Centre contact	soldered
Outer contact	clamped
Weight	0.0181 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Brass	SUCOPLATE (R) Plating
Body	Brass	SUCOPLATE (R) Plating
Insulator	PFA / PTFE	
Gasket	VMQ (Silicone rubber)	

Related Documents

Outline drawing	DOU-00009209
Catalogue drawing	DCA-00009210
Assembly instruction	DOC-0000179064

Ordering Information

Single package	25_TNC-50-3-9/133_NE
----------------	----------------------

Additional Information

Suitable cables	RG_58_C/U, RG_223_/U, ENVIROFLEX_142, RG_400_/U
-----------------	---