


Coaxial PCB Connector
84_BMA-50-0-1/111_N

Description

Right angle PCB plug

Interface Standards
IEC 60169-33_MIL-STD-348A/321

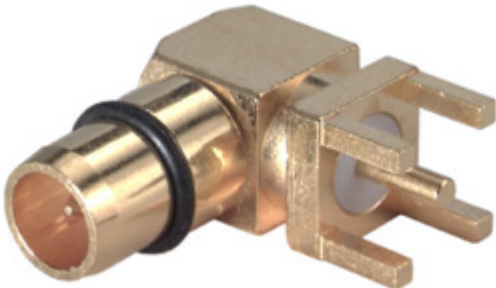

Technical Data

Electrical Data

Impedance 50 Ω
Interface frequency max. 18 GHz

Mechanical Data

Board mounting type through holes
Weight 0.0031 kg

Environmental Data

Operating temperature -65 °C to 125 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102) compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium / Brass	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Body	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Insulator	PFA / PTFE	
Gasket	NR (Natural Rubber)	

Related Documents

Catalogue drawing DCA-00012880

Ordering Information

Single package 84_BMA-50-0-1/111_NE

Remarks

PCB connector without stand-offs