




AMP CT

TE Internal #: 3-179694-0
Connector Assembly, Receptacle, Wire-to-Board, 10 Position, .079 in [2 mm] Centerline, Insulation Displacement (IDC), 1 Row, Gray, AMP CT

[View on TE.com >](#)

Connectors > PCB Connectors > Wire-to-Board Connectors > Wire-to-Board Connector Assemblies & Housings > AMP COMMON TERMINATION HOUSINGS

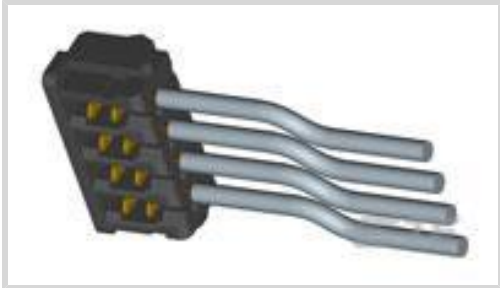

Connector Product Type: **Connector Assembly**
Connector & Housing Type: **Receptacle**
Connector System: **Wire-to-Board**
Number of Positions: **10**
Centerline (Pitch): **2 mm [.079 in]**

[All AMP COMMON TERMINATION HOUSINGS \(176\)](#)

Features

Product Type Features

Connector Product Type	Connector Assembly
Connector & Housing Type	Receptacle
Connector System	Wire-to-Board
Sealable	No
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	10
Number of Rows	1

Body Features

Primary Product Color	Gray
-----------------------	------

Contact Features

Contact Current Rating (Max)	3 A
------------------------------	-----

Termination Features

Termination Method to Wire & Cable	Insulation Displacement (IDC)
------------------------------------	-------------------------------

Mechanical Attachment

--	--



Mating Retention Type	Lock
Mating Retention	With
Connector Mounting Type	Cable Mount (Free-Hanging)

Housing Features

Housing Material	PBT GF
Centerline (Pitch)	2 mm[.079 in]

Usage Conditions

Operating Temperature Range	-30 – 105 °C[-22 – 221 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Power & Signal
---------------------	----------------

Product Compliance

For compliance documentation, visit the product page on [TE.com](#)>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1-292206-0
MINI CT SGL DIP H 10P NAT



TE Part # CAT-3980408-PHDWKV
CT 2mm Post Header Assembly with
Kink - Vertical



TE Part # CAT-3980407-RHRRRA
CT 2mm Header Assembly: Right
Angle



TE Part # CAT-3983178-PHBXVD
CT 2mm Post Header Asmbly: Box V
DIP



TE Part # 1-292250-0
CT P/HDR BOX H ASSY 10P W/KINK



TE Part # 58074-1
MTA 50/100/156 MANUAL TOOL
FRAME



TE Part # 58372-1
HEAD (IDC) 2MM C.T. W/O TL



TE Part # 1-292254-0
CT RELAY HDR ASSY 10P NAT




TE Part # 1-292215-0
MINI CT SGL RELAY 10P NAT



TE Part # 1-292207-0
MINI CT SGL DIP V 10P NAT




TE Part # 1-292133-0
CT P/HDR ASSY BOX V 10P W/O KI

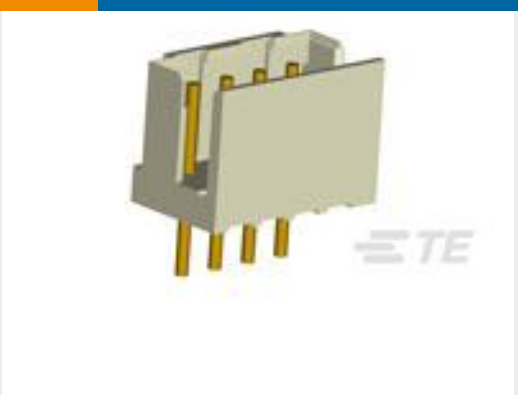

TE Part # 1-292134-0
CT BOX HDR ASSY V 10P AU W/KIN



TE Part # 1-292164-0
CT P/HDR BOX H ASSY 10P T/P NA

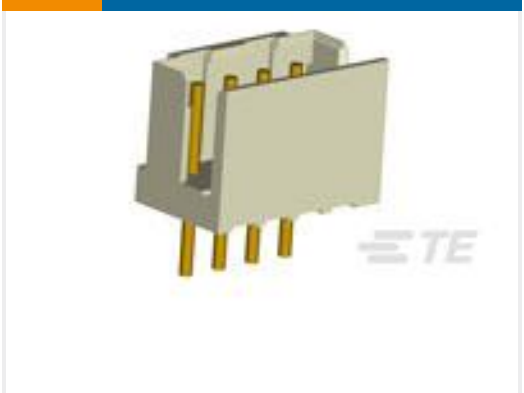

TE Part # 1-292165-0
CT P/HDR BOX V 10P T/P NAT



TE Part # 1-292166-0
CT P/HDR BOX V 10P T/P NAT W/O



TE Part # 1-292271-0
MT REC ASSY(GOLD-PLATING) FOR



TE Part # 6-292271-0
MT REC ASSY AU-PL. 10P BLUE

Also in the Series | AMP CT



PCB Connector Mounting(46)



PCB Headers & Receptacles(756)



Wire-to-Board Connector Assemblies
& Housings(256)



Wire-to-Board Connector Contacts(8)


Customers Also Bought



TE Part #9-1393211-0
T92S11D12-24



TE Part #1375820-2
CST-100 II HOUSING 2 POS

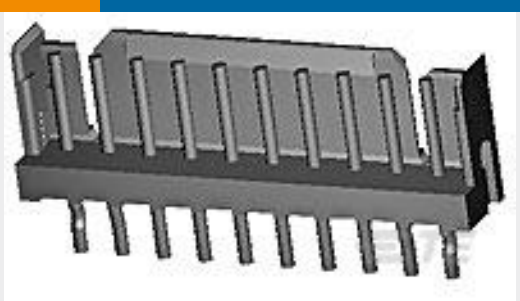


TE Part #292161-8
CT P/HDR ASSY V 8P W/KINK NAT



TE Part #173977-8
AMP COMMON TERMINATION
HOUSINGS




TE Part #953697-1
3POS MQS REC

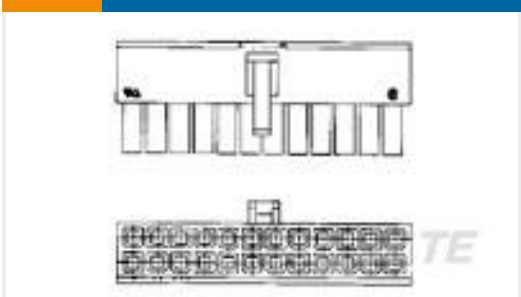

TE Part #1-794954-0
10P RCPT VAL-U-LOK V2



TE Part #1586852-1
04P UMNL PLUG HSG, GW

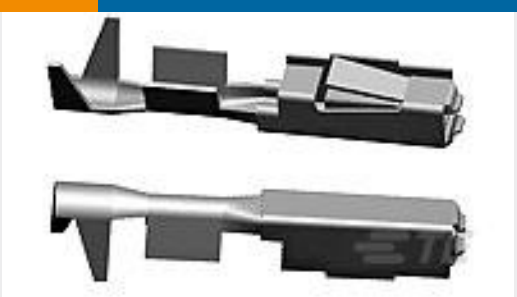

TE Part #5-928999-1
MQS0,63 Sn rec LL unseal. >0,2-0,35

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_3-179694-0_F.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_3-179694-0_F.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_3-179694-0_F.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

POWER_CONNECTORS_CATALOG_SEC02_CABLE_MOUNTED

English



[Product Specifications](#)

[Application Specification](#)

English