


Coaxial Panel Connector 12_SMP-50-0-S1/119_N

Description

Straight bulkhead receptacle plug

Interface standards
MIL-STD-348 SMP

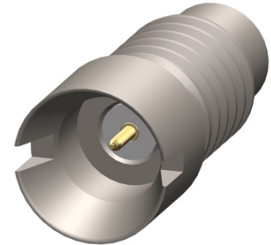

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	40 GHz

Mechanical Data

Number of matings	1000
Weight	0.0007 kg

Environmental Data

Operating temperature	-55 °C to 125 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Stainless Steel	
Body	Stainless Steel	
Insulator	PTFE (Polytetrafluoroethylene)	

Related Documents

Outline drawing	DOU-00316611
-----------------	--------------

Ordering Information

Single package	12_SMP-50-0-S1/119_NE
----------------	-----------------------