


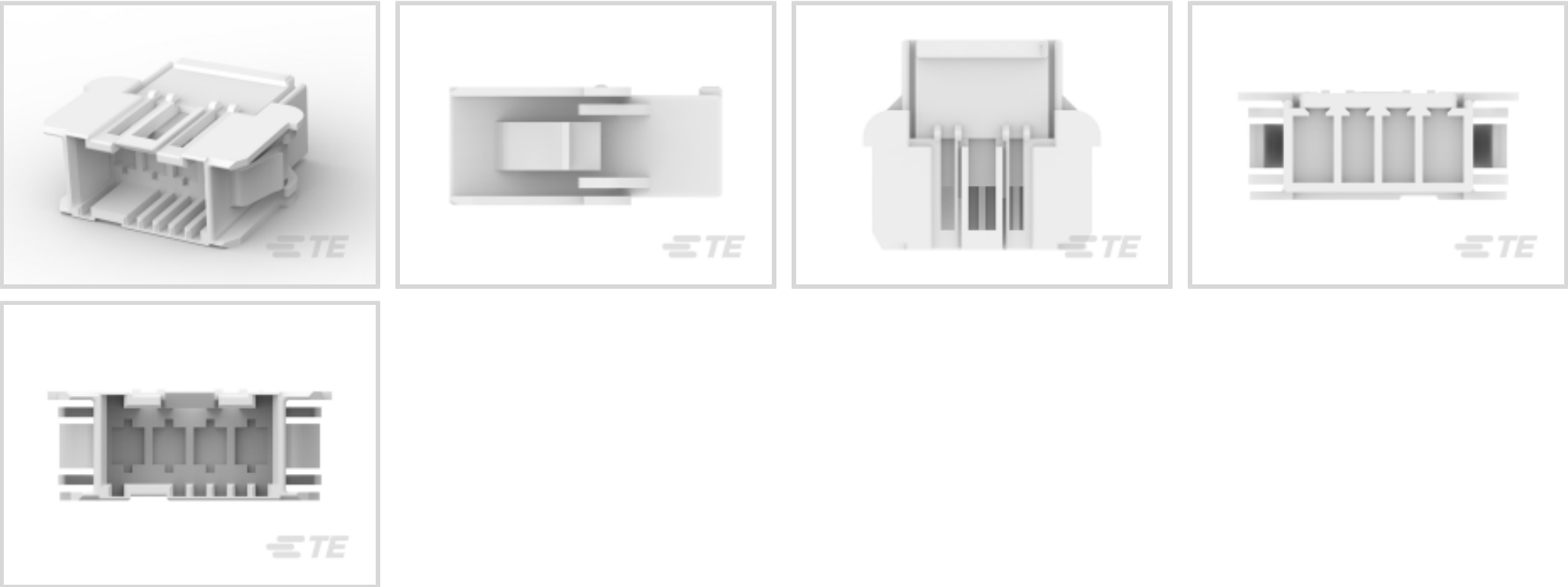

Connectors > PCB Connectors > Wire-to-Board Connectors > Wire-to-Board Connector Assemblies & Housings



Connector Product Type: **Housing**
Connector & Housing Type: **Plug**
Connector System: **Wire-to-Wire**
Number of Positions: **4**
Centerline (Pitch): **5 mm [.197 in]**

Features

Product Type Features

| | |
|-----------------------------------|--------------|
| Connector Product Type | Housing |
| Connector & Housing Type | Plug |
| Connector System | Wire-to-Wire |
| Sealable | No |
| Connector & Contact Terminates To | Wire & Cable |

Configuration Features

| | |
|---------------------|---|
| Number of Positions | 4 |
| Number of Rows | 1 |

Body Features

| | |
|-----------------------|---------|
| Primary Product Color | Natural |
|-----------------------|---------|

Mechanical Attachment

| | |
|--------------------------|---------|
| Panel Mount Feature | With |
| Panel Mount Feature Type | Latches |
| Mating Retention | Without |



| | |
|-----------------------------|----------------------------|
| Connector Mounting Type | Panel Mount |
| Housing Features | |
| Centerline (Pitch) | 5 mm[.197 in] |
| Usage Conditions | |
| Operating Temperature Range | -25 – 105 °C[-13 – 221 °F] |
| Operation/Application | |
| Circuit Application | Power & Signal |

Product Compliance

For compliance documentation, visit the product page on TE.com>




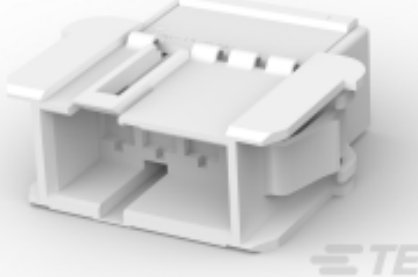
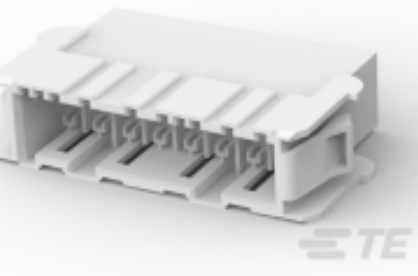
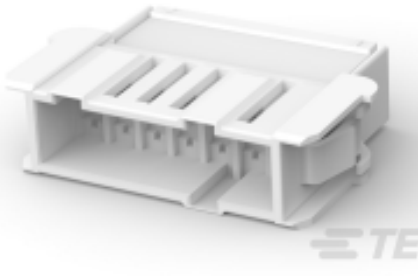
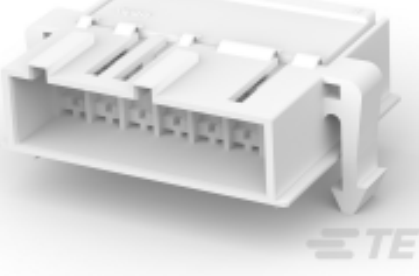
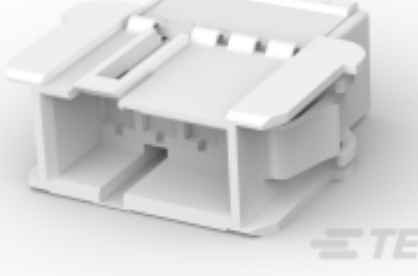





| | |
|---|---|
| EU RoHS Directive 2011/65/EU | Compliant |
| EU ELV Directive 2000/53/EC | Compliant |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold |
| EU REACH Regulation (EC) No. 1907/2006 | Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC |
| Halogen Content | Not Low Halogen - contains Br or Cl > 900 ppm. |
| Solder Process Capability | Not applicable for solder process capability |

Product Compliance Disclaimer



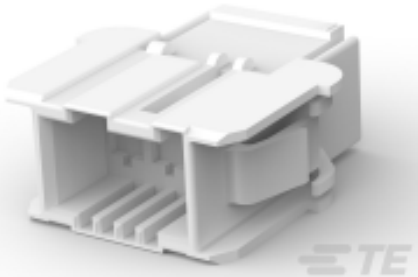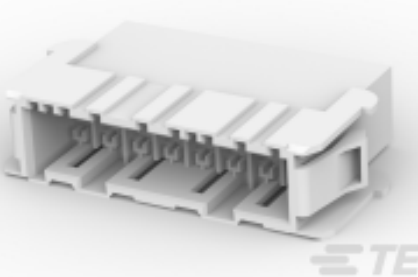

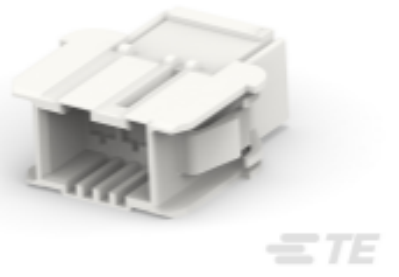This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



| | | | |
|--|---|--|--|
|  <p>TE Part # 293008-1 3 POS. FASTIN-FASTON CONN. TAB HOUSING R</p> |  <p>TE Part # 1241967-8 FASTIN FASTON TAB HOUSING 8P</p> |  <p>TE Part # 1241857-5 5 POS FASTIN/ON HOUSING PANEL MOUNT</p> |  <p>TE Part # 9-927742-4 4POS FASTIN FASTON HOUSING</p> |
|  <p>TE Part # 5-1241967-8 FASTIN FASTON TAB HOUSING 8P</p> |  <p>TE Part # 293044-1 7 POS. FASTIN-FASTON* TAB HOUSING, RAST5</p> |  <p>TE Part # 293014-1 7 POS. FASTIN FASTON TAB HSG</p> |  <p>TE Part # 927742-4 4 POS FASTIN/ON HOUSING PANEL MOUNT</p> |
|  <p>TE Part # 1-1241968-5 FASTIN FASTON HOUSING 10P</p> |  <p>TE Part # 1-293008-1 3 POS. FASTIN-FASTON CONN. TAB HOUSING R</p> |  <p>TE Part # 293008-5 3 POS. FASTIN-FASTON CONN. TAB HOUSING R</p> |  <p>TE Part # 293010-4 5 POS. FASTIN-FASTON CONN. TAB HOUSING R</p> |
|  <p>TE Part # 1-928230-2 2 POS FASTIN/ON HOUSING PANEL MOUNT</p> | | | |

Also in the Series | RAST 5 IDC Connectors


| | | | |
|--|---|--|--|
|  <p>Automotive Terminals(8)</p> |  <p>Connector Contacts(12)</p> |  <p>Crimp Terminal Housings(41)</p> |  <p>Insertion & Extraction Tools(1)</p> |
|--|---|--|--|



PCB Headers & Receptacles(417)



Rectangular Connector Housings(1)

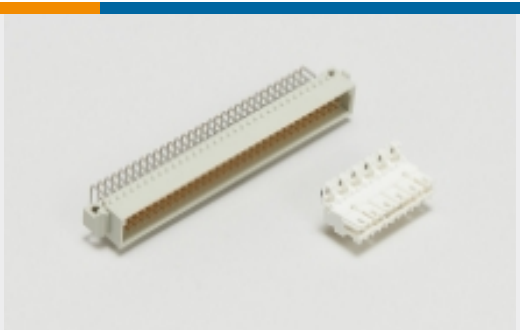

Standard Edge Connectors(34)



Standard Rectangular Connectors(68)




Wire-to-Board Connector Assemblies & Housings(214)



Wire-to-Board Connector Contacts(2)

Customers Also Bought

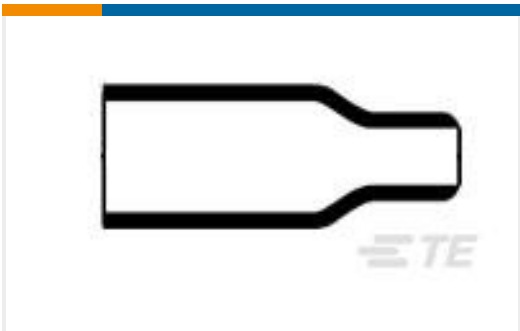

TE Part #806696-000
202A121-25-0



TE Part #2398990001
HT-SCE High Temperature Sleeves



TE Part #293008-1
3 POS. FASTIN-FASTON CONN. TAB HOUSING R



TE Part #1376477-3
2.5MM PITCH SIGNAL MATE CONN



TE Part #1376476-1
2.5 SIGNAL MATE REC CONTACT



TE Part #277148-4
TERMINAL,COPALUM R 6 3/8



TE Part #202758-3
6 PL. BLOCK



TE Part #EK7301-000
222S121-25C-0

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_293009-1_B_c-293009-1-b.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_293009-1_B_c-293009-1-b.3d_igs.zip



English

Customer View Model

[ENG_CVM_CVM_293009-1_B_c-293009-1-b.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[FASTIN_FASTON_Product_Line](#)

English

Product Specifications

[Product Specification](#)

English

Product Environmental Compliance

[MD_293009-1_122720171234_dmtec](#)

English

[MD_293009-1_122720171234_dmtec](#)

English

Agency Approvals

[VDE Certificate](#)

English