




Connectors > PCB Connectors > Wire-to-Board Connectors > FFC, FPC & Ribbon Connectors > FFC Contacts >
2.54mm FFC Connectors Socket Contacts

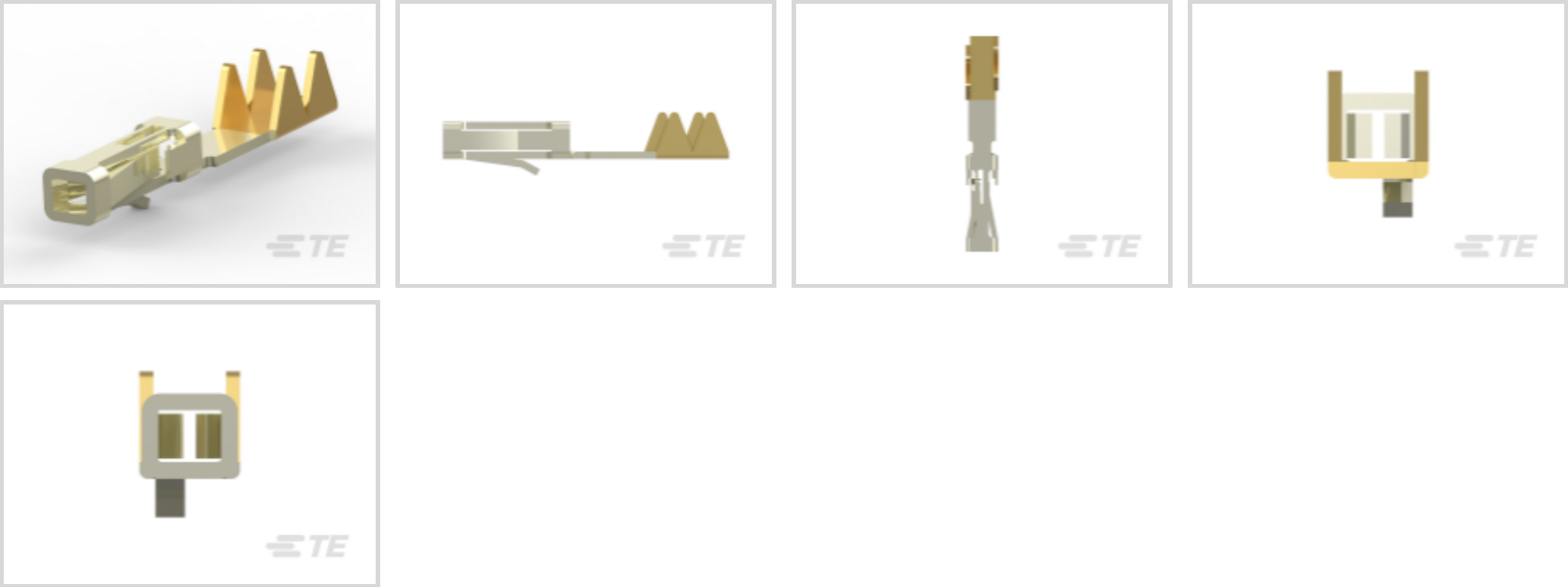

Centerline (Pitch): **2.54 mm [.1 in]**

Compatible With Wire & Cable Type: **FFC**

Contact Type: **Socket**

Contact Mating Area Plating Material: **Gold Flash**

Packaging Method: **Reel**

[All 2.54mm FFC Connectors Socket Contacts \(35\)](#)

Features

Product Type Features

Connector & Contact Terminates To	Wire & Cable
-----------------------------------	--------------

Configuration Features

Compatible With Wire & Cable Type	FFC
-----------------------------------	-----

Contact Features

	50 µin
Contact Underplating Material	Nickel
PCB Contact Termination Area Plating Material	Gold Flash
Contact Base Material	Phosphor Bronze
Contact Type	Socket
Contact Mating Area Plating Material	Gold Flash
Contact Current Rating (Max)	2 A

Termination Features

Termination Method to Wire & Cable	Insulation Displacement (IDC)
------------------------------------	-------------------------------



Housing Features

Centerline (Pitch)	2.54 mm[.1 in]
--------------------	----------------

Dimensions

Accepts Conductor Width	1.27 mm[.05 in]
-------------------------	-----------------

Usage Conditions

Operating Temperature Range	-65 – 105 °C[-85 – 221 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Signal
---------------------	--------

Packaging Features

Packaging Method	Reel
------------------	------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2023 (235) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

TE Part # CAT-F439-R2435254 2.54mm FFC Connectors Receptacle Housing	TE Part # CAT-F439-P65254 2.54mm FFC Connectors Pin Contacts	TE Part # CAT-F439-S01339254 2.54mm FFC Connectors Socket Contacts	TE Part # 1-487526-8 019 HOUSING FFC RCPT 100CL SR
TE Part # 1-528013-1 FFC PISTOL GRIP HAND TOOL CASE	TE Part # 2394880-3 FFC BASE MACHINE MARK II, ENGLISH	TE Part # 5-528441-5 APPLIC. FFC-MODU.100	

Customers Also Bought

TE Part #487526-1 002 HOUSING FFC RCPT 100CL SR	TE Part #3-1827233-6 .5FHP05H,440,B,GIG,08/Sn,HT,NS	TE Part #2-1761606-6 IDC LOW PRO HDR 16P VERT LG LAT BLUE	TE Part #4-794682-0 10P MICRO MNL ASSY,VRT,THRU,LF BLUE
TE Part #3-1827231-6 .5FHR04H,440,B,GIG,08/Sn,HT,NS	TE Part #1625854-3 0603 PROBE PAD	TE Part #103673-6 07 MTE HDR SRRA LATCH W/HLDWN	TE Part #1734577-2 MOD-JK,8P8C,SHD W/LED, G/Y,15U
TE Part #6-1393254-4 W92-X1110-30=M6/M7/M9/W6/W7	TE Part #3-1761606-5 IDC LOW PRO HDR 50P VERT LG LA		



Documents

Product Drawings

RCPT CONTACT,STD PRESS,FFC

English

CAD Files

Customer View Model

ENG_CVM_CVM_2-487406-6_AV.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2-487406-6_AV.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2-487406-6_AV.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English

Product Environmental Compliance

Product Compliance

English

Product Compliance

English

Instruction Sheets

Instruction Sheet (U.S.)

English

Extraction Tools

English