


Coaxial Cable Connector 16_MCX-50-2-14/133_N

Description

Right angle cable plug

Interface standards

IEC 60169-36_CECC 22220

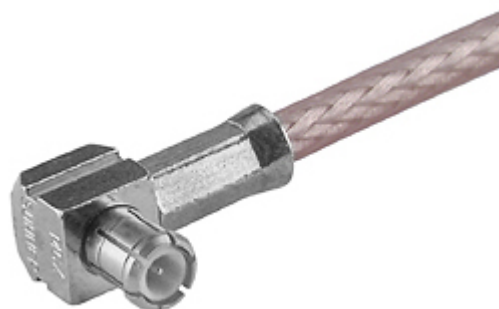

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	6 GHz

Mechanical Data

Centre contact	soldered
Outer contact	crimped
Weight	0.0012 kg

Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	SUCOPLATE (R) Plating
Body	Brass	SUCOPLATE (R) Plating
Insulator	PFA / PTFE	
Crimp ferrule	Copper	SUCOPLATE (R) Plating

Related Documents

Outline drawing	DOU-00006021
Catalogue drawing	DOU-00006016
Assembly instruction	DOC-0000179229

Ordering Information

Single package	16_MCX-50-2-14/133_NE
Bulk 100 pcs package	16_MCX-50-2-14/133_NH

Additional Information

Suitable cables	ENVIROFLEX_316, RG_316_/U, RG_188_A/U, RG_174_/U
-----------------	--